


BU-P1330-@
(Solderless Double Banana Plug)

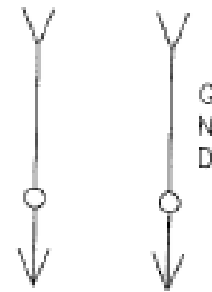

SCHEMATIC

- The BU-P1330 is a solderless, dual banana plug with plugs spaced 0.75" center-to-center.
- Overall length 1.58" (40.13mm), overall width 1.13" (28.7mm)
- Material: Body Nylon
 Contacts Nickel-plated beryllium copper
- Rating: Current 15 Amps
 Voltage Hands-free testing to 5000 VRMS
 Temperature -50°C to 105°C
- Color: The "@" in the model number indicates color.
 Available colors are: -0 Black, -2 Red
- RoHS 3 compliant, exemption 6c