

1

2

3

4

A

B

C

D

A

B

C

D

MATERIAL:

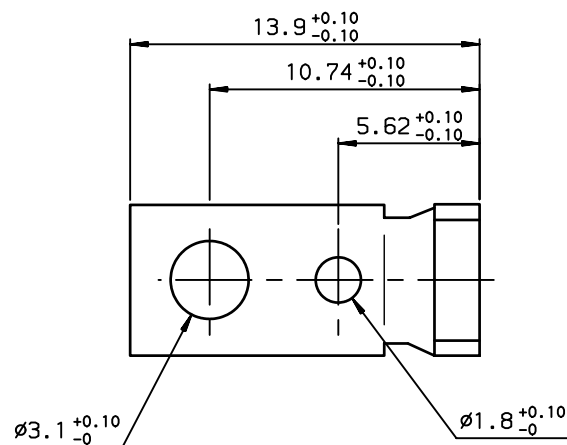
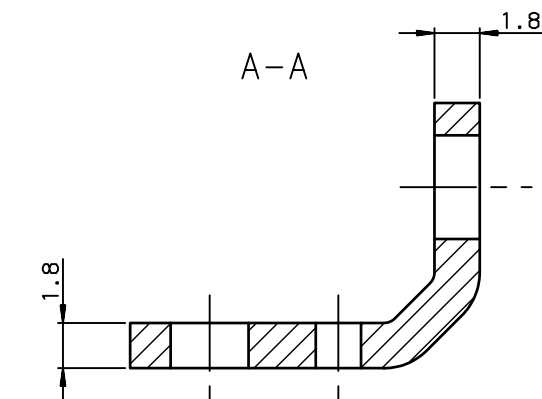
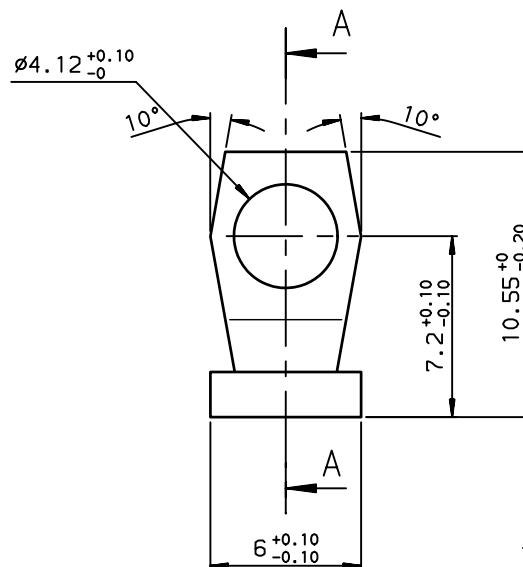
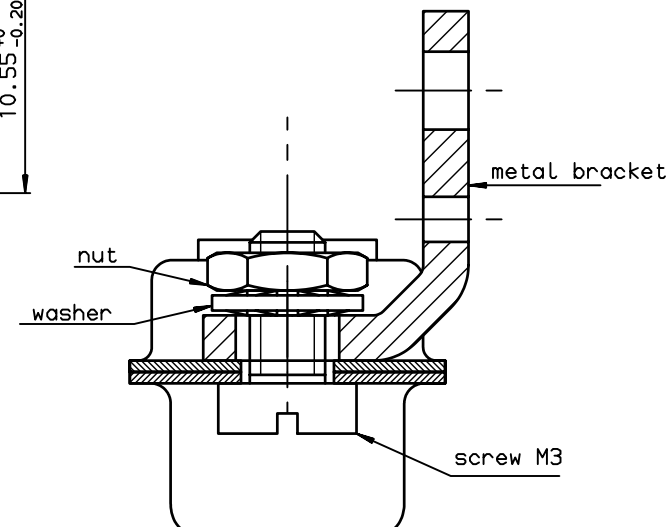
Steel . Tin Lead plating

TEMPERATURE RANGE:

-Climatic category: -55°/+125°

PACKAGING:

Per 100 pieces

BRACKET MOUNTINGPart
number

86552008TLF

NOTE:RoHS INFORMATIONS

- The "LF" products meet European union Directives and other country regulations as described in GS-22-008.
- Plating Sn (pure bright) over copper
- Packaging spec: see GS-14-920

rev	ecn no	dr	date
A	-	JOU	1998/04/10
B	LS05-0026	MPE	2005/07/08
C	LS06-0097	LGO	2006/07/28
D	LS09-0006	PCR	2009/01/08
-	-	-	-
-	-	-	-
-	-	-	-

www.fciconnect.com			surface ISO 1302		tolerance std ISO 406 ISO 1101		projection 		mm 		
TOLERANCES UNLESS OTHERWISE SPECIFIED											
Dr	JOUBERT	1998/04/10	ANGULAR	LINEAR	0.X	±0.1	size A3	Scale 5			
Eng	PESSON	1998/04/10			0.XX	±0.1					
Chr	LEGARE	1998/04/10			0.XXX	±0.1		ECN LS09-0006			
Appr	LEGARE	1998/04/10	Product family				D-SUB	Spec ref -			
			title METAL BRACKETS D SUB ACCESSORIES				dwg no C01-8655-1512		Rev. D		
catalog no			-				CUSTOMER		sheet 1 of 1		