


REV.	ECN NO.	DATE	SIGN	DESCRIPTION
A	Initial Released	2020/11/25	Ruru	Old Item No. CX-04BCM32-7001

QC Laser Mark:
YYYY = Year
WW = Week

Cable Joiner Housing Part Number
FC-001BNGY-700X

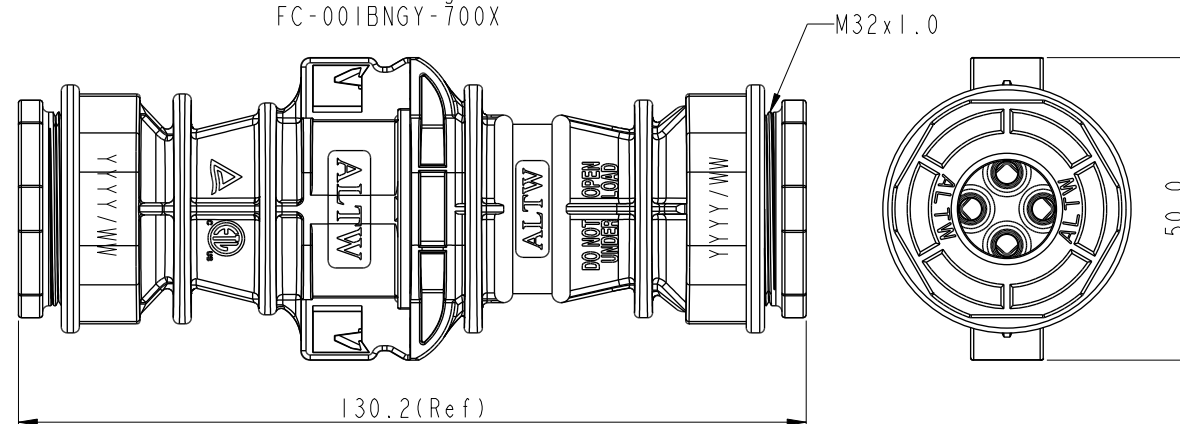

Note:
* Waterproof Rate: IP67, Mated
* Connector: Thermoplastic, Black
* Butt Pin: Copper alloy
* Gasket: Rubber, Gray
* Disassembly-Using the Unlock tool.
* Operating Temperature : -40~+105°C
* Withstanding Voltage : 6KV
* Pollution Degree : III
* Cable OD Range: 16mm~12mm
* Wire Range: 10#~12#(4mm²~6mm²)
* Avoid oil and gasoline
* Recommended sealing Nut torque
Minimum: 25Kgf-cm

* FC-001BNGY-700X
UL 6703A & TUV 2pfg 1915
* Butt Terminals
UL 486A/B

UNIT:mm
TOLERANCE
± 0.5 mm

TITLE
FICX, 4, 1, Field Installable
Crimp, Gray
SCALE
4:5
SIZE
A4
SHEET
1 OF 1
REV.
A
WC-REV.
B.4
QC: Inspection item

Amphenol LTW
安費諾亮泰企業股份有限公司

ITEM NO. FC-04IBCGY-7001	DRAWN BY Ruru	DATE 2020-11-25
DWG NO. FC-04IBCGY-7001	CHECKED BY Rita	DATE 2020-11-25
CUSTOMER ALTW	APPROVED BY Max	DATE 2020-11-25