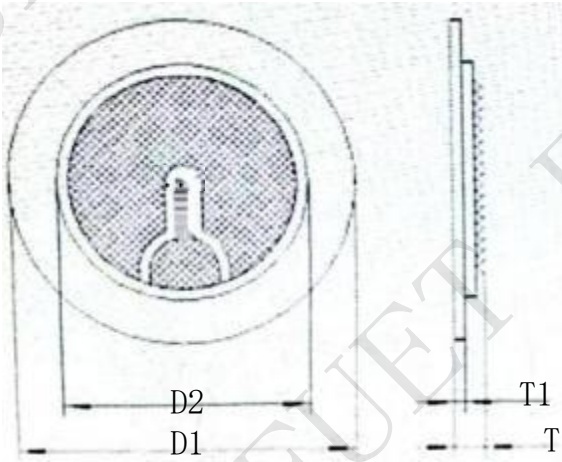


项 目 Item		要 求 Requirements										
型号规格 Type &Specification		FT-23G-3.6B1-C32										
自 由 电容 (nF) Free Capacitance		主电极：32±30%，反馈电极：3.4±30% (at 120Hz)										
介电损耗 (tan δ) Dielectric loss		≤5%										
谐振频率 (kHz) Resonant Frequency		3.6±0.5										
等 效 电 阻 (Q) Equivalent Resistance		≤600										
金属片材质 Metal Material		SUS304										
外形尺寸 (mm) External Dimension Drawing		如下图所示										
<table><tr><td>T</td><td>0.29±0.04</td></tr><tr><td>T1</td><td>0.15±0.02</td></tr><tr><td>D1</td><td>23⁰_{-0.1}</td></tr><tr><td>D2</td><td>15±0.30</td></tr><tr><td>偏心距</td><td>≤0.64</td></tr></table>		T	0.29±0.04	T1	0.15±0.02	D1	23 ⁰ _{-0.1}	D2	15±0.30	偏心距	≤0.64	用户确认意见
		T	0.29±0.04									
T1	0.15±0.02											
D1	23 ⁰ _{-0.1}											
D2	15±0.30											
偏心距	≤0.64											
		签字(盖章) : 年 A 口										

施 窗 挡