


1. External Dimensions (Unit:mm)

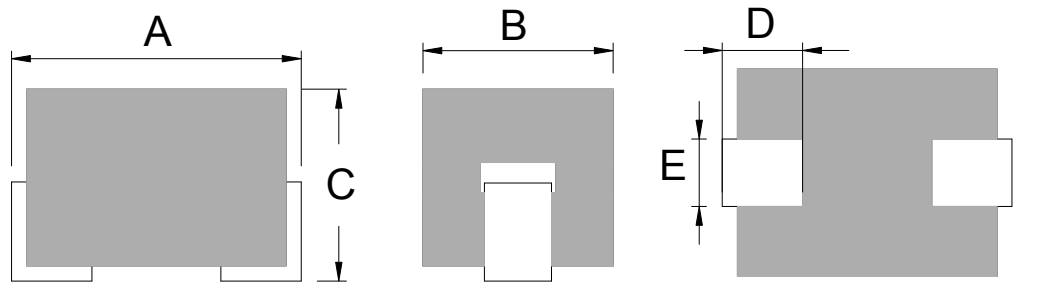

TYPE	A	B	C	D	E	Q'Ty/Reel
ABH403025	5.1Max	3.1±0.15	3.1Max	1.35±0.2	1.35±0.15	500

2. Part Number Code

ABH 403025 T 530
 A B C D

A: Series Name Ferrite Bead
 B: Dimensions(mm) 403025
 C: Tolerance T: ±25%
 D: Impedance 530=53Ω

3. Electrical Characteristics

Part Number	Impedance (Ω)		RDC	Rated Current(A)
	25MHz	100MHz	(mΩ)Max.	ΔT=40 °C TYP.
ABH403025T530	35.0±25%	53.0±25%	0.6	15.0