



A	B	C	D	E	F
			版次 0	变更摘要 新产品发行	日期 2020/12/08

技术指标:

- 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
- 温度范围: -25° C~85° C.
- 额定电压: 30V, AC/DC.
- 耐电压: 200V, AC/minute.
- 接触电阻: ≤0.02Ω.
- 绝缘电阻: ≥100MΩ.
- 额定电流: 0.5A AC/DC.

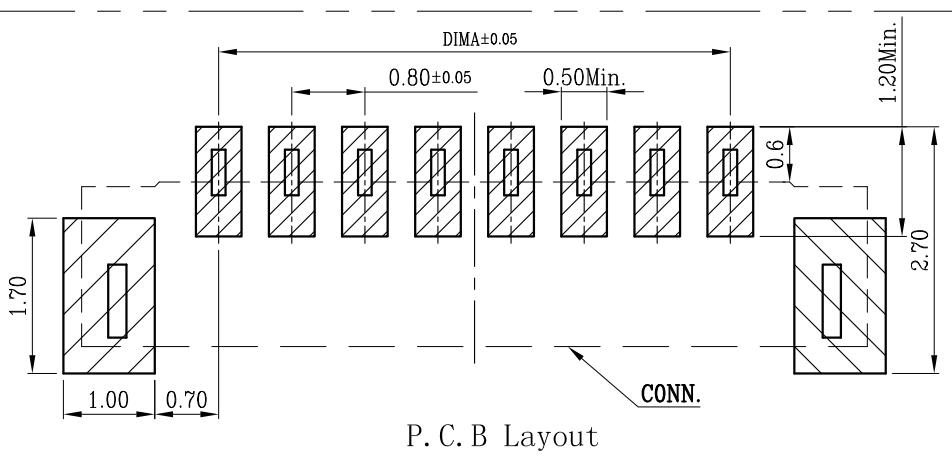

一般公差 (TOLERANCE)
 $X \pm .50$ $XX \pm .10$
 $X \pm .20$ $XXX \pm .05$
 ANGLES $\pm 1^\circ$

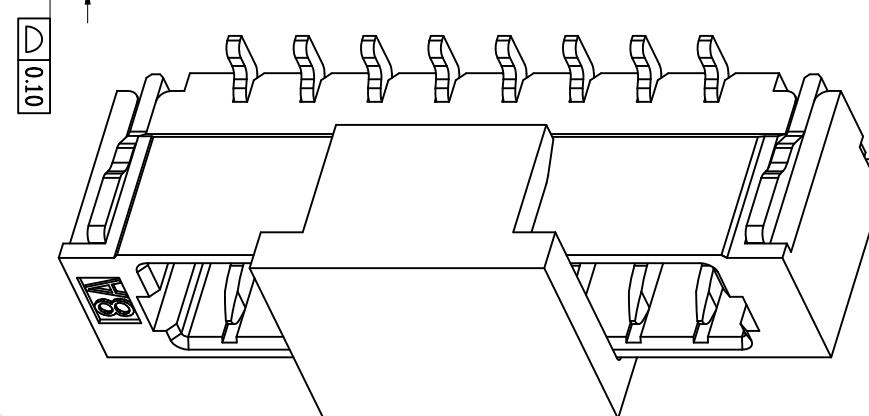

CKT	DIM A	DIM B	CKT	DIM A	DIM B
2	0.80	3.80	16	12.00	15.00
3	1.60	4.60	17	12.80	15.80
4	2.40	5.40	18	13.60	16.60
5	3.20	6.20	19	14.40	17.40
6	4.00	7.00	20	15.20	18.20
7	4.80	7.80	21	16.00	19.00
8	5.60	8.60	22	16.80	19.80
9	6.40	9.40	23	17.60	20.60
10	7.20	10.20	24	18.40	21.40
11	8.00	11.00	25	19.20	22.20
12	8.80	11.80	26	20.00	23.00
13	9.60	12.60	27	20.80	23.80
14	10.40	13.40	28	21.60	24.60
15	11.20	14.20			

韩下 HANXIA 深圳市韩下电子有限公司

品名 (TITLE)	制图 (DR)	黄彬
料号 (DWG.NO)	校对 (CHKD)	张伟
HX-0.8-4PLT	审核 (APPD)	罗小春
	张数 (SHEET)	SIZE REV
1 OF 1	mm	A4 A