

- ◆ RoHS Compliant
- ◆ IEEE802.3at compliant performance
- ◆ 720mA Current Capability
- ◆ Operating temperature: -40℃ to +85℃
- ◆ Storage temperature: -40℃ to +85℃




Electrical Specifications @25℃

Part No.	OCL	LK	DCR	Turns Ratio	HI-POT	CMRR
LK24116SN	100 KHz, 0.1V	100KHz, 0.2V	1.4Ω Max	1CT:1CT±5%	1500Vrms	1-200 MHz
	150 uH Min	0.5uH Max				-25 dB Min

Continue

Insertion Loss		Return Loss		Cross Talk	
1-100 MHz	100-200 MHz	1-40 MHz	40-200 MHz	1-100 MHz	100-200 MHz
-1.0 dB Max	-2.0 dB Max	-16 dB Min	-16+10*LOG(f/40) dB Min	-30 dB Min	-25 dB Min

MECHANICAL(Unit:mm)

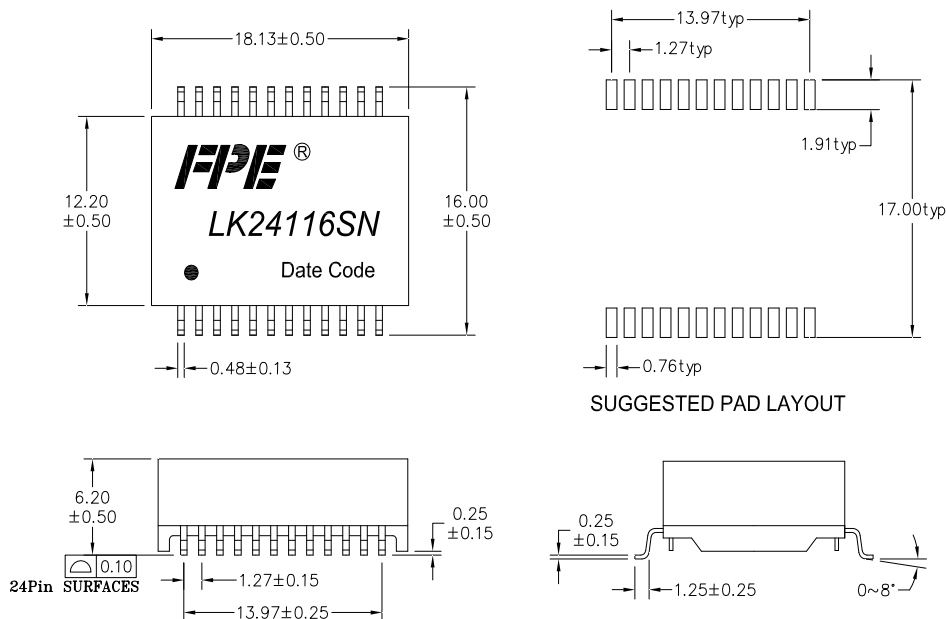

SCHEMATICS

