


承認書
SPECIFICATION FOR APPROVAL

NO: YF16053A

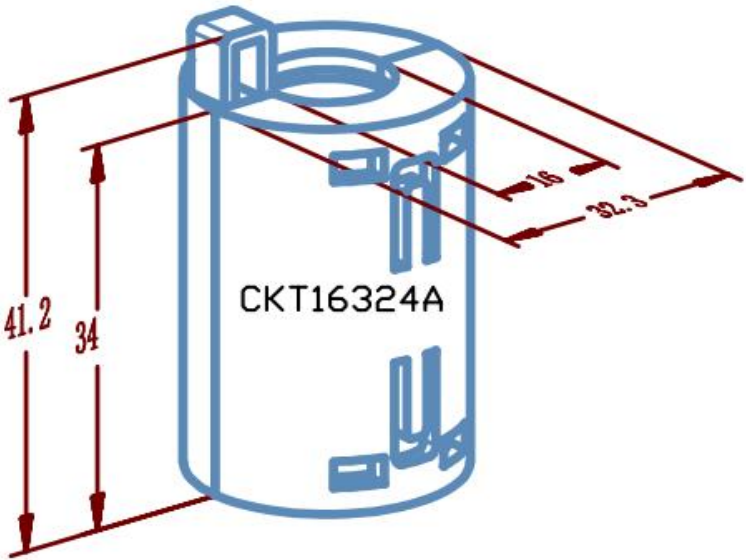


性能測試數據	
@25MHz	@100MHZ
95.0	165.0
97.9	166.0
97.9	166.8
97.8	166.5
94.9	162.0
98.3	163.3
101.3	168.2
95.7	163.7
97.3	165.2

DIMENSION 尺寸			MATERIAL 材料			TESTING CONDITION 測試條件	CUSTOMER 客戶
Measuring unit: mm			R10			測試儀器: E4991A	
OD	32.30	±0.5	1mhz-8 Ω (min)	初始磁導率	900	1-1000MHZ	
ID	16.00	±0.5	500mhz-800 Ω (max)	比損耗因子	≤16 (0.1mhz)	0.5x0.5TSx100L(mm)	
HT	41.20	± 0.8	1000mhz-230 Ω	飽和磁通密度	250(1600A/m)	DATE: 2025/4/1	

承 認 書
SPECIFICATION FOR APPROVAL

NO: YF16053A

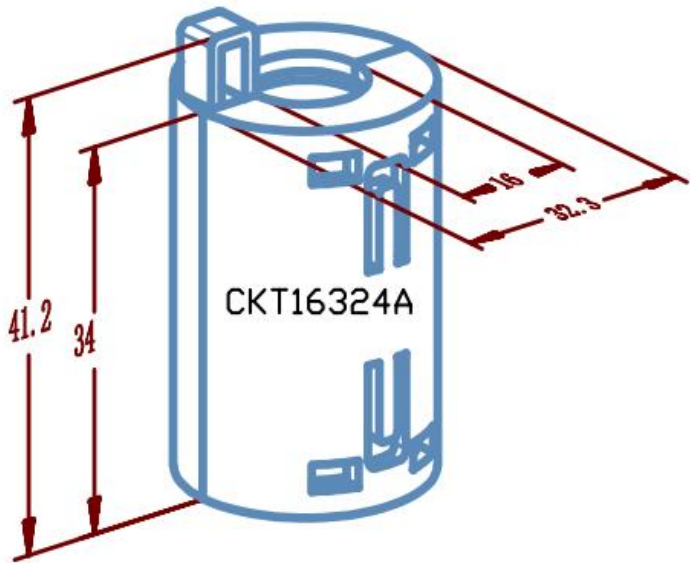

性能測試數據	
@25MHz	@100MHZ
95.0	165.0
97.9	166.0
97.9	166.8
97.8	166.5
94.9	162.0
98.3	163.3
101.3	168.2
95.7	163.7
97.3	165.2

DIMENSION 尺寸			MATERIAL 材料			TESTING CONDITION 測試條件	CUSTOMER 客戶	
Measuring unit: mm			R10			測試儀器: E4991A		
OD	32.30	±0.5	1mhz-8Ω (min)	初始磁導率	900	1-1000MHZ		
ID	16.00	±0.5	500mhz-800Ω (max)	比損耗因子	≤16 (0.1mhz)	0.5x0.5TSx100L(mm)		
HT	41.20	± 0.8	1000mhz-230Ω	飽和磁通密度	250(1600A/m)	DATE: 2025/4/1		