


承認書

SPECIFICATION FOR APPROVAL

NO: YF7151810A

PRODUCT MODEL

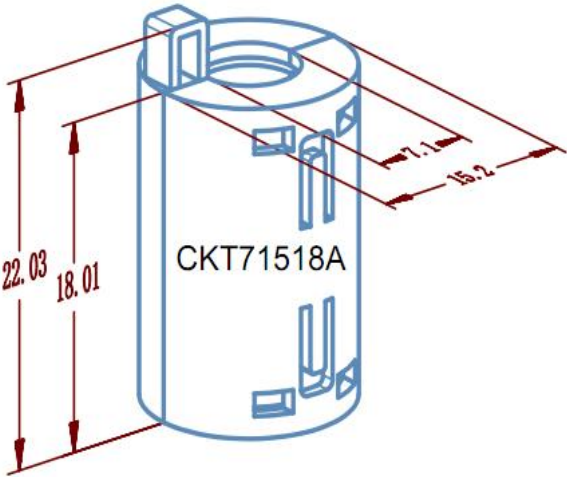

性能測試數據	
@25MHz	@100MHZ
45.6	115.2
47.0	115.9
47.0	116.5
46.9	116.2
45.6	113.1
47.2	114.0
48.6	117.4
45.9	114.3
46.7	115.3

DIMENSION			MATERIAL			TESTING CONDITION	CUSTOMER	
尺寸			材料			測試條件	客戶	
Measuring unit: mm			R10			測試儀器: E4991A		
OD	15.00	±0.5	1mhz-8 Ω	初始磁導率	980	1-500MHZ		
ID	7.00	±0.3	100mhz-100 Ω	比損耗因子	18 (0.1mhz)	0.5x0.5TSx100L(mm)		
HT	18.00	± 0.8	500mhz-650 Ω	飽和磁通密度	350(1600A/m)	DATE: 2025/4/1		