


承 認 書
SPECIFICATION FOR APPROVAL

NO: YF90053A

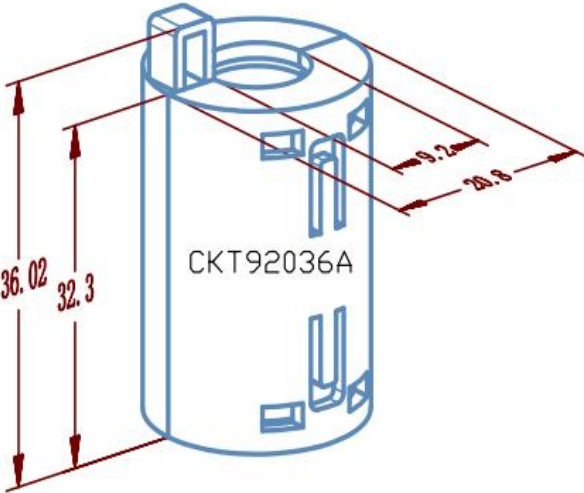

性能測試數據	
@25MHz	@100MHZ
81.2	190.2
83.6	191.3
83.7	192.3
83.6	191.9
81.1	186.8
84.1	188.3
86.6	193.8
81.8	188.6
83.2	190.4

DIMENSION			MATERIAL			TESTING CONDITION	CUSTOMER
尺寸			材料			測試條件	客戶
Measuring unit: mm			R10			測試儀器: E4991A	
OD	20.80	±0.5	1mhz-8 Ω (min)	初始磁導率	900	1-1000MHZ	
ID	9.20	±0.3	500mhz-320 Ω (max)	比損耗因子	≤16 (0.1mhz)	0.5x0.5TSx100L(mm)	
HT	36.02	± 0.8	1000mhz-210 Ω	飽和磁通密度	350(1600A/m)	DATE: 2025/4/1	