
 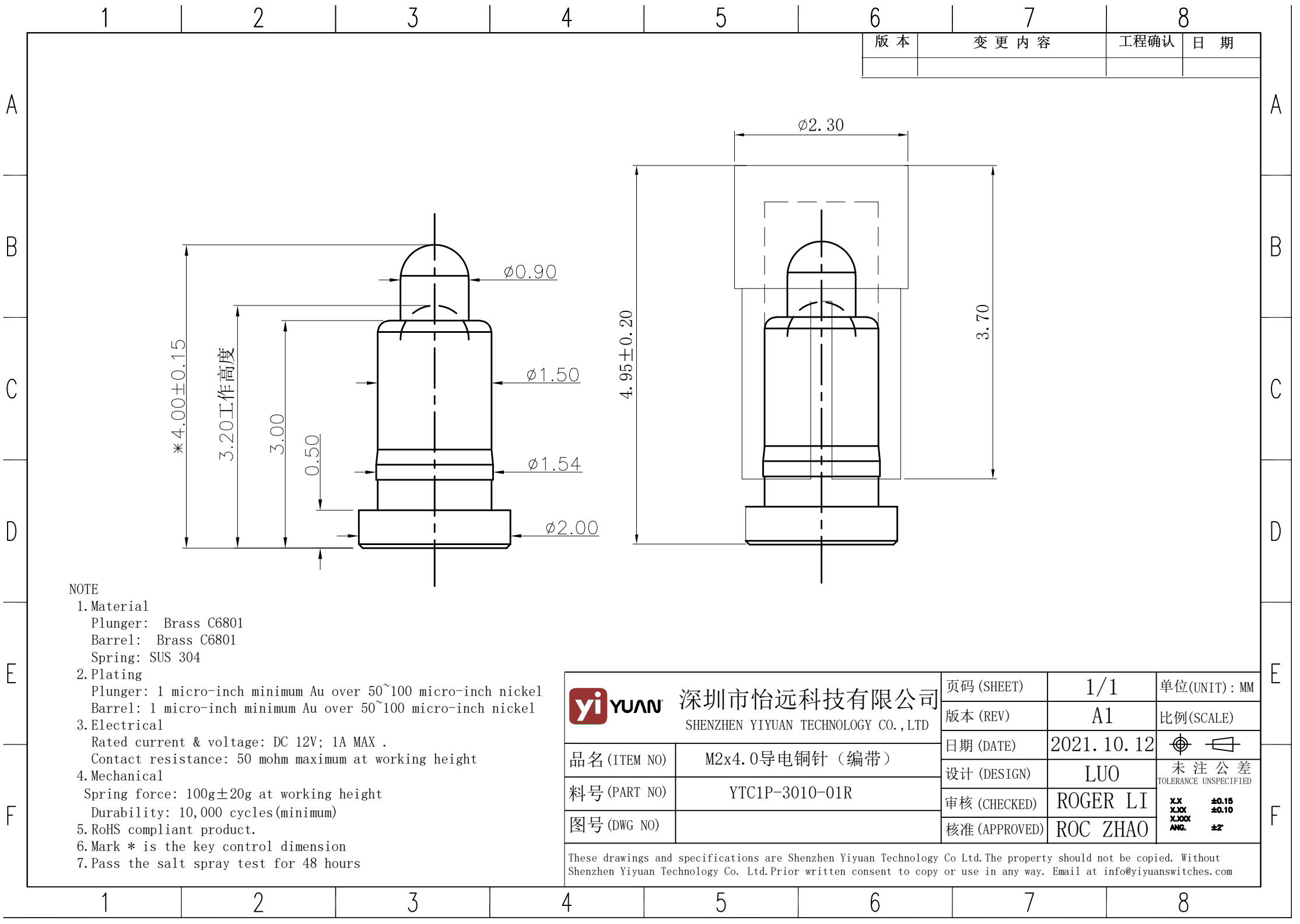




NOTE

1. Material
Plunger: Brass C6801
Barrel: Brass C6801
Spring: SUS 304
2. Plating
Plunger: 1 micro-inch minimum Au over 50~100 micro-inch nickel
Barrel: 1 micro-inch minimum Au over 50~100 micro-inch nickel
3. Electrical
Rated current & voltage: DC 12V; 1A MAX .
Contact resistance: 50 mohm maximum at working height
4. Mechanical
Spring force: 100g±20g at working height
Durability: 10,000 cycles(minimum)
5. RoHS compliant product.
6. Mark * is the key control dimension
7. Pass the salt spray test for 48 hours

yiYUAN 深圳市怡远科技有限公司 SHENZHEN YIYUAN TECHNOLOGY CO.,LTD		页码 (SHEET)	1/1	单位(UNIT): MM	
		版本 (REV)	A1	比例(SCALE)	
		日期 (DATE)	2021. 10. 12		
		设计 (DESIGN)	LUO	未注公差 TOLERANCE UNSPECIFIED	
		审核 (CHECKED)	ROGER LI	XX ±0.15 XXX ±0.10 ANG. ±2°	
品名 (ITEM NO)	M2x4.0导电铜针（编带）	核准 (APPROVED)	ROC ZHAO		
料号 (PART NO)	YTC1P-3010-01R				
图号 (DWG NO)					
These drawings and specifications are Shenzhen Yiyuan Technology Co Ltd.The property should not be copied. Without Shenzhen Yiyuan Technology Co. Ltd.Prior written consent to copy or use in any way. Email at info@yiyuanswitches.com					