

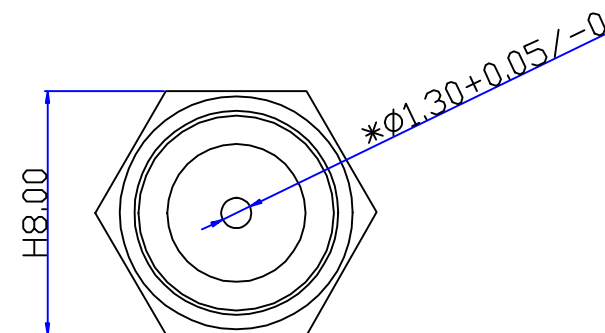
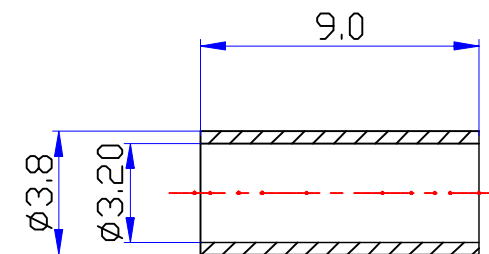


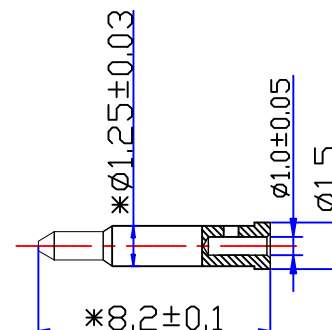

Product NO.

DOSIN-806-0020

REV	DESCRIPTION	DWN	DATE	APPROVEN
A	First issue	JIM	2010/02/03	John kine

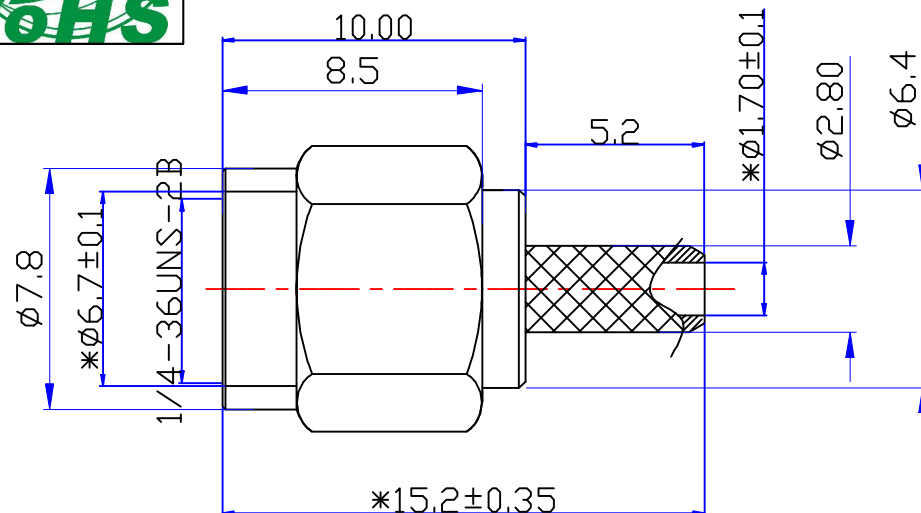

Specification.

VSWR:1.3MAX

Frequency range:DC~3G

Working Voltage:500V rms @ sea level

Insulation resistance:5000 Ohms min

Temperature range:-55℃ TO +155℃

Relative temperature:≤95%(40° C±2° C)

Drawings products are in line with ROHS standards.

1	BODY	Brass	GOLD 2U"	1
2	CONTACT	Brass	GOLD 3U"	1
3	Insulator	POM		1
4	Casing	Brass	Nickel 50U"	1
5				
6				
7				
8				
9				
10				
NO	Component Number	Material	Finish	QTY

NOTE:

DRAWN
Zelin. Zhang

2012/04/
10

CHECKED

 
APPROVALS
John

12/04.2012

Tolerance

0-6 ±0.2
6-30 ±0.3
30-120 ±0.5
Angular ±2°

View



UNIT

MM

SCALE

1:1



Dosin Industrial(H.K)Co.,Ltd

东莞市德索五金电子制品有限公司

Dosin Hardware Electronics Co.,Ltd

E-mail:dosin2005@163.com

dosin2005@dosiin-china.com

Web:http://www.china-guan.com

TEL: (0086) 769-61153906

FAX: (0086) 769-61675836

Name:

SMA MALE FOR RG179CABLE CONNECTOR

SIZE

Product NO.

DOSIN-806-0020

DateTime

2012/04/10

CAD FILE

D/company drawings/BD

SHEET 1 OF 1