
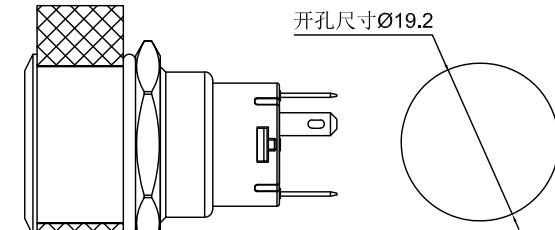
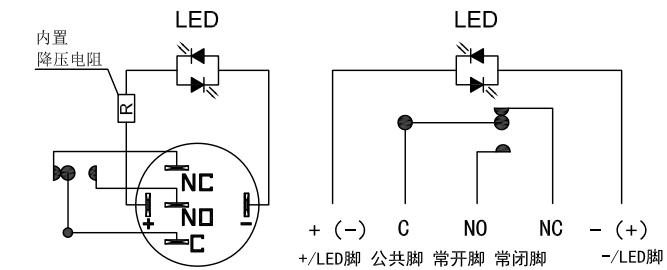
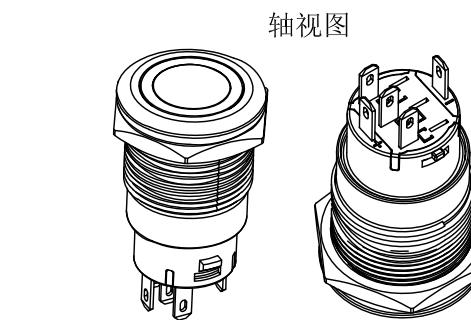


- HAOYU -

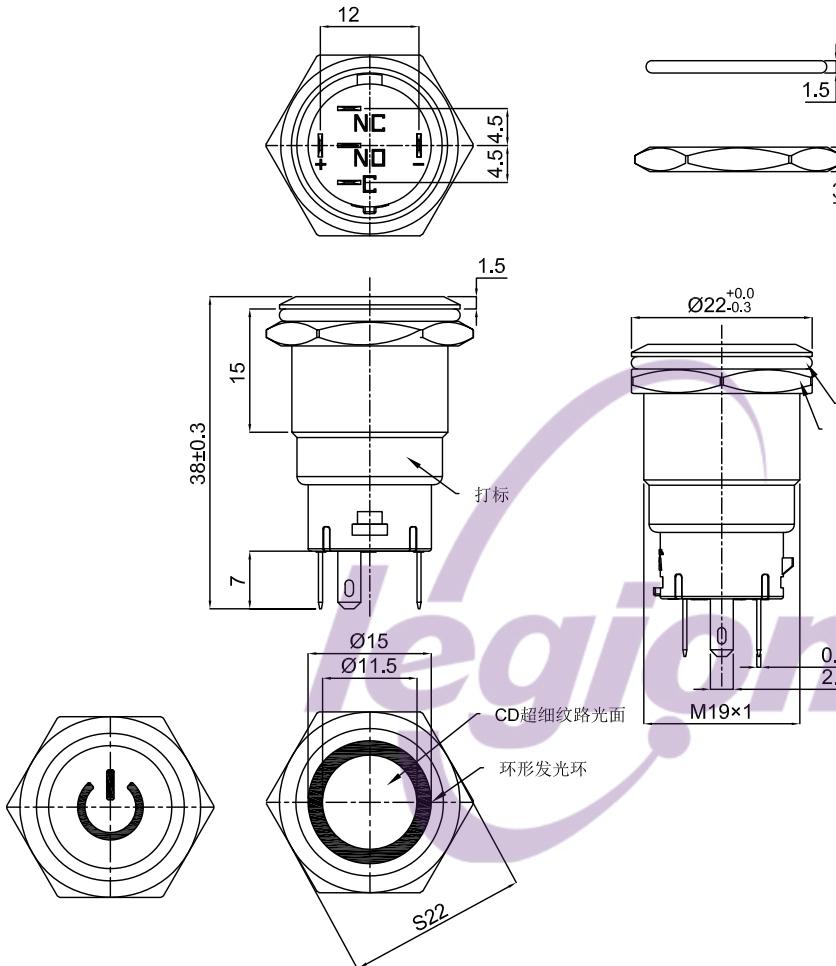

- 1.Rating : DC36V 3A.
- 2.Contact resistance: $\leq 50\text{m}\Omega$.
- 3.Insulation resistance: $\geq 1000\text{M}\Omega$ (DC500V).
- 4.Withstanding voltage: 2000VAC .
- 5.Operating Force: $\geq 4\text{N}$
- 6.按压行程: 自锁3mm/复位2.5±0.1mm
- 7.life test: 50000 cycles.LED灯寿命: 40000h,
- 8.Operation temperature range:-25°C ~85°C.
- 9.Sign"^{*}" is importance dimension.

发光类型:E环形/DY电源符号/D单点状/E+DY环形+电源符号/E+D环形+单点状

发光颜色: R红/G绿/L蓝/Y黄/W白/Q橙/P紫

额定电压: AC/DC:3V/6V/12V/24V/36V/48V/AC:60V/110V/220V

TEL: 0769-82310511-867

10	发光区域	PC		
9	C/NO/NC TERMINAL	BRASS	1	Ag-PLATED
8	LED TERMINAL	BRASS	2	Ag-PLATED
7	CONTACT	SILVER ALLOY	3	Ag-PLATED
6	C/NO/NC BASE	PA46	1	
5	LED BASE	PC	1	
4	NUT	BRASS	1	Ni-PLATED
3	WASHER	RUBBER	1	WHITE
2	COVER	SUS/BRASS	1	BRASS:Ni-PLATED
1	BUTTON	SUS	1	
NO.	PART NAME	MATERIAL	QTY	FINISHING

东莞市六钧电子五金有限公司

PRO.AGL: REV :AC