
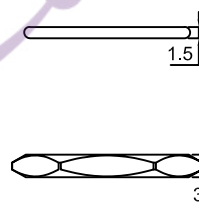
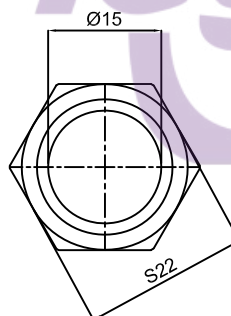
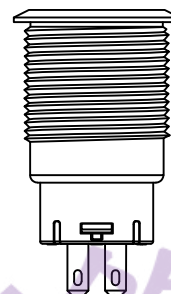
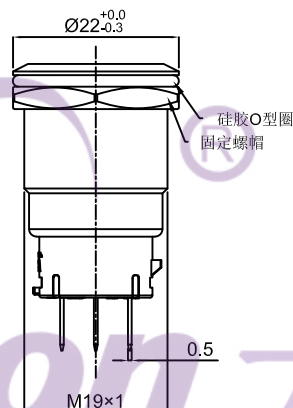


发热电流: U_i : AC250V, I_{th} : 5A;
额定电流: 3A/DC36V;
工作环境温度: $-20^{\circ}\text{C} \sim +55^{\circ}\text{C}$;
按压行程: 自锁3mm、自复2.5mm ± 0.1 ;
接触行程: 1.5mm ± 0.1 ;
按压扭力: $\leq 6\text{N}$;
NO脚反推扭力: $\leq 30\text{N}$;
螺帽装配力矩: 5-14N.m;
防护等级: IP67;
防暴等级: IK10;
接触电阻: $\leq 50\text{m}\Omega$;
绝缘电阻: $\geq 1000\text{M}\Omega$;
电气寿命: 50000次以上;
机械寿命: 500000次以上;
工频耐压: 2000V/1min;


按键: 不锈钢/铝合金氧化;
外壳: 不锈钢/黄铜镀镍、铬/铝合金氧化;
O型圈: 硅胶;
固定螺帽: 黄铜镀镍;
LED底座: PC;
C/NO/NC底座: 尼龙PA46;
接触材料: 银合金;
C/NO/NC引脚: H62电镀金;

Tel: 0769-82310511-867


- 1: 线材焊接的温度及时长: $320^{\circ}\text{C} \pm 20^{\circ}\text{C}$, 时长3秒以下;
2: 可配专用接插件使用;
2.1: 1NO1NC开关功能线材: 绿线C、蓝线NO、黄线NC;
2.2: 2NO2NC开关功能线材: 绿黑线C、蓝黑线NO、黄白线NC;

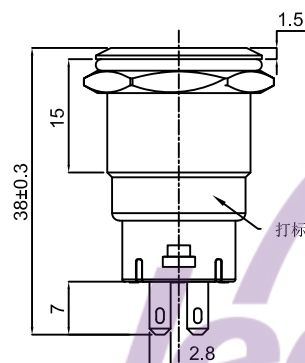

轴视图

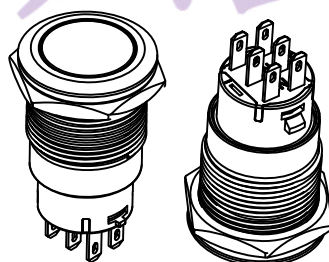

安装视图

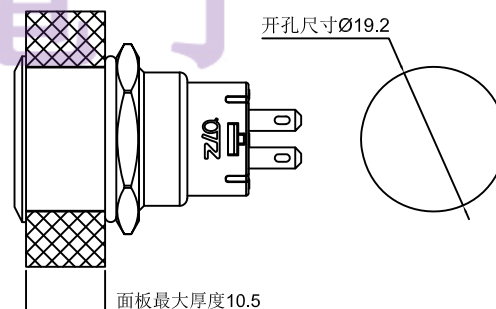

8	C/NO/NC CONTACT FOOT	BRASS	6	Ag-PLATED	TOLERANCE UNLESS SPECIFIED									
7	CONTACT	SILVER ALLOY	3											
6	C/NO/NC HOUSING	PA46	1		<1.5: $\pm 0.1\text{mm}$ >1.5~5.0: $\pm 0.25\text{mm}$ >5.0: $\pm 0.3\text{mm}$	ANGULAR $\pm 1^{\circ}$								
5	LED HOUSING	PC	1				NO	DATE	REVISIONS			BY	APPD	
4	NUT	BRASS	1	Ni-PLATED	TITLE: PUSH SWITCH				UNIT : MM	ROHS COMPLIANT	DWN			
3	O-RING	SILICA GEL	1	WHITE	MODEL : HY-19A-P22-S-CU-008				SCALE: 1:1	CHK'D				
2	CASE	SUS/BRASS	1	Ni-PLATED	东莞市六钧电子五金有限公司				APPD					
1	BUTTON	SUS	1											
NO.	PART	NAME	MATERIAL	QTY	FINISHING					PRO.AGL:		REV :A0		