




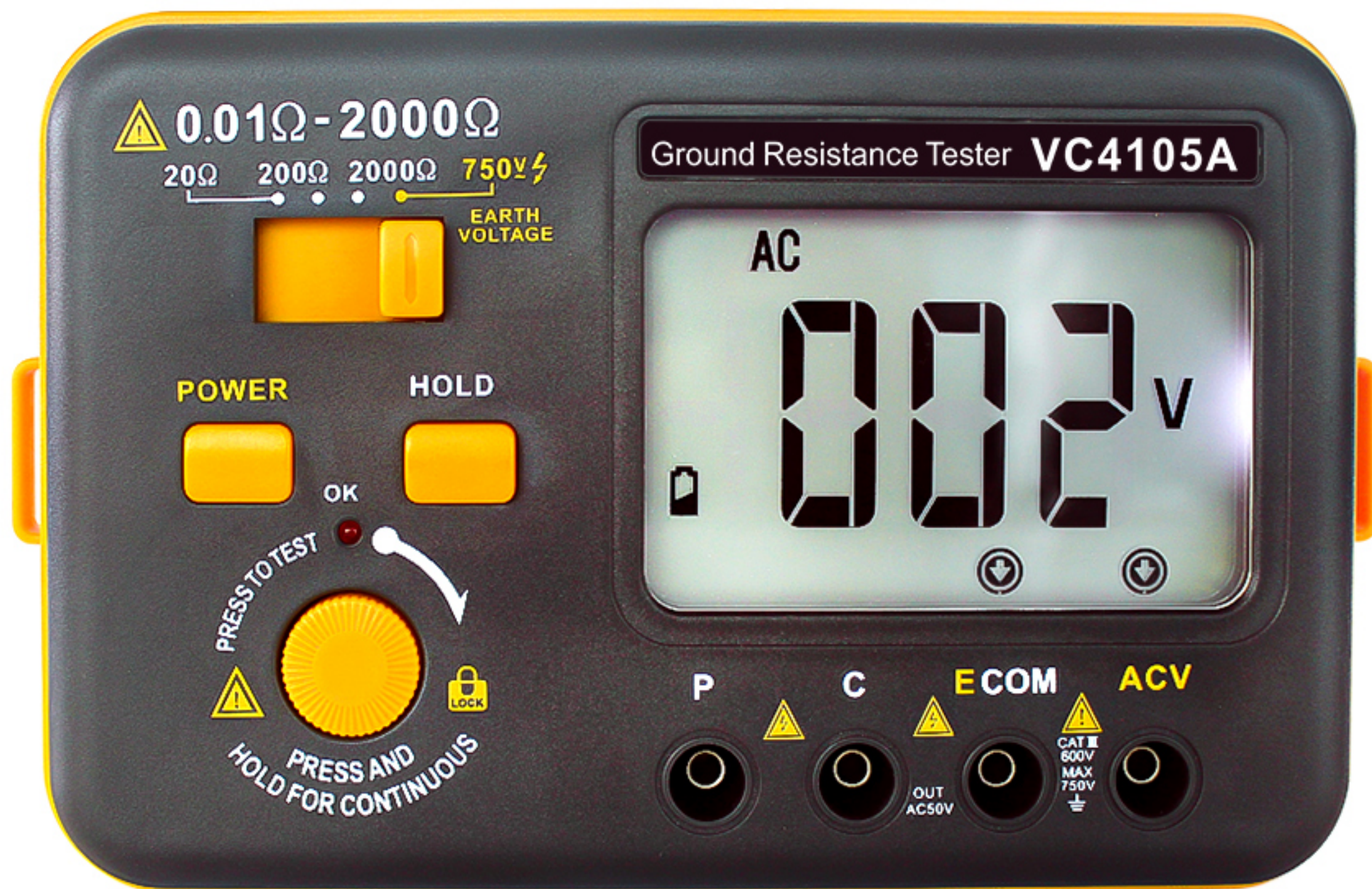


## PROTECTION COVER

Protect the screen  
from scratches

185mm/7.28inch


65mm/2.56inch

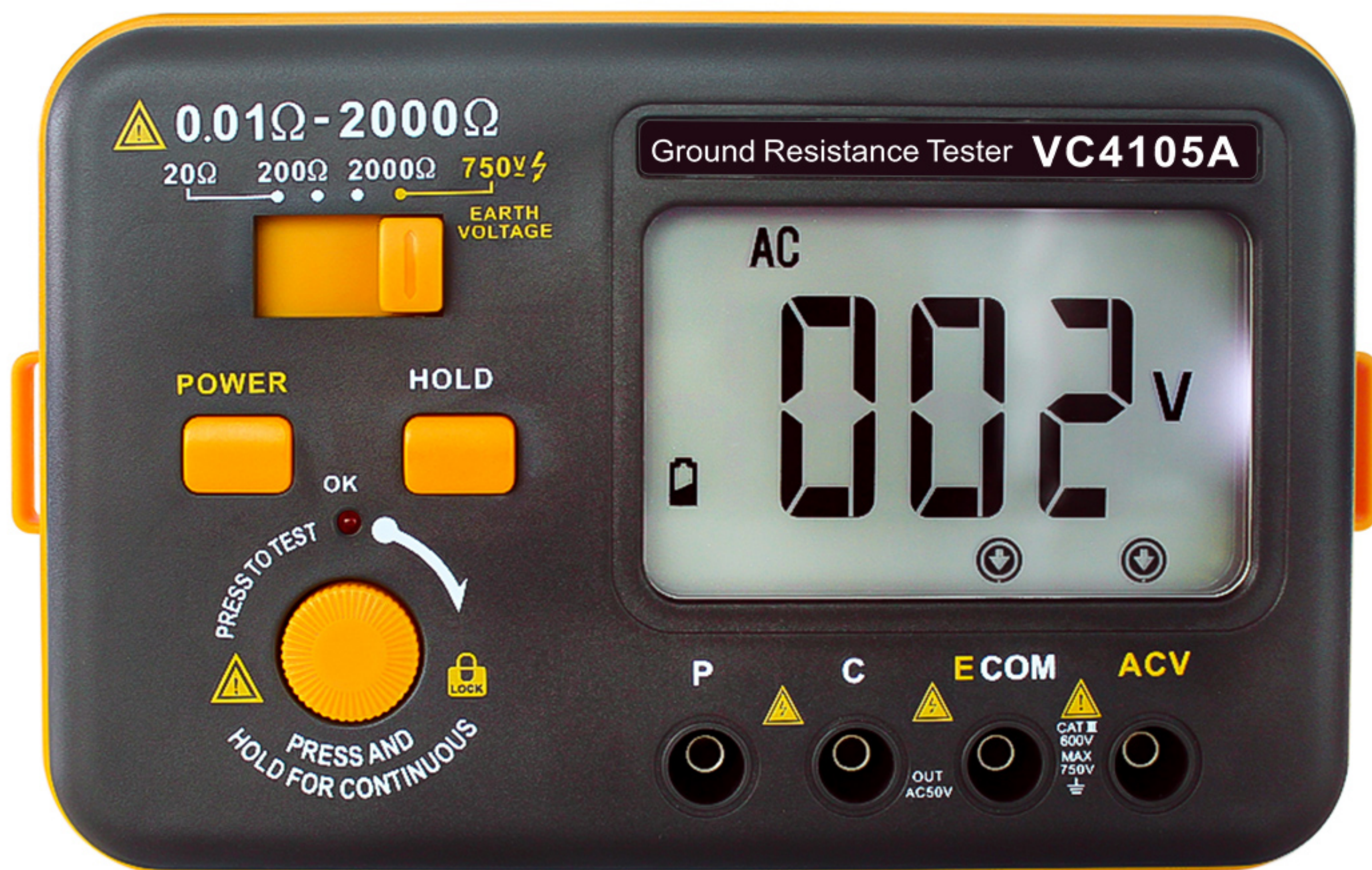

115mm/4.53inch

- |                      |                  |               |
|----------------------|------------------|---------------|
| ① Resistance         | ② AC voltage     | ③ HD screen   |
| ④ Power button       | ⑤ Test knob      | ⑥ HOLD button |
| ⑦ Potential sampling | ⑧ Current output | ⑨ COM jack    |
| ⑩ Voltage input      |                  |               |



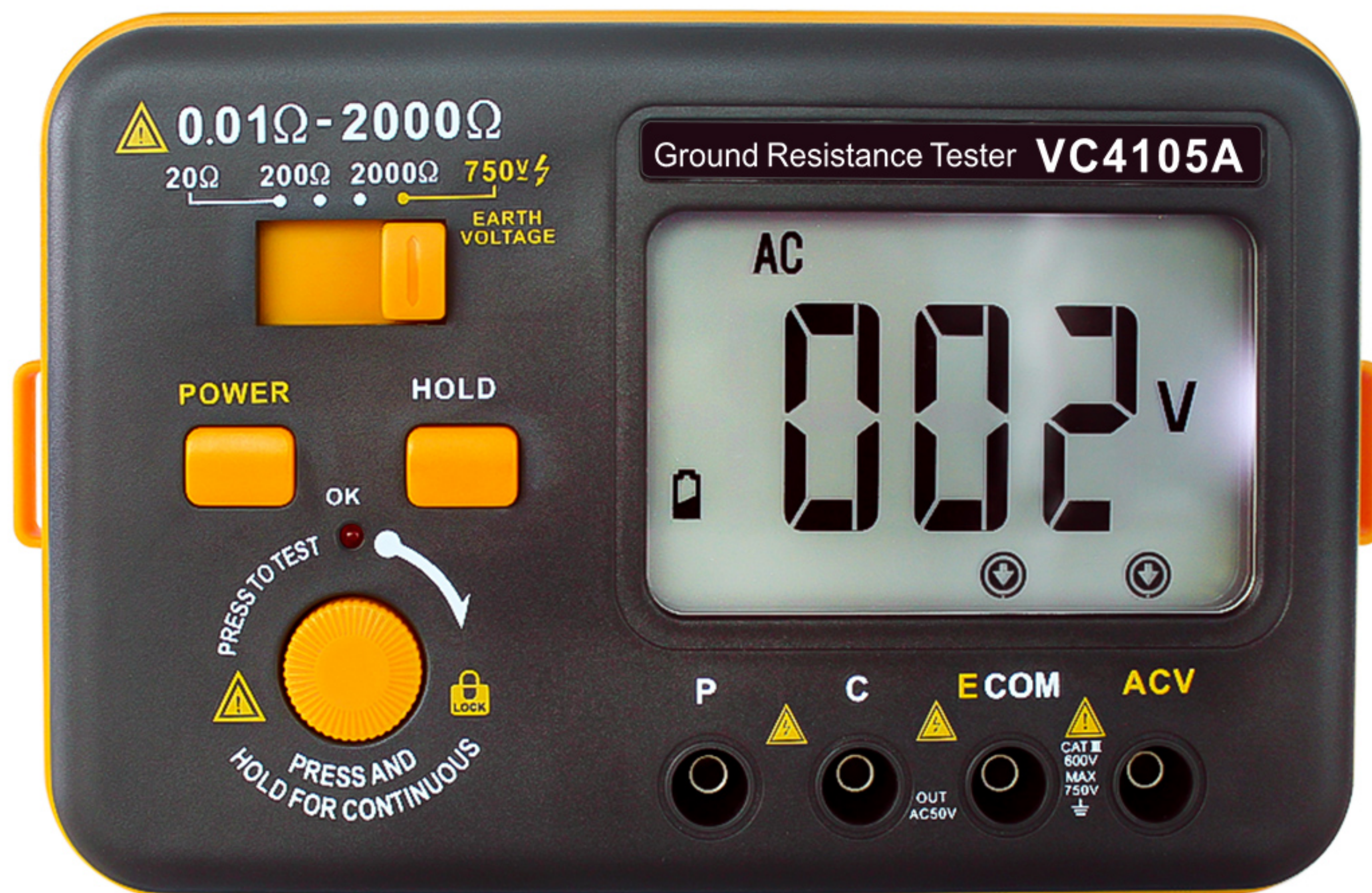

## RESISTANCE METER





Measure the grounding resistance of each electrical device

- ◆ LCD display, max. reading: 1999
- ◆ It can be used to measure the grounding voltage
- ◆ Compact size, portable and easy to use
- ◆ Dust-proof and moisture-proof structure, suitable for field use
- ◆ 8 AA batteries, durable
- ◆ It can be used to measure the grounding resistance of lightning equipment


|                       |                                                                                     |                    |                    |
|-----------------------|-------------------------------------------------------------------------------------|--------------------|--------------------|
| Display               | LCD, max. reading: 1999                                                             | Display size       | 78mm x 50mm        |
| Battery               | AA battery x 8                                                                      | No-load power      | ≤800mw             |
| Operation environment | 0°C~+40°C;<80%RH                                                                    | Storage conditions | -10°C~+50°C;<85%RH |
| AC voltage            | 750V                                                                                | Resistance         | 20Ω/200Ω/2000Ω     |
| Size & weight         | 185mm x 115mm x 65mm About 680g<br>(including battery, excluding other accessories) |                    |                    |

## PACKAGE LIST:

- 1\* VC4105A earth resistance tester
- 1\* Carrying bag
- 1\* User manual
- 2\* Auxiliary ground nails
- 2\* Auxiliary test leads with clip (red+green)
- 3\* Standard test leads (5M green+10M yellow+15M red)

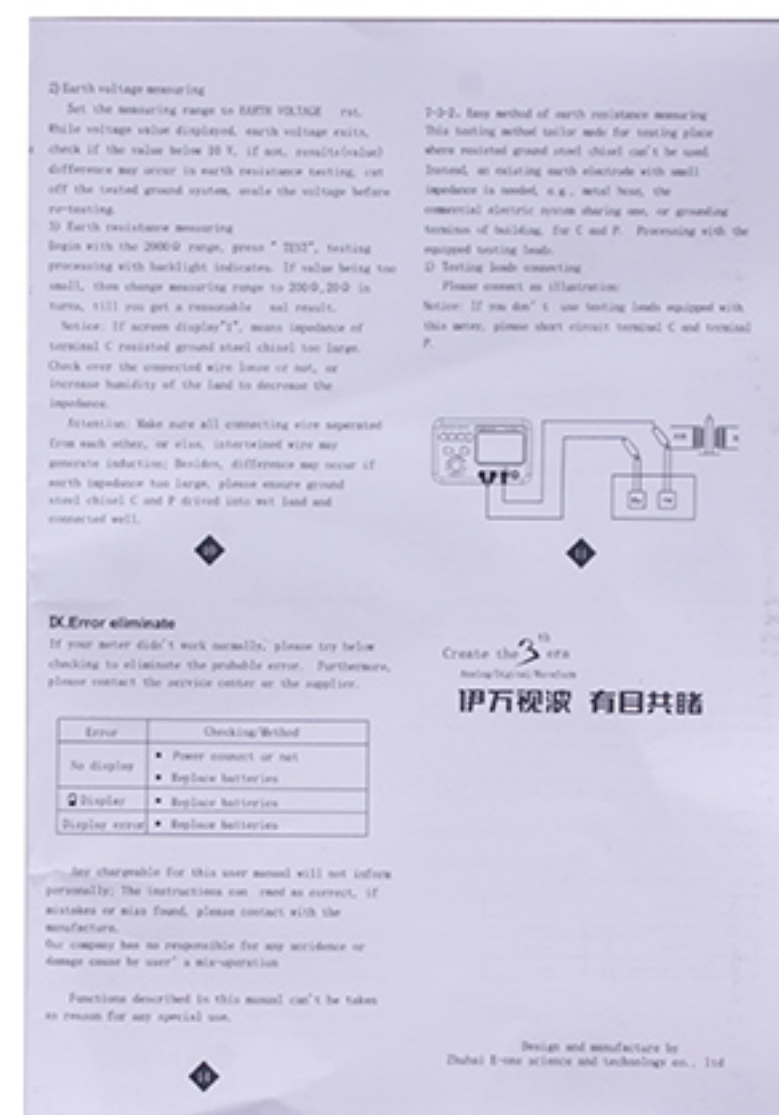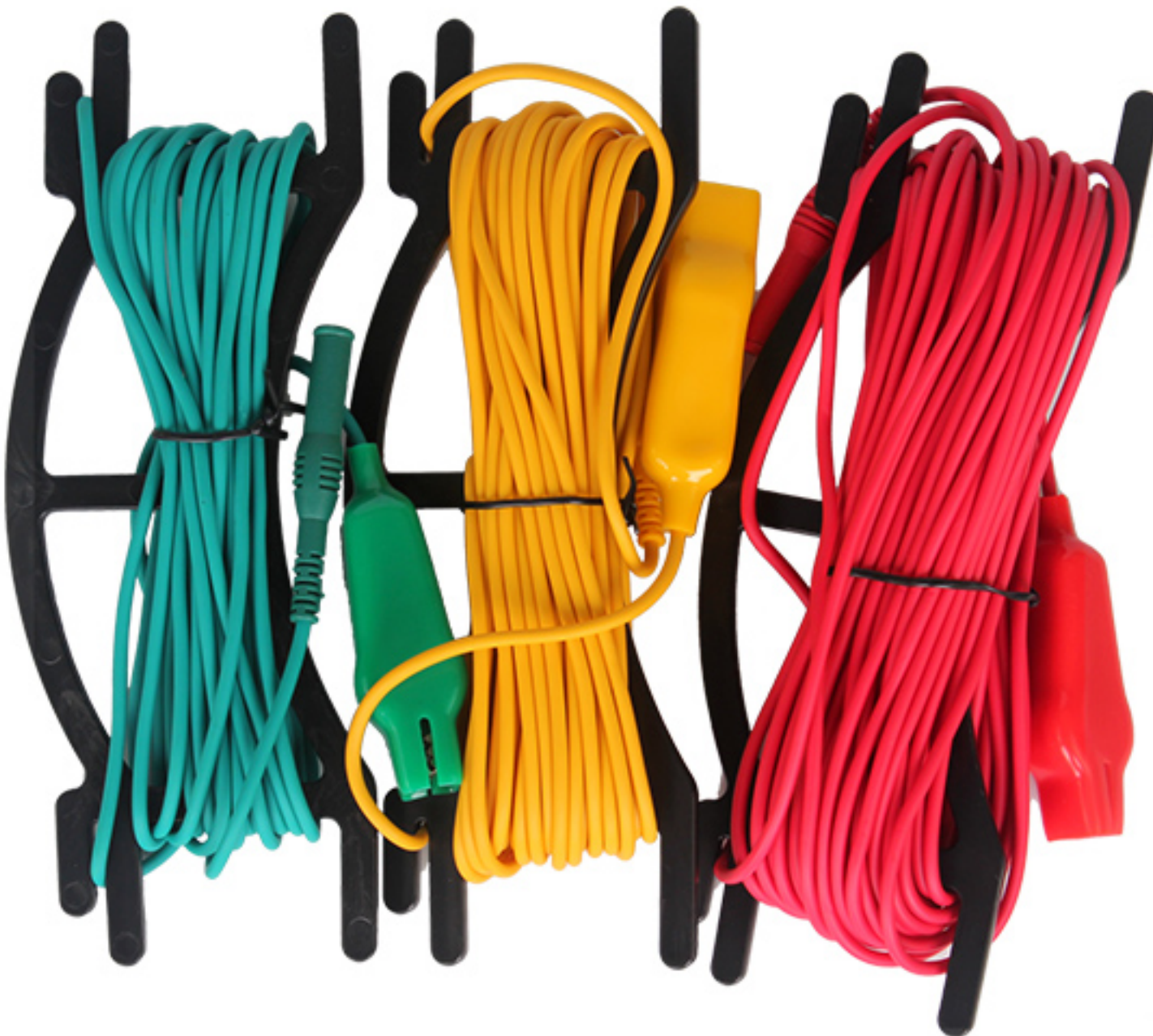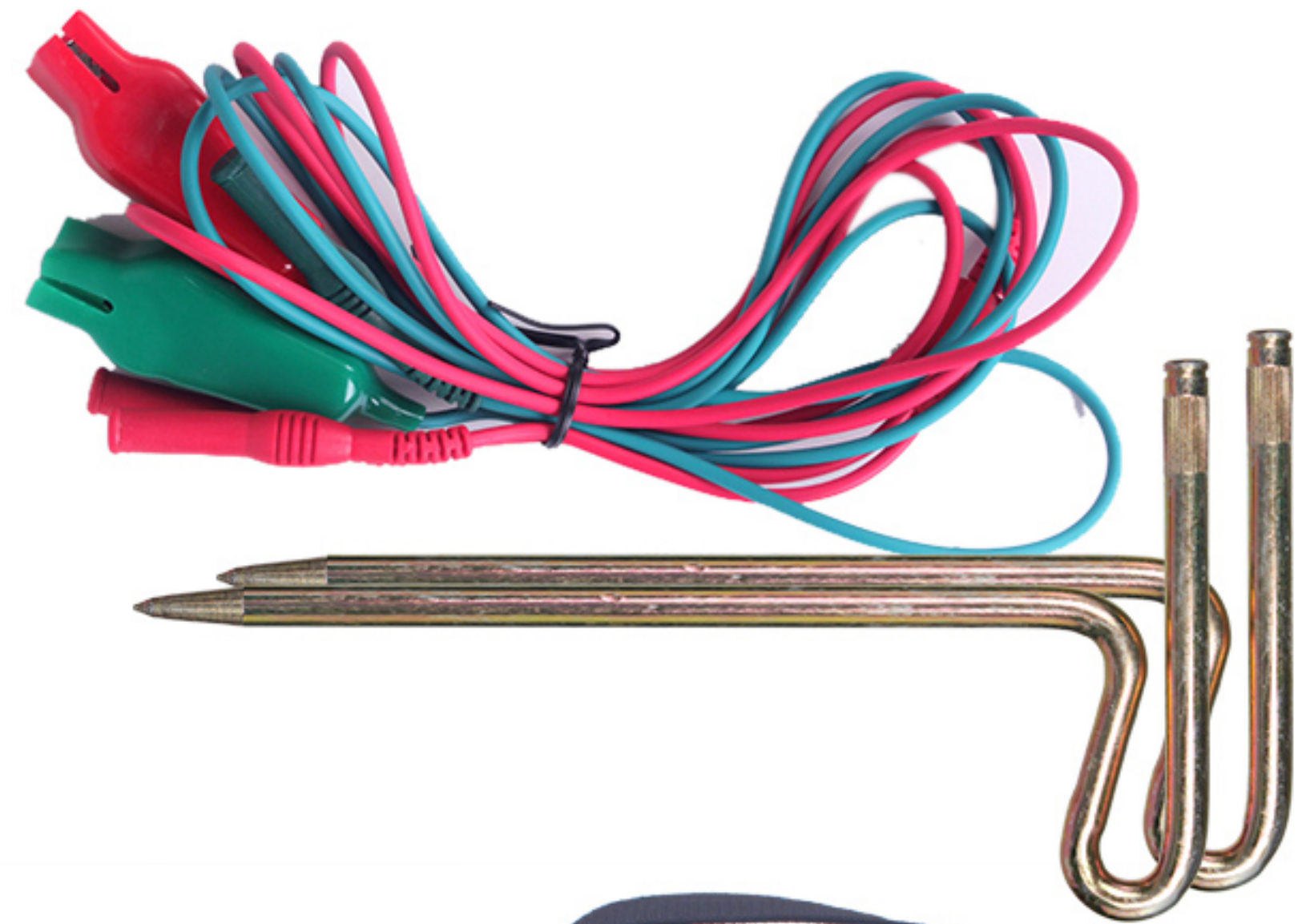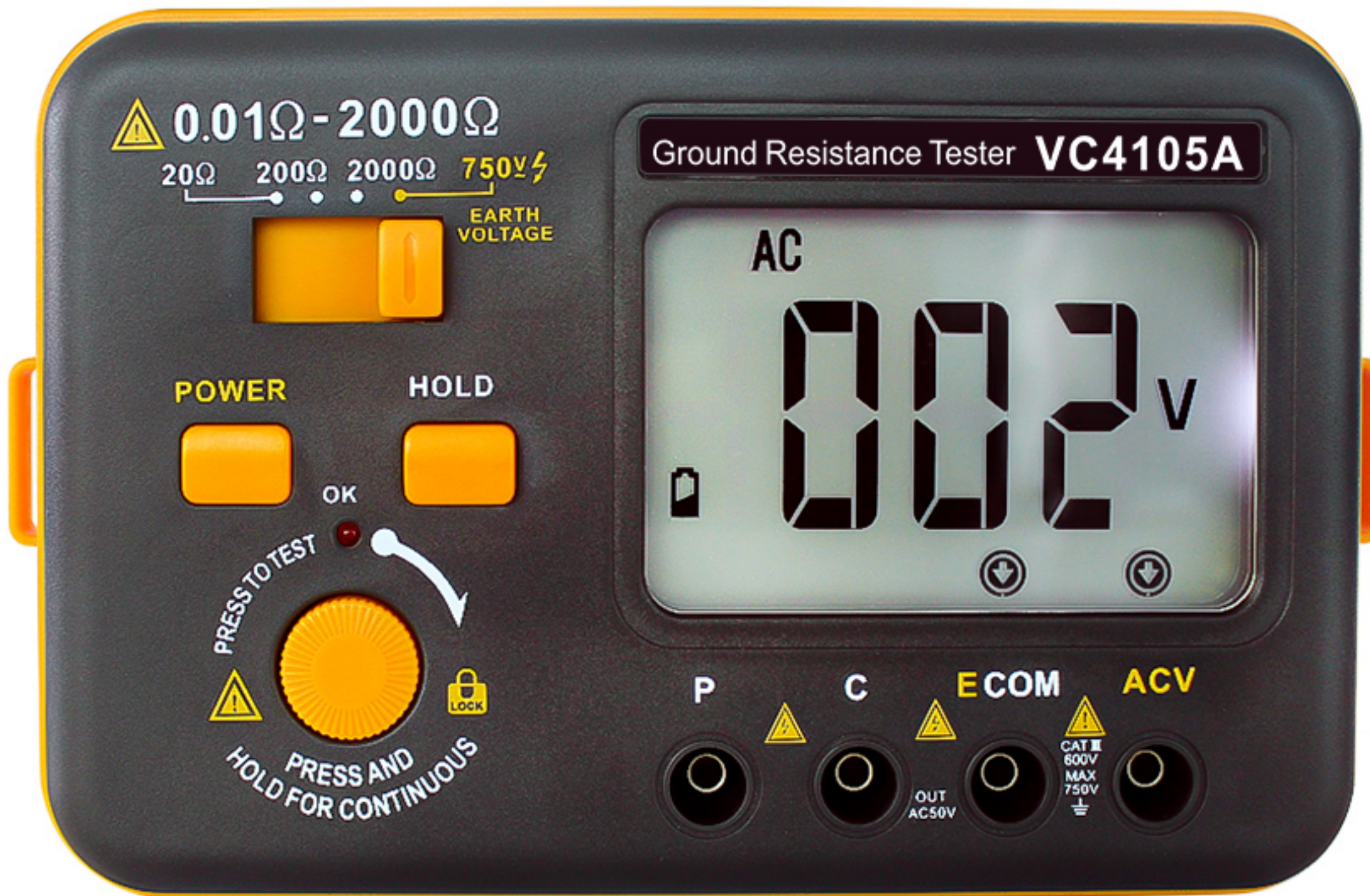


DUST-PROOF

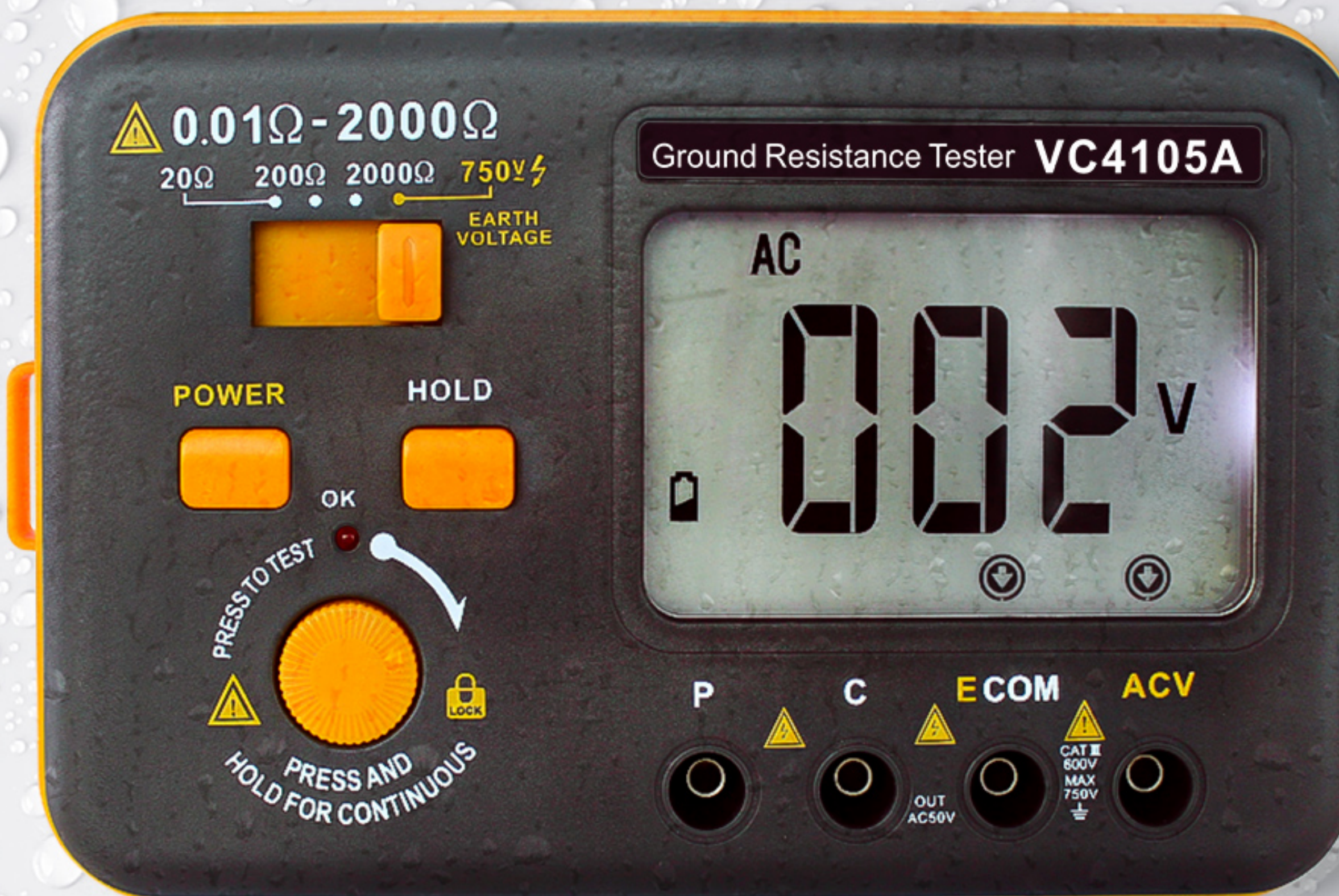

MOISTURE PROOF

# SHOW DETAILS

Easy to operate and high measurement efficiency

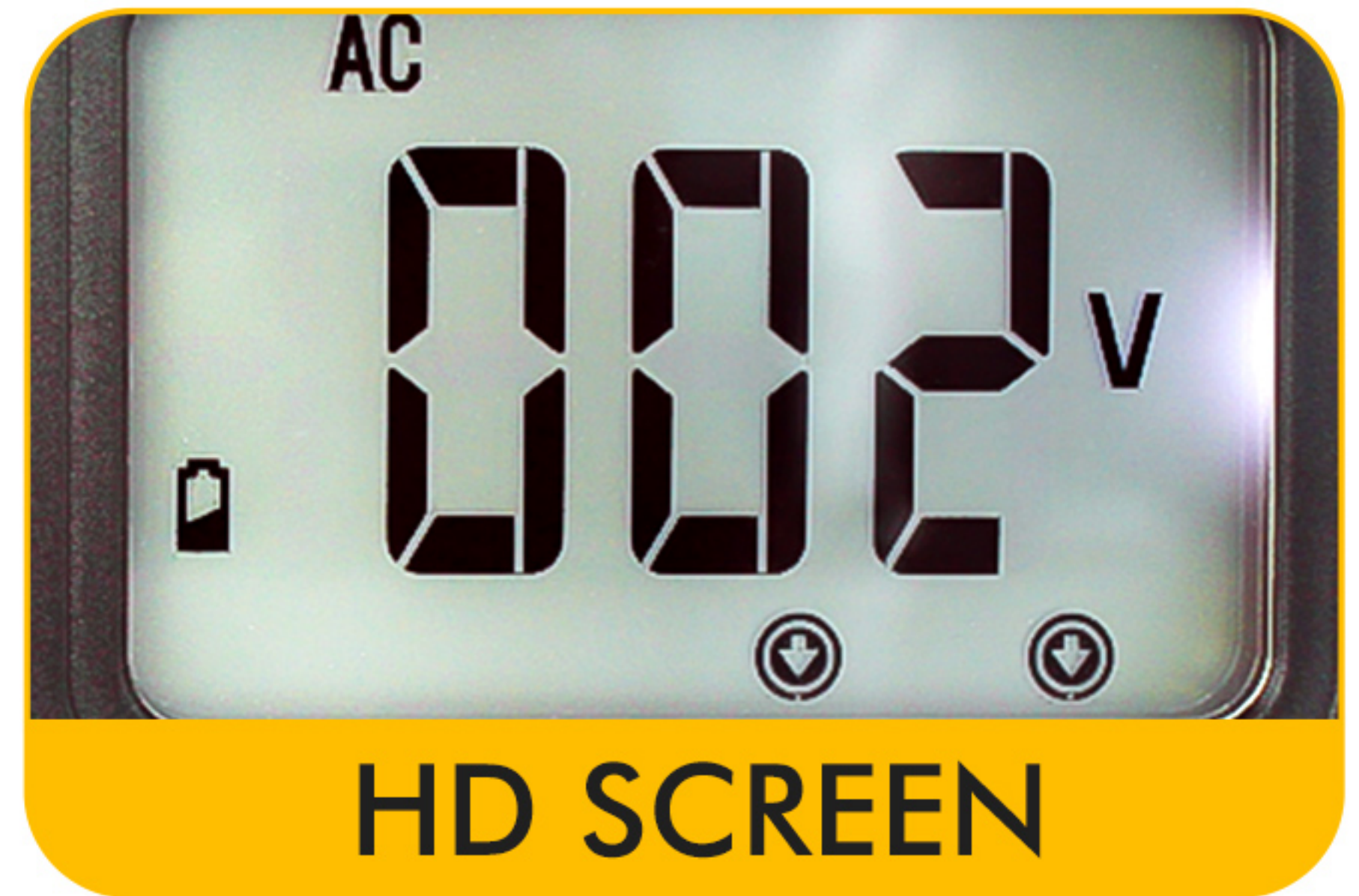

# MEASURING

## Earth resistance measuring



## Earth voltage measuring



# TEST LINE

A clip to wrap, easy to storage and use

Red:15M

Yellow:10M

Green:5M



# CARRYING BAG



# VC4105A

## Ground Resistance Tester

Grounding resistance: **20 $\Omega$ /200 $\Omega$ /2000 $\Omega$**

AC voltage: **750V**



"1"

Overload  
display



Circuit  
protection

V~

Grounding  
voltage



Backlight  
function

$\Omega$

grounding  
resistance



Key Lock

H

Data  
retention



High voltage  
display

SKYCEEN  VC4105A

# Ground Resistance Tester

Grounding resistance: **20 $\Omega$ /200 $\Omega$ /2000 $\Omega$**

AC voltage: **750V**



"1"

Overload  
display



Circuit  
protection

V~

Grounding  
voltage



Backlight  
function

$\Omega$

grounding  
resistance



Key Lock

H

Data  
retention



High voltage  
display

**Protection cover**



185mm/7.28inch

115mm/4.53inch



65mm/2.56inch



**Max.reading: 1999**



**One-button operation**



**resistance: 20Ω/200Ω/2000Ω  
voltage: 750V**



**Carrying bag**

# Measurement

