


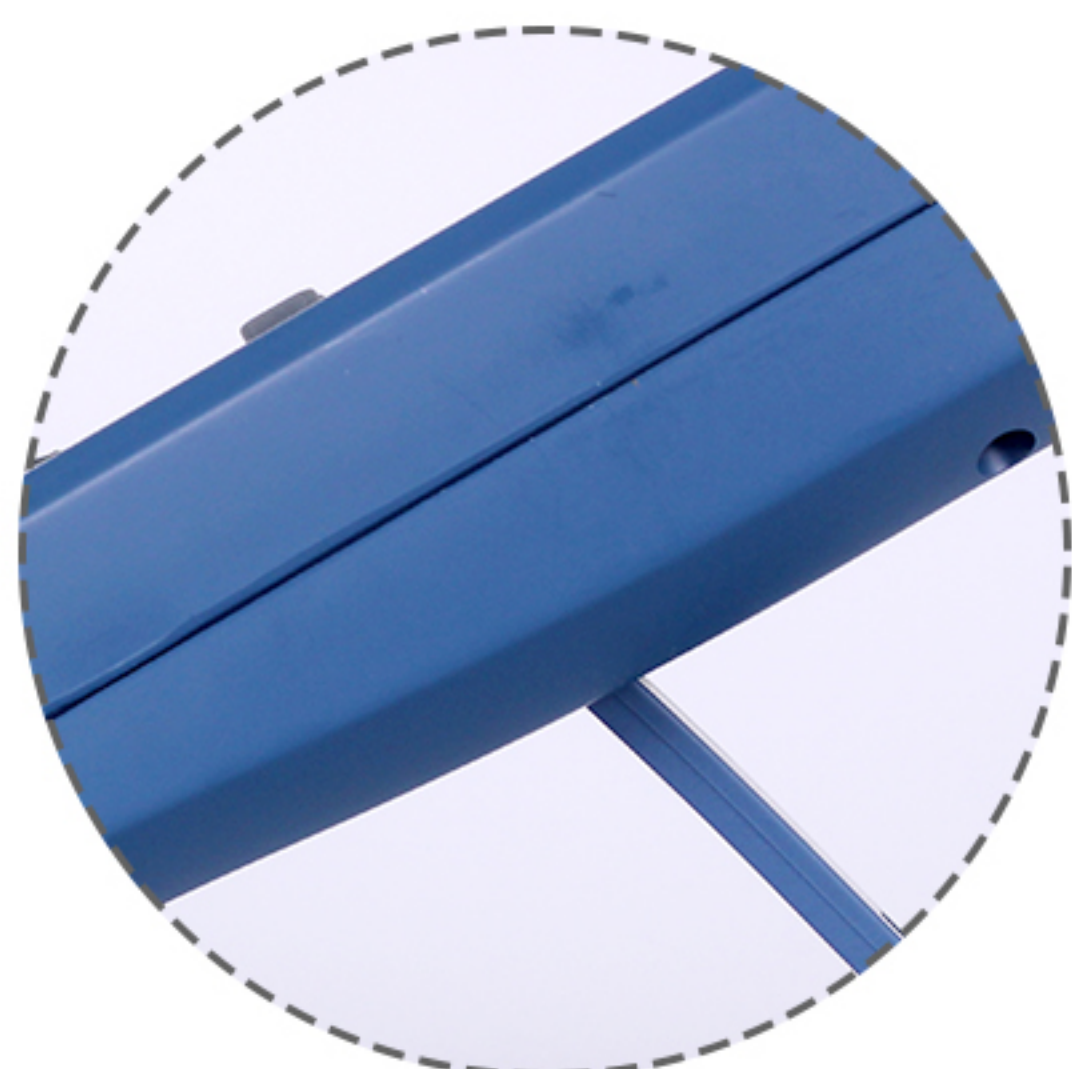






DC VOLTAGE MEASUREMENT



MEASURING RANGE
400mV~1000V

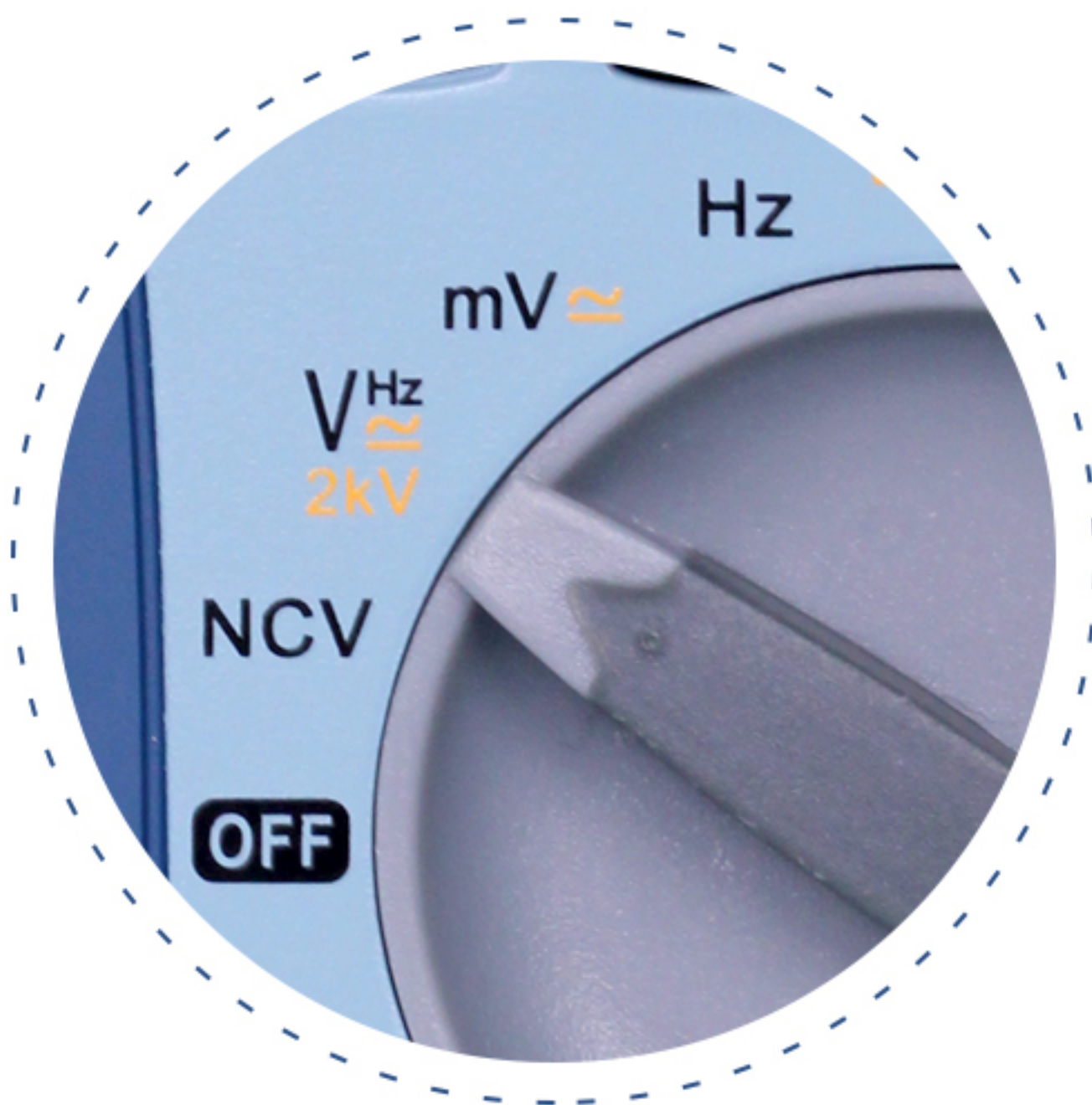





Features	Range	Resolution	Uncertainty
AC Voltage	4V~750V	1.0mV	± (2.0%+5d)
DC Voltage	400mV~1000V	0.1mV	± (1.0%+5d)
mV Voltage	40mV~400mV	0.01mV	± (1.0%+5d)
2kV AC Voltage	500V~2000V	1V	± (5.0%+10d)
2kV DC Voltage	500V~2000V	1V	± (3.0%+5d)
AC/DC Current	400μA/4000μA	0.1μA	± (1.25%+5d)
AC/DC Current	40mA/200mA	10μA	± (1.25%+5d)
Resistance	400Ω~40MΩ	0.1Ω	± (1.0%+5d)
Capacitance	4nF~4mF	1pF	± (4.0%+15d)
Temperature	-20°C~250°C	1°C	± (2.0%+3d)

Product and accessories display

VC92、Table pen、Battery
Canvas bag、Manual and certificate

