


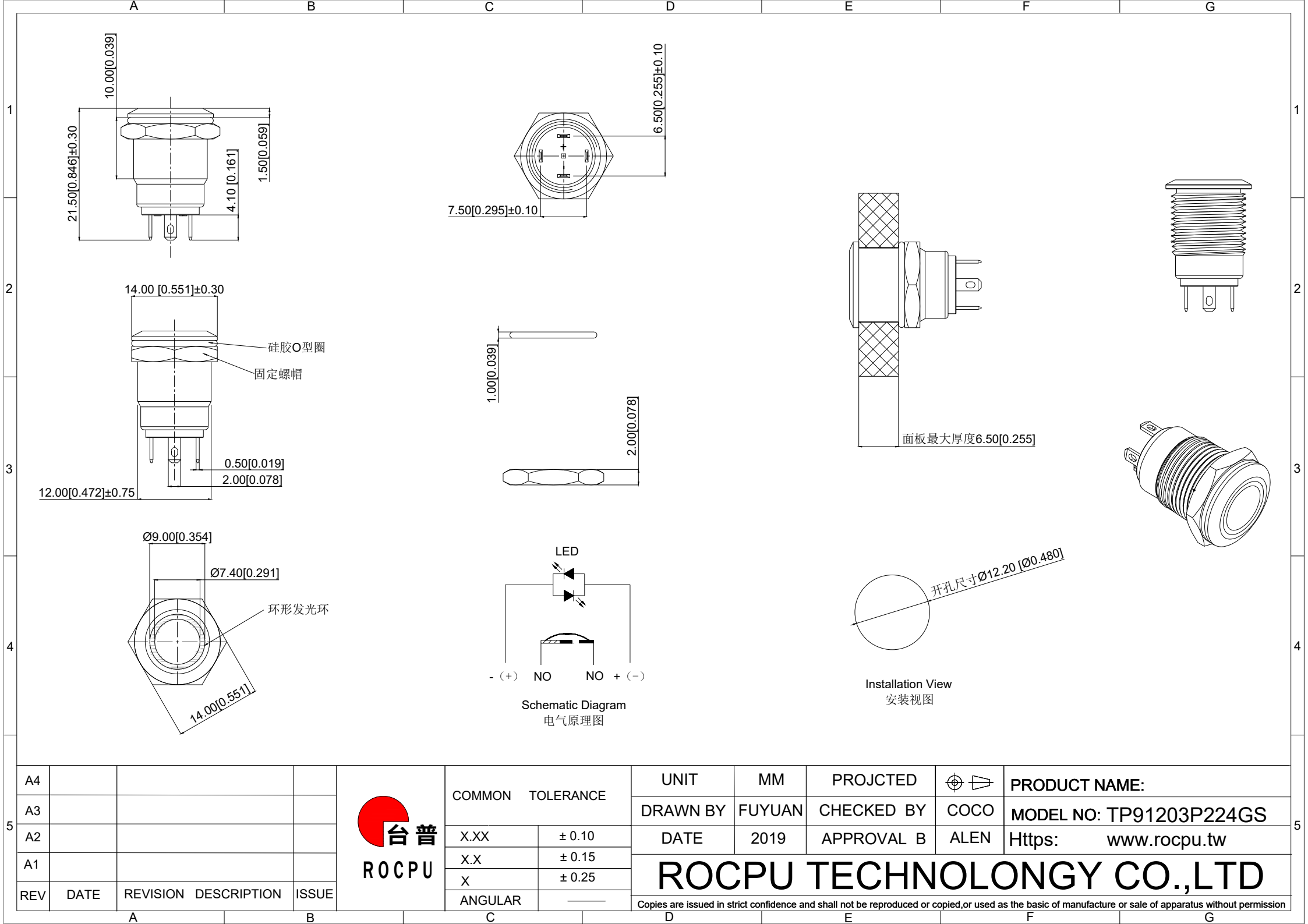

A4				
A3				
A2				
A1				
REV	DATE	REVISION	DESCRIPTION	ISSUE



COMMON TOLERANCE

X.XX	± 0.10
X.X	± 0.15
X	± 0.25
ANGULAR	—

UNIT

MM

PROJECTED



PRODUCT NAME:

DRAWN BY

FUYUAN

CHECKED BY

COCO

MODEL NO: TP91203P224GS

DATE

2019

APPROVAL B

ALEN

Https: www.rocpcu.tw

ROCPCU TECHNOLOGY CO.,LTD

Copies are issued in strict confidence and shall not be reproduced or copied, or used as the basic of manufacture or sale of apparatus without permission

性能参数											
1. Heating current: Ui: AC250V, lth: 3A 发热电流: Ui: AC250V, lth: 3A 2. Rated current:2A/DC36V 额定电流:2A/DC36V 3. Power-frequency withstand voltage:2000V1min 工频耐压:2000V1min 4. Insulation resistance:≥1000MΩ 绝缘电阻 :≥1000MΩ 5. Contact resistance:≤50mΩ 接触电阻 :≤50mΩ 6. Pressing stroke:1.80mm ± 0.10 按压行程:1.80mm ± 0.10 7. Contact stroke:0.60mm±0.10 接触行程 :0.60mm±0.10 8. welding temperature: 320 ℃± 20 ℃ 焊接温度: 320 ℃± 20 ℃ 9. Welding duration: Less than 3 seconds in duration 焊接时长: Less than 3 seconds in duration 10. Nut assembly torque:5-14N 螺帽装配力矩:5-14N 11. Protection level:IP65 防护等级:IP65 12. Explosion prevention level: IK08 防暴等级: IK08											
13. Working environment temperature: -20 ℃~+55 ℃ 工作环境温度: -20 ℃~+55 ℃ 14. Compression torque: ≤ 3N 按压扭力: ≤3N 15. Electrical life: 100000 cycles 电气寿命: 100000 cycles 16. mechanical: 5000000cycles 机械寿命: 5000000cycles 17. Operation method:Self compound 操作方式: 自复式 18. NO reverse thrust foot torque: ≤30N NO反推脚扭力: ≤30N 19. LED lamp power consumption: 20m以下 LED灯功耗: 20m以下 20. LED lamp lifespan: 40000h LED寿命: 40000h 21. LED color: Green LED颜色: 绿色											

A														B														C														D														E														F														G																																																							
材质参数																																																																																																																																											