
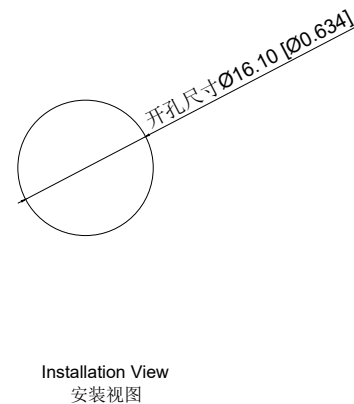
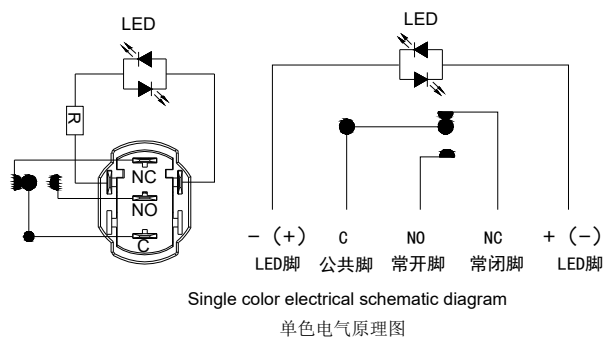
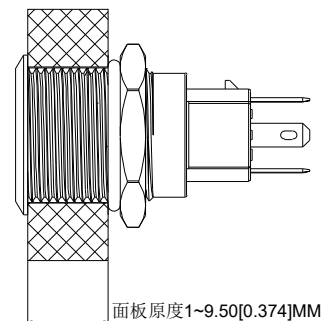
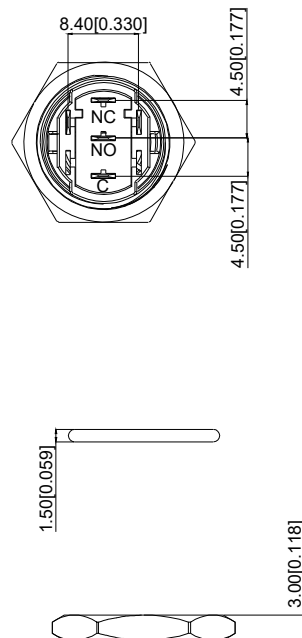


A4				
A3				
A2				
A1				
REV	DATE	REVISION	DESCRIPTION	ISSUE

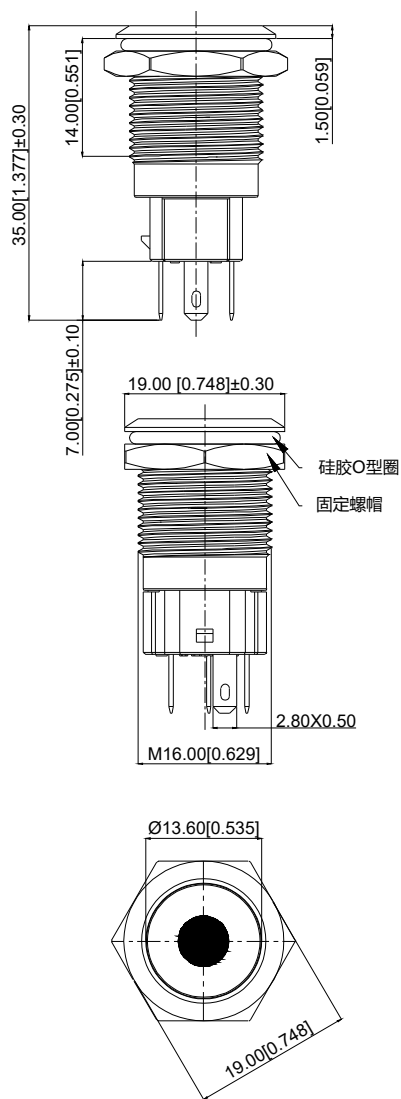

COMMON TOLERANCE

X.XX	± 0.10
X.X	± 0.15
X	± 0.25
ANGULAR	—

UNIT	MM	PROJECTED	PRODUCT NAME:
DRAWN BY	FUYUAN	CHECKED BY	COCO
DATE	2019	APPROVAL B	ALEN
MODEL NO: TP91649P224GS			
Https: www.rocpcu.tw			
ROCPU TECHNOLOGY CO.,LTD			
Copies are issued in strict confidence and shall not be reproduced or copied, or used as the basic of manufacture or sale of apparatus without permission			

	A	B	C	D	E	F	G																						
1	性能参数 1. Heating current: Ui: AC250V, Ith: 5A 发热电流: Ui: AC250V, Ith: 5A 2. Rated current:3A/DC36V 额定电流:3A/DC36V 3. Power-frequency withstand voltage:2000V1min 工频耐压:2000V1min 4. Insulation resistance:≥1000MΩ 绝缘电阻 :≥1000MΩ 5. Contact resistance:≤50mΩ 接触电阻 :≤50mΩ 6. Pressing stroke:2.80mm ± 0.10 按压行程:2.80mm ± 0.10 7. Contact stroke:1.50mm±0.10 接触行程 :1.50mm±0.10 8. welding temperature: 320 ℃± 20 ℃ 焊接温度: 320 ℃± 20 ℃ 9. Welding duration: Less than 3 seconds in duration 焊接时长: Less than 3 seconds in duration 10. Nut assembly torque:5-14N 螺帽装配力矩:5-14N 11. Protection level:IP67 防护等级:IP67 12. Explosion prevention level: IK09 防暴等级: IK09 连接形式 1. Welding temperature of wire: 320 ± 20 ℃ 线材焊接温度: 320±20℃ Wire welding duration: less than 3 seconds 线材焊接时长: 时长3秒以下 2. Can be used with dedicated connectors: 可配专用接插件使用: 2.1 Switch function wire: green (C) blue wire (NO) yellow wire (NC) 开关功能线材: 绿色(C) 蓝线 (NO) 黄线 (NC) 2.2 LED functional wire: red wire positive pole, black wire negative pole, LED without distinction between positive and negative poles LED功能线材: 红线正极, 黑线负极, LED不分正负极				13. Working environment temperature: -20 ℃~+55 ℃ 工作环境温度: -20 ℃~+55 ℃ 14. Compression torque: ≤ 3.5N 按压扭力: ≤3.5N 15. Electrical life: 500000 cycles 电气寿命: 500000 cycles 16. mechanical: 500000cycles 机械寿命: 500000cycles 17. Operation method:Self repeating form 操作方式: 自复式 18. NO reverse thrust foot torque: ≤30N NO反推脚扭力: ≤30N 19. LED lamp power consumption: 20m以下 LED灯功耗: 20m以下 20. LED lamp lifespan: 40000h LED寿命: 40000h 21. LED color: Green LED颜色: 绿色				1																				
										2	2																		
												3	3																
														4	4														
																5	5												
																		6	6										
																				7	7								
																						8	8						
																								9	9				
																										10	10		
																												11	11

A4				 台 普 ROC PU	COMMON TOLERANCE		UNIT	MM	PROJCTED		PRODUCT NAME:		
A3							DRAWN BY	FUYUAN	CHECKED BY	COCO	MODEL NO: TP91649P224GS		
A2					X.XX	± 0.10	DATE	2019	APPROVAL B	ALEN	Https: www.rocpu.tw		
A1					X.X	± 0.15	ROC PU TECHNOLOGY CO.,LTD						
REV	DATE	REVISION DESCRIPTION	ISSUE		X	± 0.25							
					ANGULAR	——	Copies are issued in strict confidence and shall not be reproduced or copied,or used as the basic of manufacture or sale of apparatus without permission						
A		B		C		D		E		F		G	

A		B		C		D		E		F		G	
材质参数													
10	luminous zone 发光区			PC 塑料		1							
9	LEDpin LED脚			Brass 黄铜		1		Silvering 镀银					
8	Base 底座			PA46		1							
7	Pin 引脚			Brass 黄铜		1		gold-plating 镀金					
6	Contact material 接触材质			silver alloy 银合金		1		Silvering 镀银					
5	LED Base LED底座			PBT		1							
4	Arm nut 固定螺帽			Brass 黄铜		1		nickeling 镀镍					
3	Oring O型圈			Silica gel 硅胶		1							
2	Housing 外壳			SUS 不锈钢		1							
1	Key 按键			SUS 不锈钢		1							
NO 序号	Part name 部件名			Material 材料		QTY 数量		Remark 备注					

A4				 台普 ROCPSU	COMMON TOLERANCE		UNIT	MM	PROJCTED		PRODUCT NAME:		
A3							DRAWN BY	FUYUAN	CHECKED BY	COCO	MODEL NO: TP91649P224GS		
A2					DATE	2019	APPROVAL B	ALEN	Https: www.rocpsu.tw				
A1					ROCPSU TECHNOLOGY CO.,LTD								
REV	DATE	REVISION	DESCRIPTION									ISSUE	ANGULAR
A		B		C		D		E		F		G	

Copies are issued in strict confidence and shall not be reproduced or copied,or used as the basic of manufacture or sale of apparatus without permission