

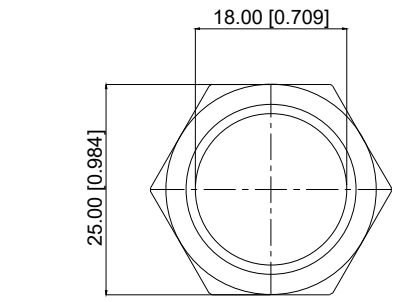
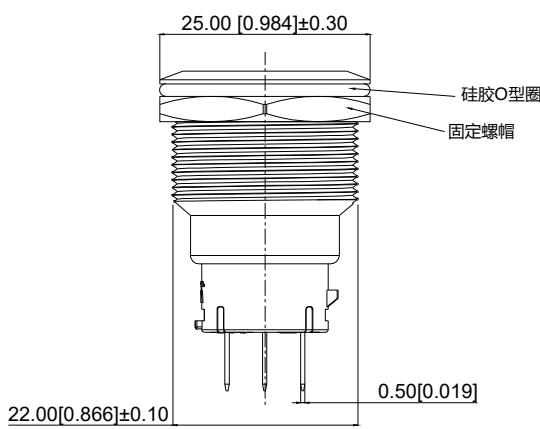
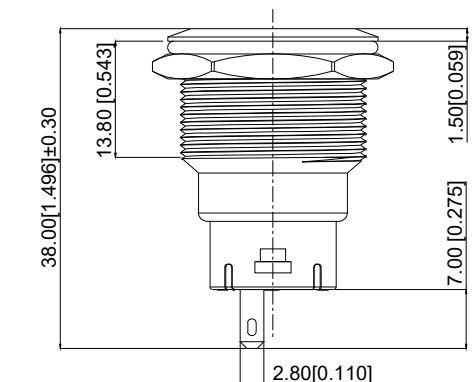
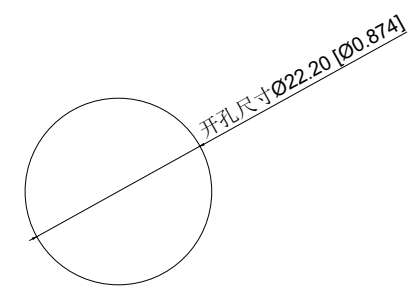


Electrical principles without lights
无灯电气原理

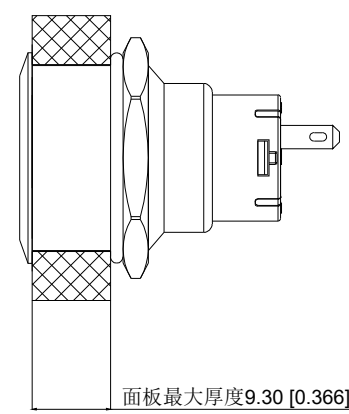

Installation View
安装视图

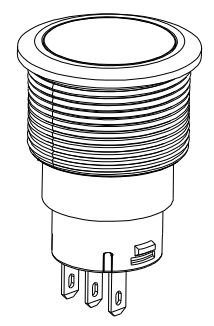

REV	DATE	REVISION	DESCRIPTION	ISSUE
A4				
A3				
A2				
A1				



COMMON TOLERANCE	
X.XX	± 0.10
X.X	± 0.15
X	± 0.25
ANGULAR	—

UNIT	MM	PROJECTED	PRODUCT NAME:
DRAWN BY	FUYUAN	CHECKED BY	MODEL NO: TP92236P2S
DATE	2019	APPROVAL B	Https: www.rocpu.tw
ROCPU TECHNOLOGY CO.,LTD			
Copies are issued in strict confidence and shall not be reproduced or copied, or used as the basic of manufacture or sale of apparatus without permission			

		A		B		C		D		E		F		G	
1	性能参数														1
	1. Heating current: Ui: AC250V, lth: 5A 发热电流: Ui: AC250V, lth: 5A														
	2. Rated current:3A/DC36V 额定电流:3A/DC36V														
	3. Power-frequency withstand voltage:2000V1min 工频耐压:2000V1min														
	4. Insulation resistance:≥1000MΩ 绝缘电阻 :≥1000MΩ														
	5. Contact resistance:≤50mΩ 接触电阻 :≤50mΩ														
	6. Pressing stroke:2.50mm ± 0.10 按压行程:2.50mm ± 0.10														
	7. Contact stroke:1.50mm±0.10 接触行程 :1.50mm±0.10														
	8. Nut assembly torque:5-14N 螺帽装配力矩:5-14N														
	9. Protection level:IP67 防护等级:IP67														
2	10. Explosion prevention level: IK10 防暴等级: IK10														2
	11. Working environment temperature: -20 ℃~+55 ℃ 工作环境温度: -20 ℃~+55 ℃														
	12. Compression torque: ≤ 6N 按压扭力: ≤6N														
	连接形式														
	1. Welding temperature of wire: 320 ± 20 ℃ 线材焊接温度: 320±20℃ Wire welding duration: less than 3 seconds 线材焊接时长: 时长3秒以下														
	2. Can be used with dedicated connectors: 可配专用接插件使用:														
	2.1 Switch function wire: Green Line (C), blue Line (NO), yellow Line (NC) 开关功能线材: 绿线(C)、蓝线 (NO)、黄线 (NC)														
3															3
4															4
5															5

材质参数												