

● SPECIFICATION TABLE:

产品型号	电感值	测试频率	直流电阻	直流电流
单位	uH	HZ	Ω max	Amax
CD32-1R0M	1.0±20%	100KHZ/0.25V	0.04	3.34
CD32-2R2M	2.2±20%	100KHZ/0.25V	0.06	2.35
CD32-3R3M	3.3±20%	100KHZ/0.25V	0.10	1.83
CD32-4R7M	4.7±20%	100KHZ/0.25V	0.14	1.50
CD32-5R6M	5.6±20%	100KHZ/0.25V	0.16	1.36
CD32-6R8M	6.8±20%	100KHZ/0.25V	0.20	1.22
CD32-8R2M	8.2±20%	100KHZ/0.25V	0.23	1.09
CD32-100M	10±20%	100KHZ/0.25V	0.29	0.95
CD32-120M	12±20%	100KHZ/0.25V	0.32	0.88
CD32-150M	15±20%	100KHZ/0.25V	0.40	0.82
CD32-180M	18±20%	100KHZ/0.25V	0.52	0.76
CD32-220M	22±20%	100KHZ/0.25V	0.66	0.63
CD32-270M	27±20%	100KHZ/0.25V	0.76	0.62
CD32-330M	33±20%	100KHZ/0.25V	0.87	0.56
CD32-390M	39±20%	100KHZ/0.25V	1.10	0.51
CD32-470M	47±20%	100KHZ/0.25V	1.25	0.47
CD32-560M	56±20%	100KHZ/0.25V	1.59	0.42
CD32-680M	68±20%	100KHZ/0.25V	1.82	0.38
CD32-820M	82±20%	100KHZ/0.25V	2.44	0.34
CD32-101M	100±20%	100KHZ/0.25V	2.84	0.31
CD32-121M	120±20%	100KHZ/0.25V	3.19	0.28
CD32-151M	150±20%	100KHZ/0.25V	4.20	0.16
CD32-181M	180±20%	100KHZ/0.25V	5.11	0.15
CD32-221M	220±20%	100KHZ/0.25V	7.31	0.14
CD32-271M	270±20%	100KHZ/0.25V	8.24	0.12
CD32-331M	330±20%	100KHZ/0.25V	10.19	0.10


Remark: 1. Inductance Tested at 1MHz, 0.25Vrms (20℃)

2. Isat: DC current at which the inductance drops approximate 30% from its value without current;

3. Irms: DC current that causes the temperature rise (ΔT =40° C) from 25° C ambient.


4. Operating Temperature : -25℃ ~ +125℃

● SHAPES AND DIMENSIONS 外形尺寸 (Unit:mm)

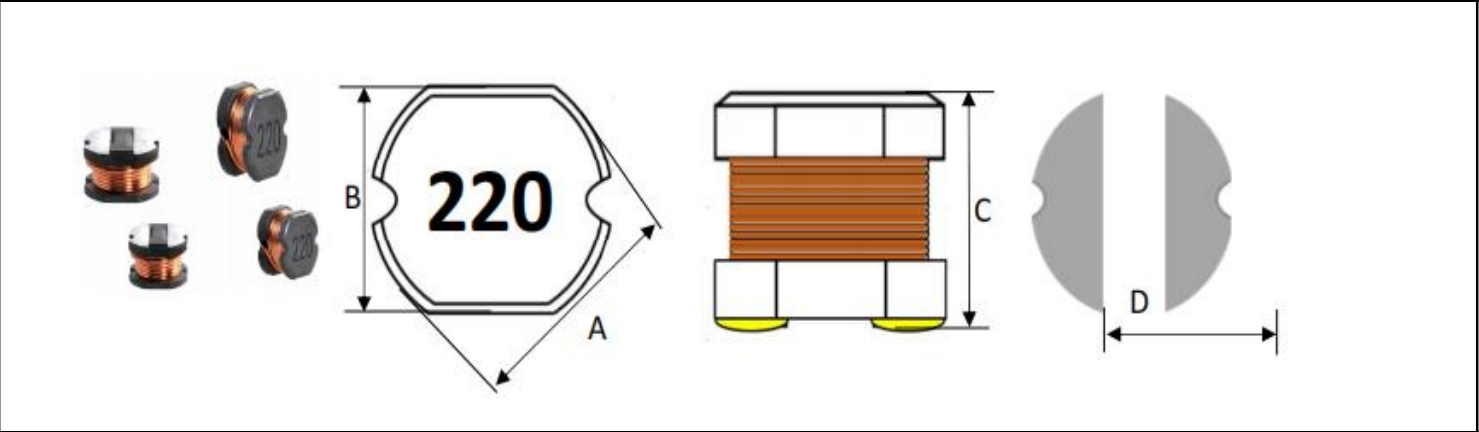

SERIES	A	B	C	D(ref)
CD32	3.5±0.3	3.0±0.3	2.1±0.3	1

● SPECIFICATION TABLE:

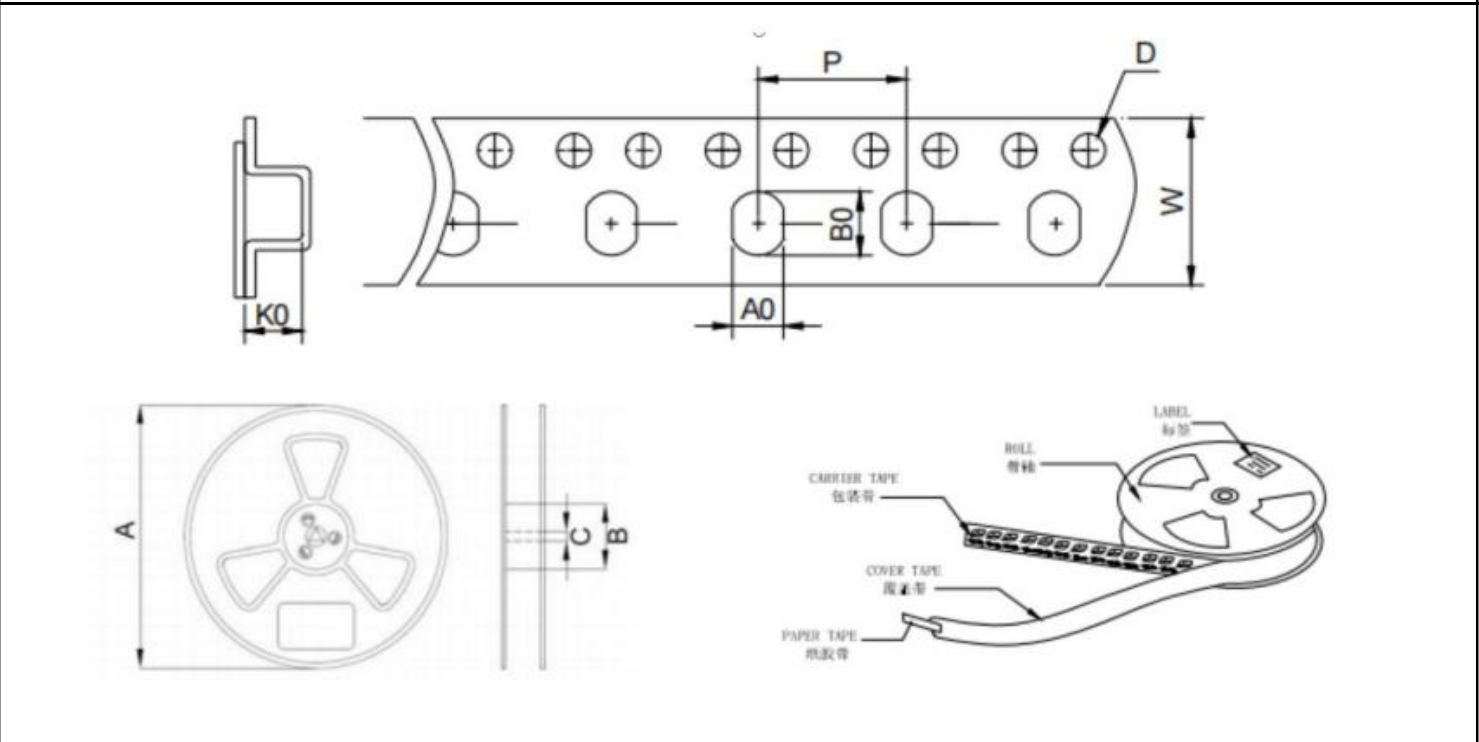

Type	Reel Dimension				
	A	B	C	D	P
CD32	330	100	13		
Tape Dimension					
W	A0	B0	K0	D	P
12.0	3.3	3.8	2.5	1.5	8.0