


● SPECIFICATION TABLE:

产品型号	电感值	测试频率	直流电阻	直流电流
单位	uH	HZ	Ω max	Amax
CD76-1R0M	1.0±20%	100KHZ/0.25V	0.01	8.00
CD76-1R5M	1.5±20%	100KHZ/0.25V	0.02	7.50
CD76-2R2M	2.2±20%	100KHZ/0.25V	0.03	7.00
CD76-3R3M	3.3±20%	100KHZ/0.25V	0.05	6.50
CD76-4R7M	4.7±20%	100KHZ/0.25V	0.06	6.00
CD76-6R8M	6.8±20%	100KHZ/0.25V	0.07	5.00
CD76-100M	10±20%	100KHZ/0.25V	0.07	4.50
CD76-120M	12±20%	100KHZ/0.25V	0.08	4.00
CD76-150M	15±20%	100KHZ/0.25V	0.09	3.50
CD76-180M	18±20%	100KHZ/0.25V	0.10	3.00
CD76-220M	22±20%	100KHZ/0.25V	0.11	2.50
CD76-270M	27±20%	100KHZ/0.25V	0.12	2.00
CD76-330M	33±20%	100KHZ/0.25V	0.13	1.50
CD76-390M	39±20%	100KHZ/0.25V	0.16	1.00
CD76-470M	47±20%	100KHZ/0.25V	0.18	0.90
CD76-560M	56±20%	100KHZ/0.25V	0.24	0.85
CD76-680M	68±20%	100KHZ/0.25V	0.28	0.80
CD76-820M	82±20%	100KHZ/0.25V	0.37	0.78
CD76-101M	100±20%	100KHZ/0.25V	0.43	0.72
CD76-121M	120±20%	100KHZ/0.25V	0.47	0.66
CD76-151M	150±20%	100KHZ/0.25V	0.64	0.58
CD76-181M	180±20%	100KHZ/0.25V	0.71	0.51
CD76-221M	220±20%	100KHZ/0.25V	0.96	0.49
CD76-271M	270±20%	100KHZ/0.25V	1.11	0.42
CD76-331M	330±20%	100KHZ/0.25V	1.26	0.40
CD76-391M	390±20%	100KHZ/0.25V	1.77	0.36
CD76-471M	470±20%	100KHZ/0.25V	1.96	0.35


Remark: 1. Inductance Tested at 1MHz, 0.25Vrms (20℃)
2. Isat: DC current at which the inductance drops approximate 30% from its value without current;
3. Irms: DC current that causes the temperature rise (ΔT =40° C) from 25° C ambient.
4. Operating Temperature : -25℃ ~ +125℃

● SHAPES AND DIMENSIONS 外形尺寸 (Unit:mm)

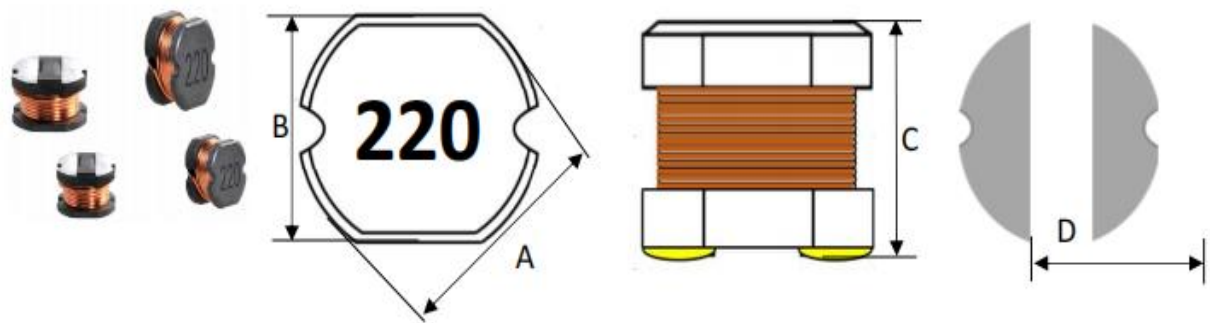

SERIES	A	B	C	D(ref)
CD76	7.8±0.3	7.0±0.3	6.2±0.3	2.4

● SPECIFICATION TABLE:

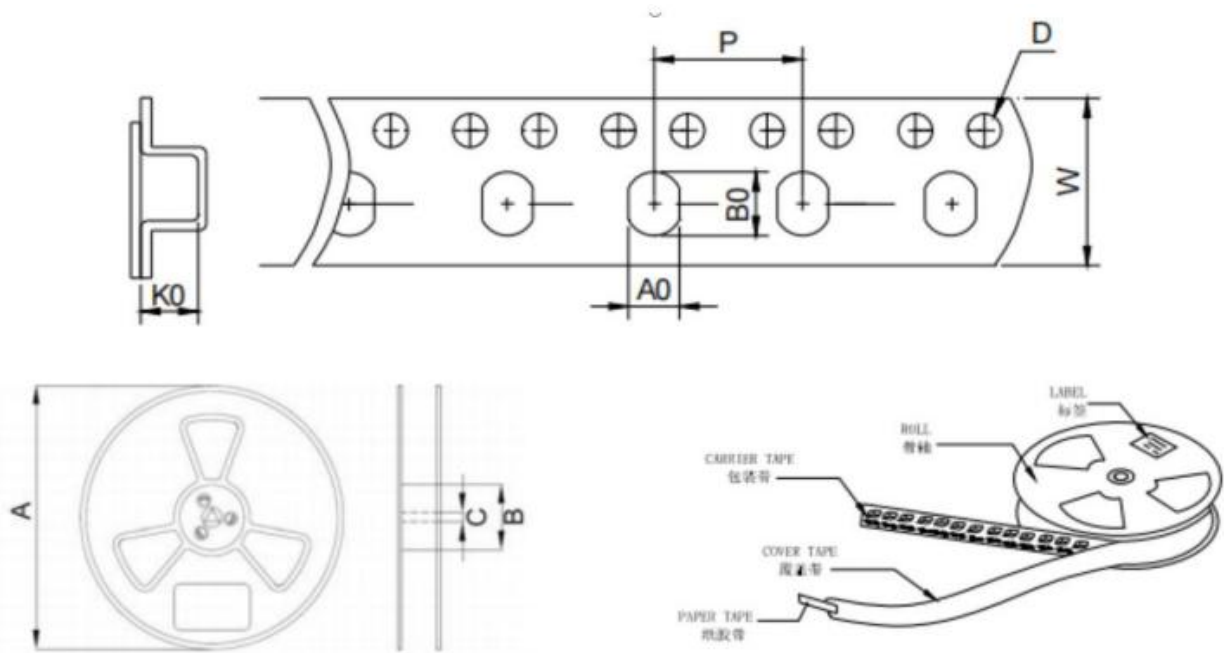

Type	Reel Dimension				
	A	B	C	D	P
CD75	330	100	13		
Tape Dimension					
W	A0	B0	K0	D	P
16.0	7.6	8.6	6.3	1.5	12.0