

SMD transformer for vehicle and LAN transformer



FEATURES

- Matched to PMC-Sierra's PM4351 COMET transceiver
- Small surface mount package
- Contains both transmit and receive transformers
- Isolation voltage: 1500Vrms

Series/Type: **T1137NLMT**



ELECTRICAL SPECIFICATIONS @25°C

OCL	DCR (Ω) , ce		Turn Ratio	CW/W	LL	
1.2mH Min	0.70(Pri)	1.20(Sec)	1CT :2.42CT	30pF Max	-0.6 μ H Max	

*Testing Conditions:100KHz 0.1V 8mA DC BIAS

DIMENSIONS & MARKING

SCHEMATICS

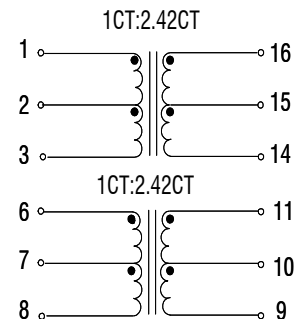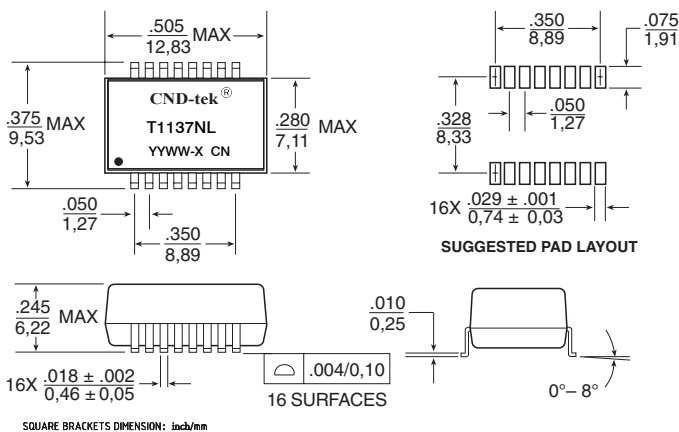

Packaging Specifications

