

Common mode chokes for telecom applications

High impedance to minimize common mode noise

Excellent EMI performance

Operate temperature range: -40°C to +125°C (Including self temperature rise)

Storage temperature range: -40°C to +125°C







CM422SG471N H


Electrical Specification @25°C

OCL:	PIN1-4 = PIN2-3 = 470uH +50%/-30% @100KHz/0.1V
Rated Current:	0.90A Max
Hi-POT :	500VAC 1mA,1S,50Hz
Turn Ratio:	1:1±5%
D.C.R:	PIN1-4 = PIN2-3 = 200mΩ Max.

Dimensions

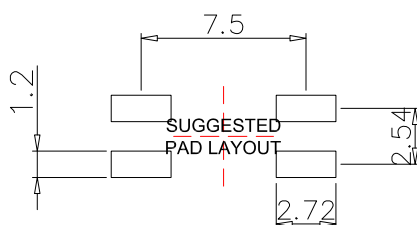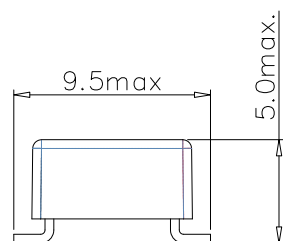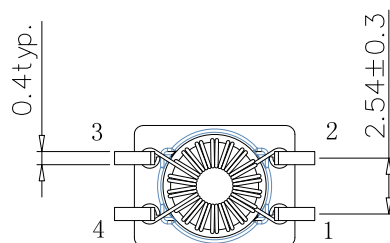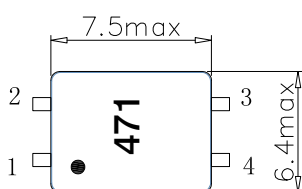

Schematic

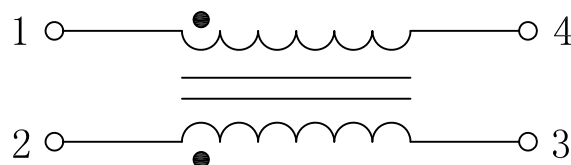

(Units: mm, Unless otherwise specified, all tolerances are ±0.25)