


CHIP COMMON MODE CHOKE

High Common Mode Impedance at High Frequency.
Excellent Noise Suppression Performance.
Small Size and Low Profile, Surface Mount Type.
Operating Temperature Range: -40 ℃ to +125 ℃.
RoHS Compliant.
AEC-Q200 Compliant.




Part Number	Electrical Specifications @25°C						
	Common mode Impedance (Ω@10MHz)		Common mode Impedance (uH +50%/-30%)	DCR (Ω Max)	Rated Current mA Max	RatedVolt (Vdc Max)	IR M(Ω Min)
ACT45B-201-2PTL000H	6000Min	12000Typ.	200	4.50	70	50	10

MECHANICAL


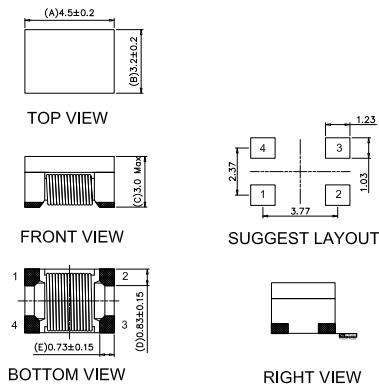


SCHEMATICS

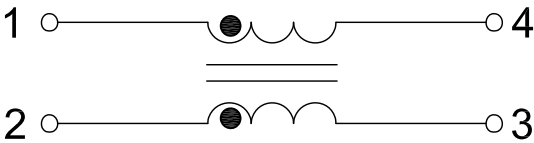

Unless otherwise specified all tolerances are:±0.25 in mm

TAPING AND PACKING

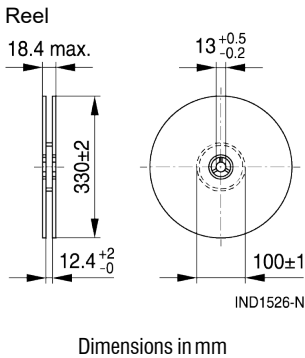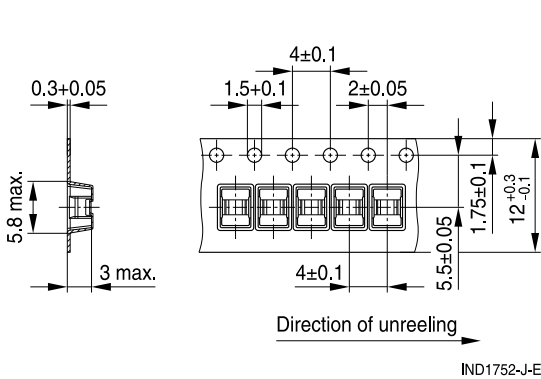

Quantity (pcs):
2000 PCS PER REEL
10REELS PER CARTON
10000 PCS PER CARTON