




CHIP COMMON MODE CHOKE


High Common Mode Impedance at High Frequency.
Excellent Noise Suppression Performance.
Small Size and Low Profile, Surface Mount Type.
Operating Temperature Range: -40°C to $+150^{\circ}\text{C}$.
RoHS Compliant.
AEC-Q200 Compliant.

Part Number	Electrical Specifications @25°C					
	Common mode Impedance (Ω @10MHz)	Common mode Impedance ($\mu\text{H} \pm 50\%/-30\%$)	DCR (Ω Max)	Rated Current mA Max	Rated Volt (Vdc Max)	IR M(Ω Min)
CM4532S-110-A T	300Min 600Typ.	11	0.60	250	50	10

MECHANICAL


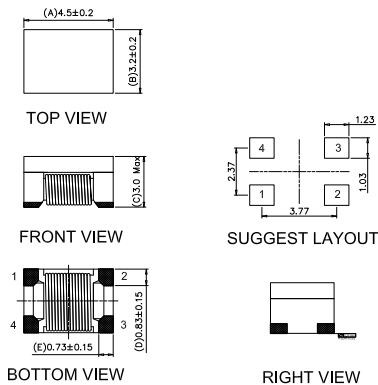


SCHEMATICS

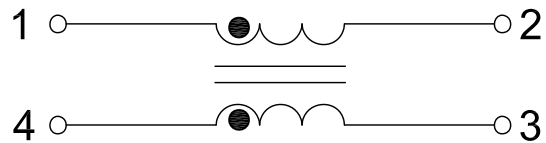

Unless otherwise specified all tolerances are ± 0.25 in mm

TAPING AND PACKING

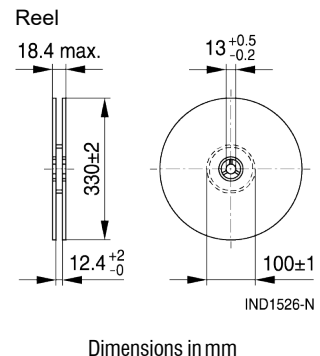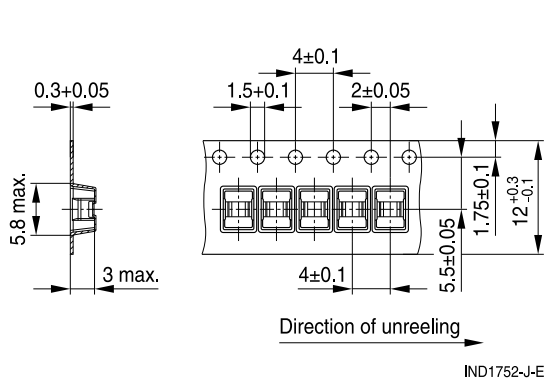

Quantity (pcs):
2000 PCS PER REEL
10 REELS PER CARTON
20000 PCS PER CARTON