


# DC1206J-10X *Proto Advantage*

Datasheet revision 1.0


[www.Proto-Advantage.com](http://www.Proto-Advantage.com)

## 10 pack: Discrete to TH Adapters – SM/TH/J pins

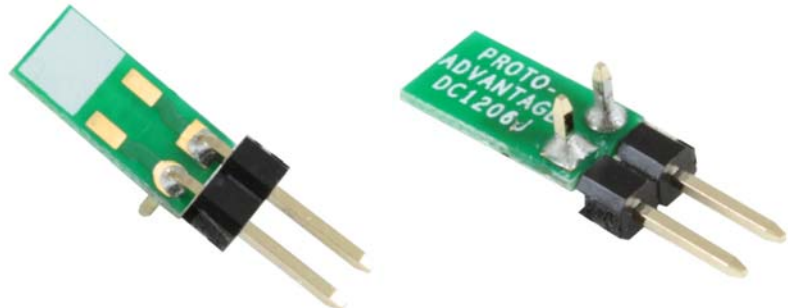

| DIMENSIONS                         |             |             |             |              |              |              |
|------------------------------------|-------------|-------------|-------------|--------------|--------------|--------------|
| Part Numbers                       | mm          |             |             | inches       |              |              |
|                                    | A           | B           | C           | A            | B            | C            |
| DC0402S / DC0402T / DC0402J        | 0.25        | 0.65        | 0.65        | 0.010        | 0.026        | 0.026        |
| DC0603S / DC0603T / DC0603J        | 0.70        | 0.90        | 1.00        | 0.028        | 0.035        | 0.039        |
| DC0805S / DC0805T / DC0805J        | 1.05        | 0.95        | 1.40        | 0.041        | 0.037        | 0.055        |
| DC1206S / DC1206T / <b>DC1206J</b> | <b>2.05</b> | <b>1.05</b> | <b>1.80</b> | <b>0.081</b> | <b>0.041</b> | <b>0.071</b> |
| DC1210S / DC1210T / DC1210J        | 1.90        | 1.10        | 2.70        | 0.075        | 0.043        | 0.106        |
| DC1411S / DC1411T / DC1411J        | 1.10        | 1.80        | 2.25        | 0.043        | 0.071        | 0.089        |
| DC1813S / DC1813T / DC1813J        | 2.70        | 1.40        | 3.40        | 0.106        | 0.055        | 0.134        |
| DC2010S / DC2010T / DC2010J        | 3.45        | 1.25        | 2.70        | 0.136        | 0.049        | 0.106        |
| DC2220S / DC2220T / DC2220J        | 3.75        | 1.55        | 5.40        | 0.148        | 0.061        | 0.213        |
| DC2413S / DC2413T / DC2413J        | 2.60        | 2.25        | 2.30        | 0.102        | 0.089        | 0.091        |
| DC2512S / DC2512T / DC2512J        | 4.85        | 1.25        | 3.40        | 0.191        | 0.049        | 0.134        |
| DC2917S / DC2917T / DC2917J        | 4.15        | 2.05        | 4.60        | 0.163        | 0.081        | 0.181        |
| DC2924S / DC2924T / DC2924J        | 3.85        | 2.35        | 4.15        | 0.152        | 0.093        | 0.163        |

Top View (SMD Footprint)

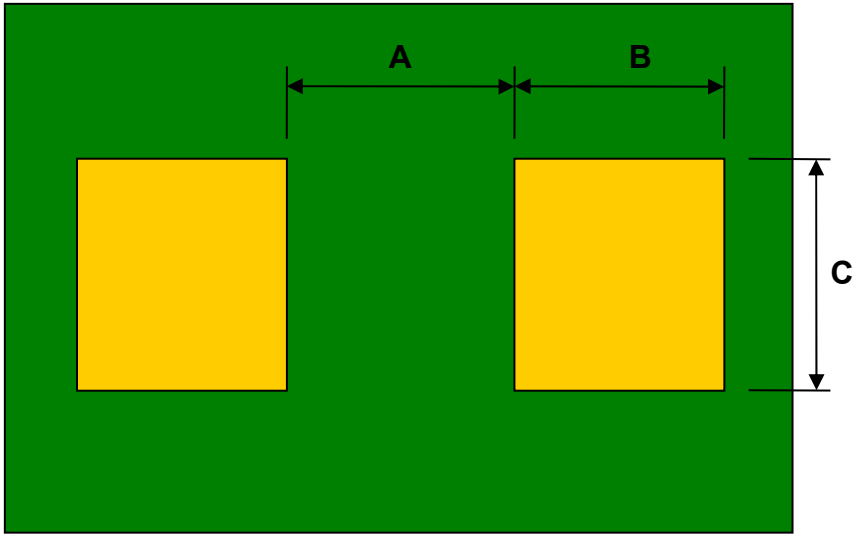

(Representative drawing only - not to scale)