


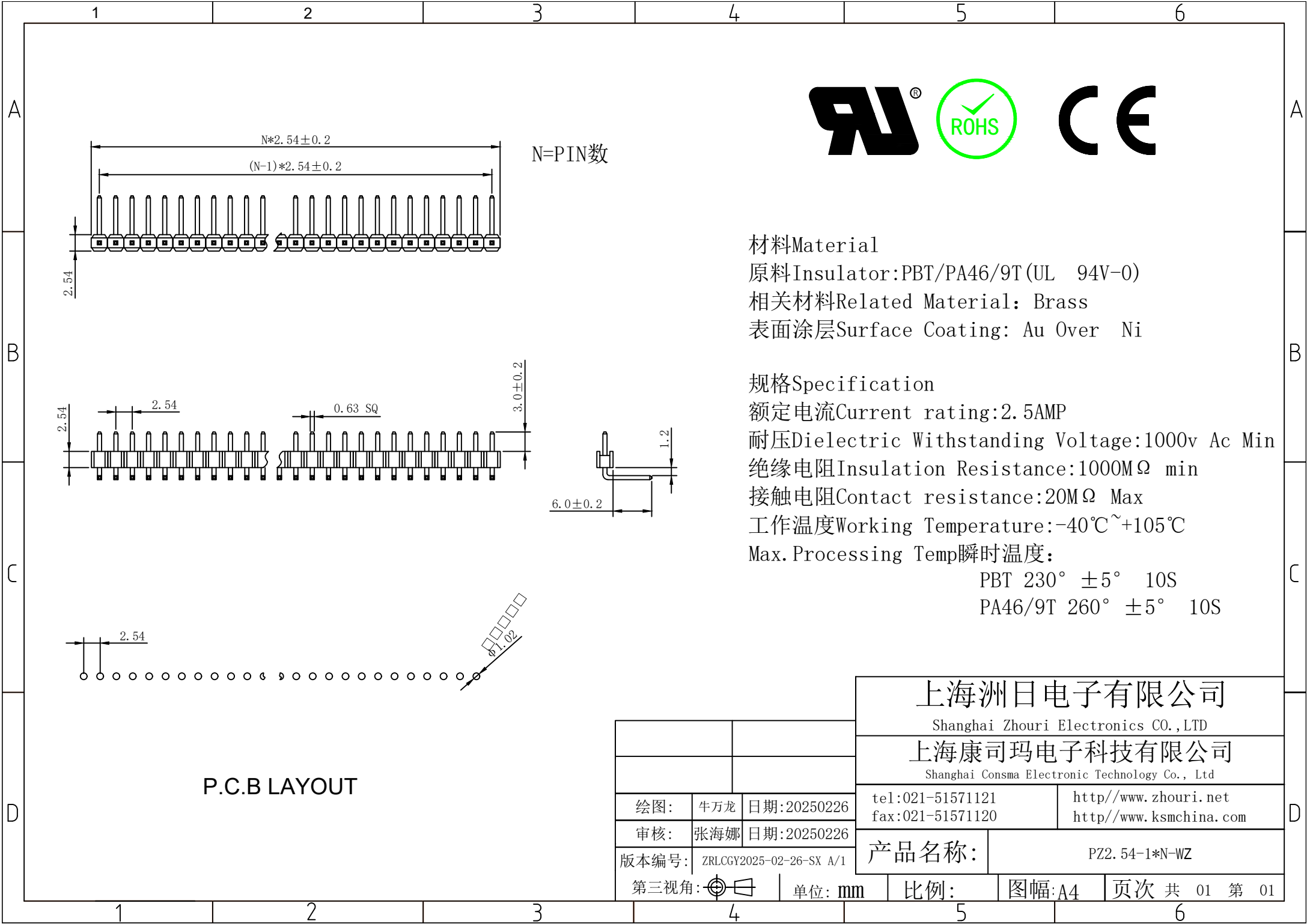

材料Material
原料Insulator:PBT/PA46/9T(UL 94V-0)
相关材料Related Material: Brass
表面涂层Surface Coating: Au Over Ni

规格Specification
额定电流Current rating:2.5AMP
耐压Dielectric Withstanding Voltage:1000v Ac Min
绝缘电阻Insulation Resistance:1000MΩ min
接触电阻Contact resistance:20MΩ Max
工作温度Working Temperature:-40℃~+105℃
Max.Processing Temp瞬时温度:
PBT 230° ±5° 10S
PA46/9T 260° ±5° 10S

上海洲日电子有限公司			
Shanghai Zhouri Electronics CO.,LTD			
上海康司玛电子科技有限公司			
Shanghai Consma Electronic Technology Co., Ltd			
tel:021-51571121		http://www.zhouri.net	
fax:021-51571120		http://www.ksmchina.com	
产品名称:		PZ2.54-1*N-WZ	
第三视角:	单位: mm	比例:	图幅:A4
版本编号: ZRLCGY2025-02-26-SX A/1		页次 共 01 第 01	