
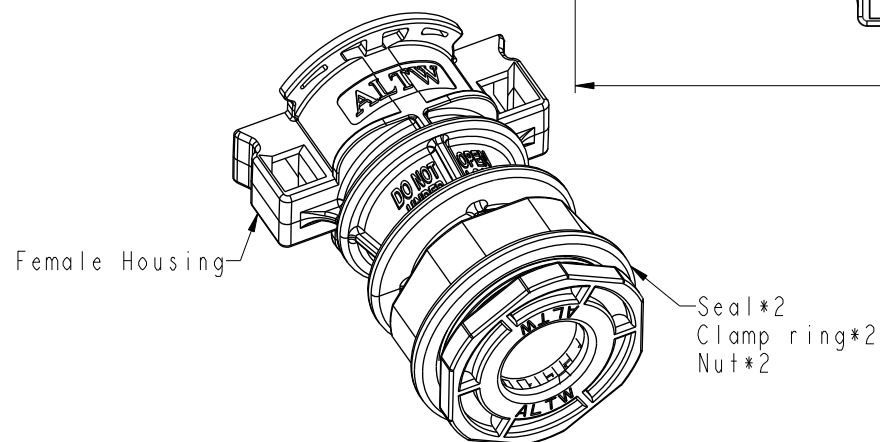
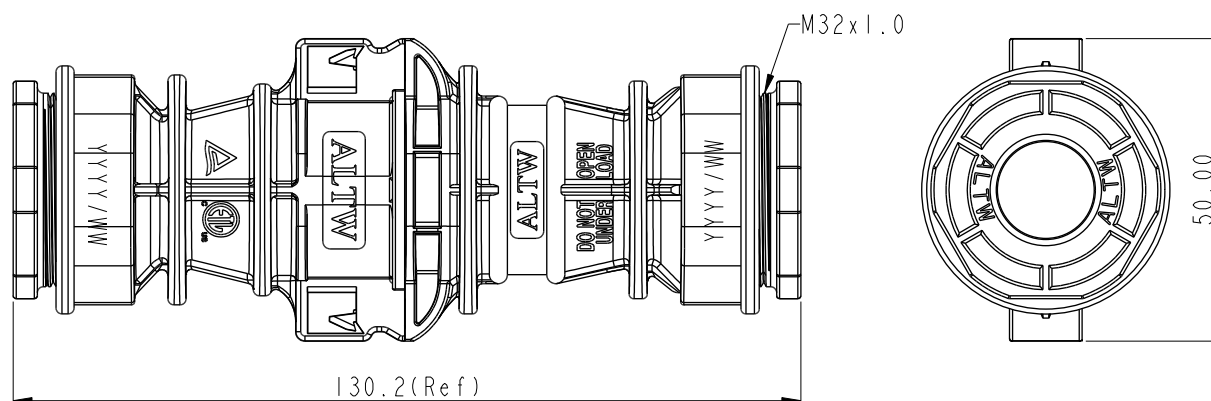


REV.	ECN NO.	DATE	SIGN	DESCRIPTION
A	Initial Released	2020/11/25	Ruru	Old Item No. CX-00B0M32-7001

QC Laser Mark:
YYYY = Year
WW = Week

Cable Joiner Housing Part Number
FC-001BNGY-700X

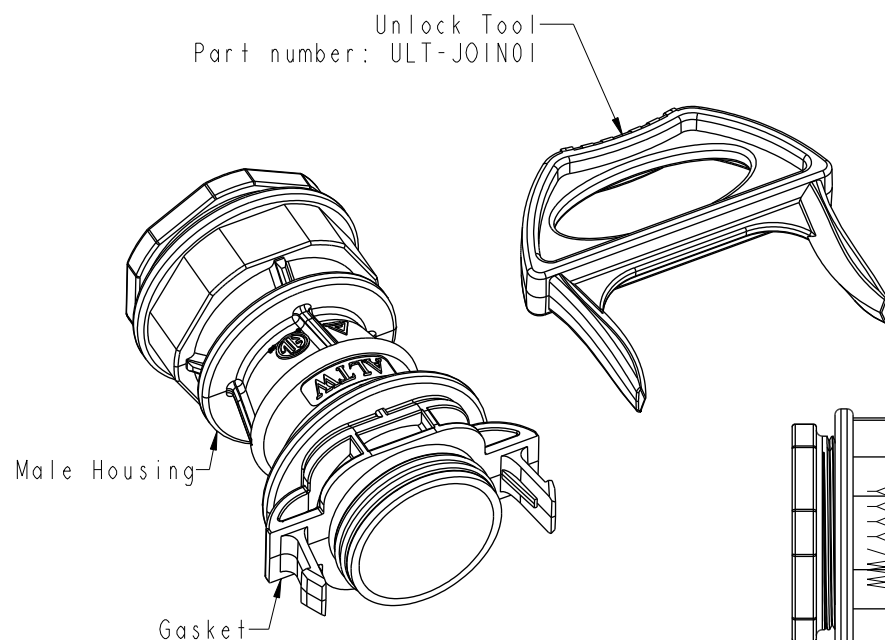

* FC-001BNGY-700X
UL 6703A & TUV 2pfg 1915

Note:
* Waterproof Rate: IP67, Mated
* Connector: Thermoplastic, Black
* Butt Pin: Copper alloy
* Gasket: Rubber, Gray
* Disassembly-Using the Unlock tool.
* Operating Temperature : -40~+105°C
* Withstanding Voltage : 6KV
* Pollution Degree : III
* Cable OD Range: 16mm~12mm
* Avoid oil and gasoline
* Recommended sealing Nut torque
Minimum: 25Kgf-cm

A	UNIT:mm	TITLE FICX, NONE, I, Field Installable None, Gray		Amphenol LTW		ITEM NO FC-001BNGY-7001	DRAWN BY Ruru	DATE 2020-11-25
	TOLERANCE ± 0.5 mm	SCALE 4:5	SIZE A4	SHEET 1	OF 1	DWG NO FC-001BNGY-7001	CHECKED BY Rita	DATE 2020-11-25
		REV. A	WC-REV. B.4	QC: Inspection item		CUSTOMER ALTW	APPROVED BY Max	DATE 2020-11-25