

## SUMMARY

### # Wires

|              |   |
|--------------|---|
| Low voltage  | 4 |
| High voltage | 1 |



*Image is for illustrative purpose only*

|                  |                                 |
|------------------|---------------------------------|
| Series           | 2B                              |
| Termination type | Male solder Hybrid High-Voltage |
| IP rating        | 50                              |
| AWG wire size    | 30.00 - 22.00                   |
| Cable Ø          | 6.30 - 7.20 mm                  |
| Status           | active                          |
| Matching parts   | <a href="#">EGG.2B.704.CLL</a>  |

### Download

[Request a quote](#)

## TECHNICAL DETAILS

### Mechanics

|                   |                                                                                                                               |
|-------------------|-------------------------------------------------------------------------------------------------------------------------------|
| Shell Style/Model | FG*: Straight plug, cable collet and nut for fitting a bend relief                                                            |
| Keying            | 1 key (alpha=0, plug: male contacts, receptacle: female contacts)                                                             |
| Housing Material  | Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces |
| Variant           | Z : Nut for fitting a bend relief                                                                                             |
| Weight            | 30.62 g                                                                                                                       |

### Performance

|               |                             |
|---------------|-----------------------------|
| Configuration | 2B.704 : 1 High V. 4 Low V. |
| Insulator     | L: PEEK (UL 94 / V-0/1.5)   |
| Rated Current | 5 Amps                      |

### Specifications

|                                              |
|----------------------------------------------|
| Contact Type: Solder                         |
| Test voltage HV Ue (kV dc) 7.5               |
| Test voltage HV Ue (kV rms) 5.3              |
| Rated current HV (A) 8                       |
| Test voltage LV cont-cont sold.(kV rms) 0.85 |
| Test voltage LV cont-shell sold.(kV rms) 1.2 |


LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Rated current LV (A) 5

Others

- Endurance (Shell): 5000
- Temp (min / max): -55°C / +250°C
- Humidity (max): <=95% [at 60 deg C / 140 F]
- Vibration: 15 g [10 Hz - 2000 Hz]
- Shock Resistance: 100 g [ 6 ms]
- Climatical Category: 50/175/21
- Shielding (min): 75 dB (10 MHz)
- Shielding (min): 40 dB (1 GHz)
- Salt Spray Corrosion: >1000 hr

DRAWINGS

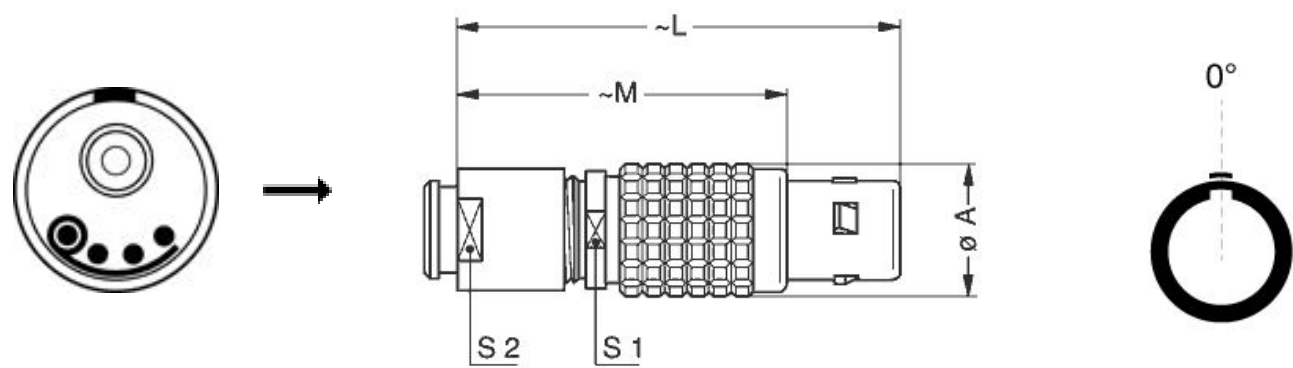

Dimensions

|     | A    | L    | M    | S1   | S2   |
|-----|------|------|------|------|------|
| mm. | 15   | 49   | 37   | 13   | 12   |
| in. | 0,59 | 1,93 | 1,46 | 0,51 | 0,47 |

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided “as is”. LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

Spanner wrench: [DCD.2B.025.PA120](#)

Caps: [BFG.2B.100.PCSG](#)

*LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.*