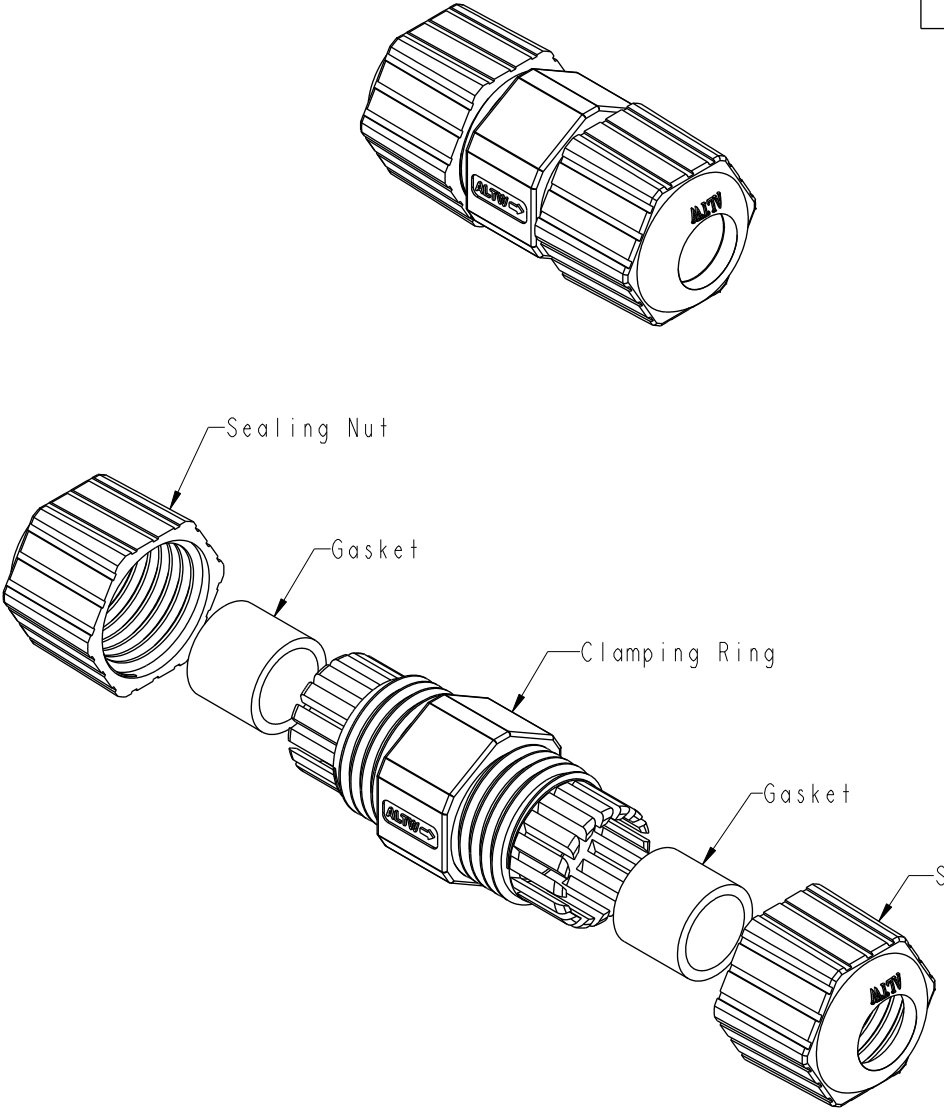
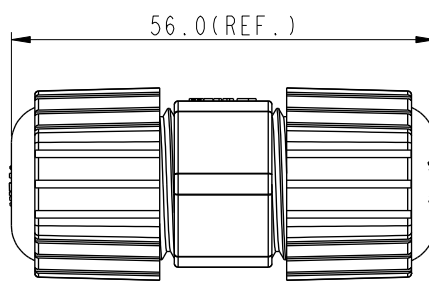
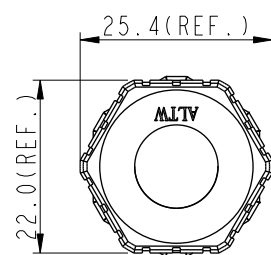
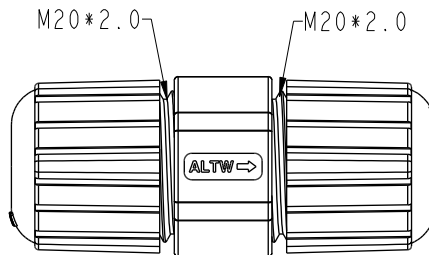
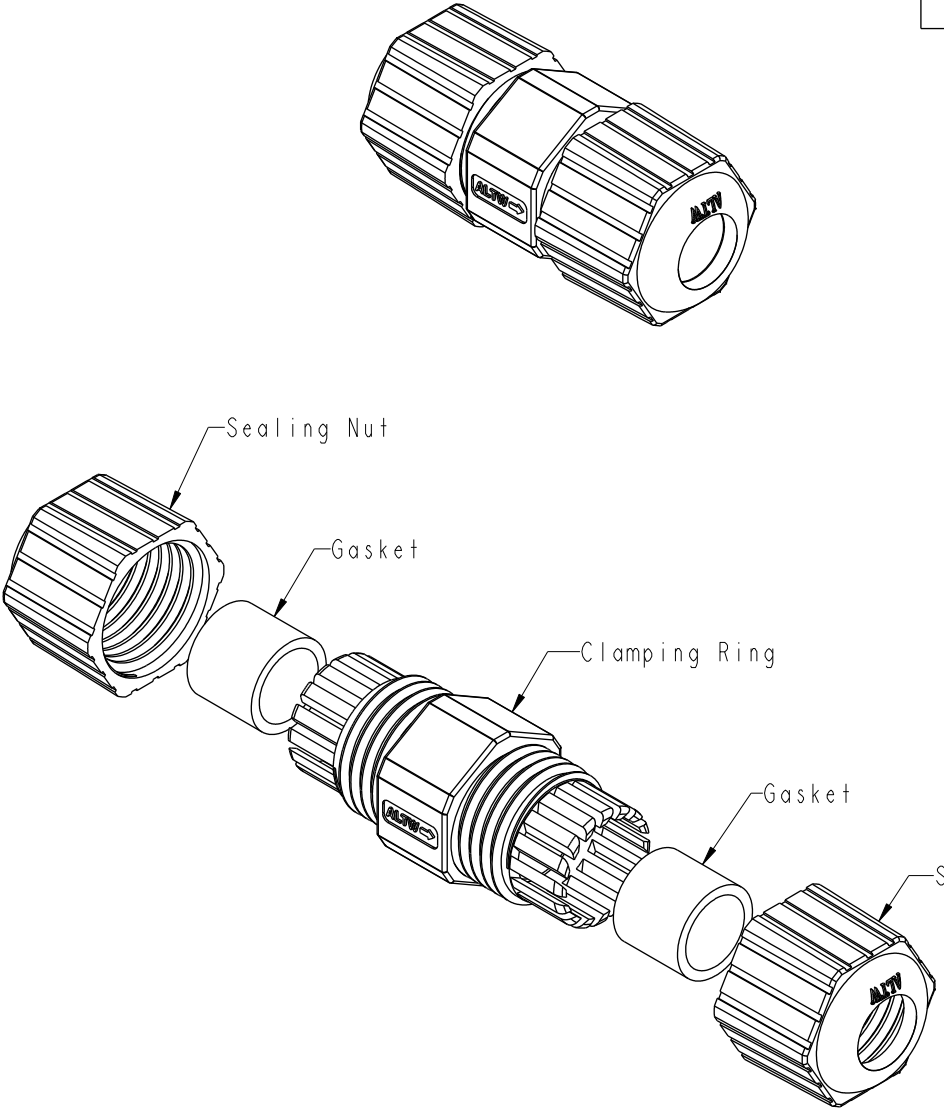


	1	2	3	4	5	6	7	8	
F					REV.	ECN NO.	DATE	SIGN	DESCRIPTION
					A	Initial Released	2020/11/24	Ruru	Old Item No. CX-00B0M20-7001
E									
D									
C									
B									
A									

Sealing Nut

Gasket

Clamping Ring

Gasket

Sealing Nut

56.0(REF.)

M20*2.0

M20*2.0

25.4(REF.)

22.0(REF.)

Note:

- * Waterproof Rate: IP67, Mated
- * Sealing Nut: Thermoplastic, Black
- * Gasket: Rubber, Black
- * Center Housing: Thermoplastic, Black
- * Clamping Ring: Thermoplastic, Black
- * Cable Range: Ø6~Ø10mm
- * One Set non-Assembly in One PE Bag

UNIT:mm		TITLE		Amphenol LTW		ITEM NO		DRAWN BY		DATE	
		FICX, NONE, I, Field Installable				FC-001BNBK-7001		Ruru		2020-11-24	
		None, Black				FC-001BNBK-7001		Rita		2020-11-24	
TOLERANCE		SCALE	SIZE	SHEET	OF	CUSTOMER		APPROVED BY		DATE	
±0.5 mm		1:2	A4	1	1	ALTW		Max		2020-11-24	
		REV.	WC-REV.	QC: Inspection item							
		A	A.3								

安費諾亮泰企業股份有限公司

W10814-03-0001A2