

Han 16M-Metal Cover-Bolt-for Base

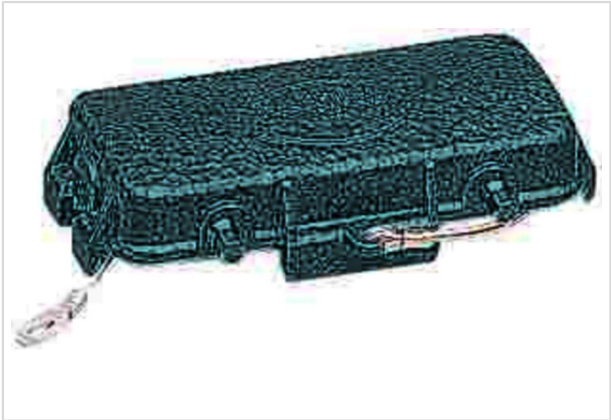


Image is for illustration purposes only. Please refer to product description.

Part number	09 37 016 5405
Specification	Han 16M-Metal Cover-Bolt-for Base
HARTING eCatalogue	https://b2b.harting.com/09370165405

Identification

Category	Accessories
Series of hoods/housings	Han [®] M
Type of accessory	Protection cover
Description of the accessory	for bulkhead mounted housings
	for surface mounted housings
	for cable to cable housing
	Metal
	With fixing cord

Version

Size	16 B
Locking type	Double locking lever

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R1 (HL 1-3) R7 (HL 1-3)

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076 CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	DNV GL

Commercial data

Packaging size	1
Net weight	70 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140055773
ETIM	EC002314
eCl@ss	27440208 Cap for industrial connectors