

SUMMARY

Wires

High voltage 8



Image is for illustrative purpose only

Series 2P
Termination type Male solder
IP rating 50
AWG wire size 0.00 - 0.00
Cable Ø 3.20 - 5.20 mm
Status active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model CA*: Straight plug with cable collet
Keying
Housing Material PSU (Polysulfone), gray
Weight 8.64 g

Performance

Configuration 2P.H08 : 8 High Voltage
Insulator
Rated Current 6.5 Amps

Specifications


Test voltage contact-contact : 10.3 kV rms
Air clearance min.: 7.42 mm
Creepage distance min.: 7.42 mm

Others

Temp (min / max): -50°C / +150°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

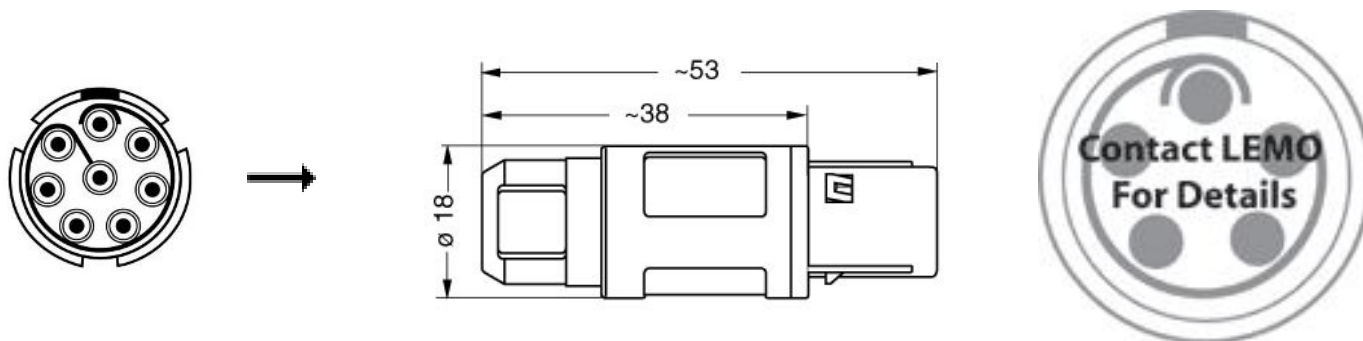

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.