

材料Material

原料Insulator: PA9T (UL 94V-0)

相关材料Related Material: Brass

表面涂层Surface Coating: Au Over Ni

规格Specification

额定电流Current rating: 2.5AMP

耐压Dielectric Withstanding Voltage: 1000V AC Min




绝缘电阻Insulation Resistance: 1000MΩ min

接触电阻Contact resistance: 20MΩ Max

工作温度Working Temperature: $-40^{\circ}\text{C} \sim +105^{\circ}\text{C}$

Max. Processing Temp 瞬时温度:

PA9T $260^{\circ} \pm 5^{\circ}$ 10S

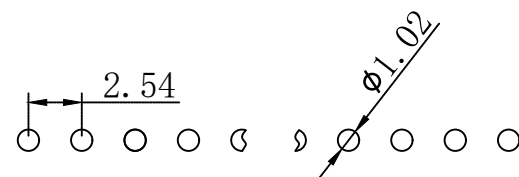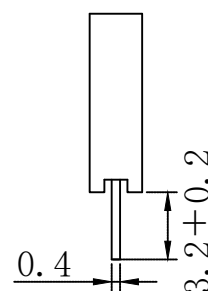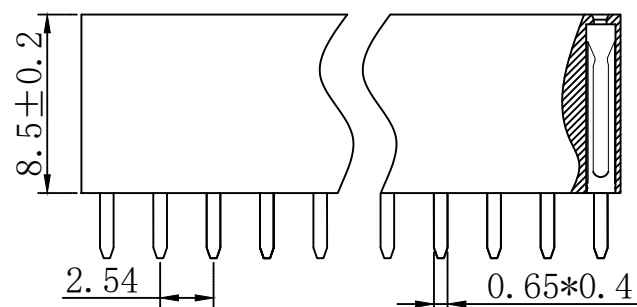

P.C.B LAYOUT

上海洲日电子有限公司

Shanghai Zhouri Electronics CO.,LTD

上海康司玛电子科技有限公司

Shanghai Consma Electronic Technology Co., Ltd

tel:021-51571121

<http://www.zhouri.net>

fax:021-51571120

<http://www.ksmchina.com>

产品名称:

PM 2.54-1xN-9T

绘图:

牛万龙

日期:20250226

审核:

张海娜

日期:20250226

版本编号:

ZRLCGY2025-02-26-SX A/1

第三视角:



单位: mm

比例:

图幅: A4

页次 共 01 第 01