


TQFP-64/ LQFP-64/ VQFP-64  
to DIP-64 SMT Adapter (0.5 mm pitch, 10 x 10 mm body)


| REF. | DIMENSIONS |       |      |        |       |      |
|------|------------|-------|------|--------|-------|------|
|      | mm         |       |      | inches |       |      |
|      | MIN.       | TYP.  | MAX. | MIN.   | TYP.  | MAX. |
| A    |            | 10.00 |      |        |       |      |
| A2   |            | 10.00 |      |        |       |      |
| B    |            | 2.00  |      |        |       |      |
| C    |            | 0.30  |      |        |       |      |
| D    |            | 0.20  |      |        |       |      |
| E    |            | 0.50  |      |        |       |      |
| F    |            |       |      |        | 0.600 |      |
| G    |            |       |      |        | 0.100 |      |
| H    |            |       |      |        | 0.025 |      |

Top View (SMT Footprint)

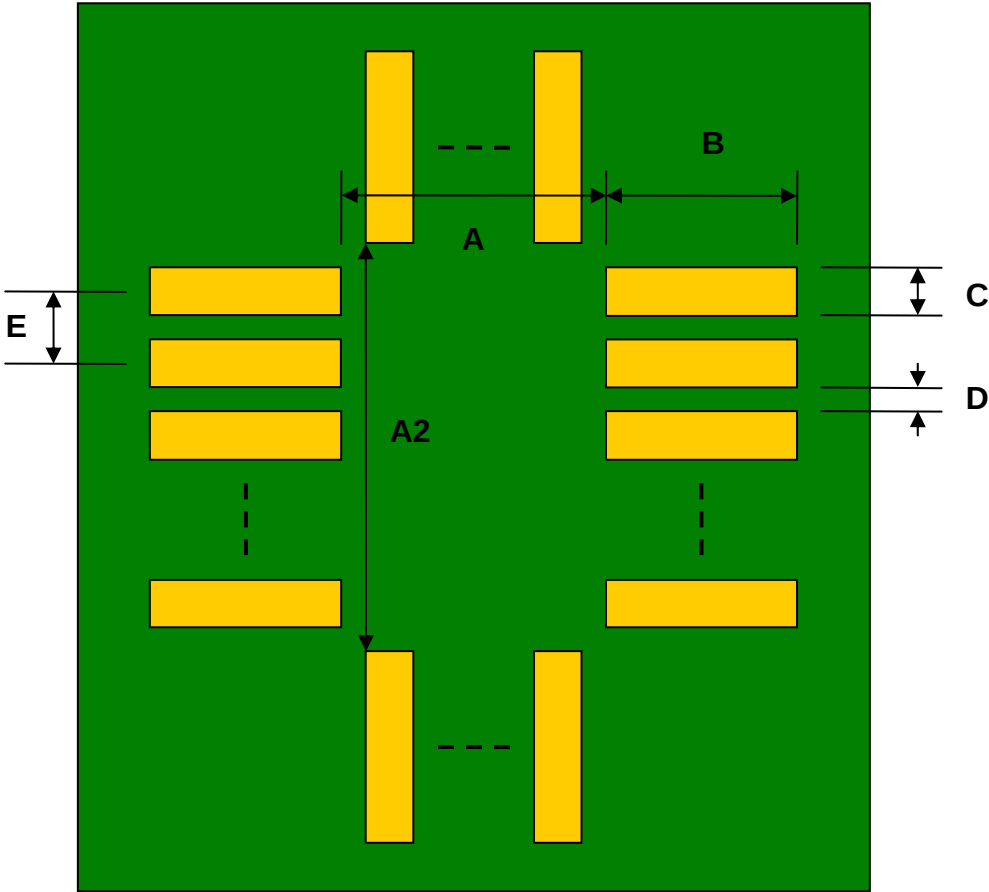


(Representative drawing only - not to scale)

**Bottom View (DIP Pins)**

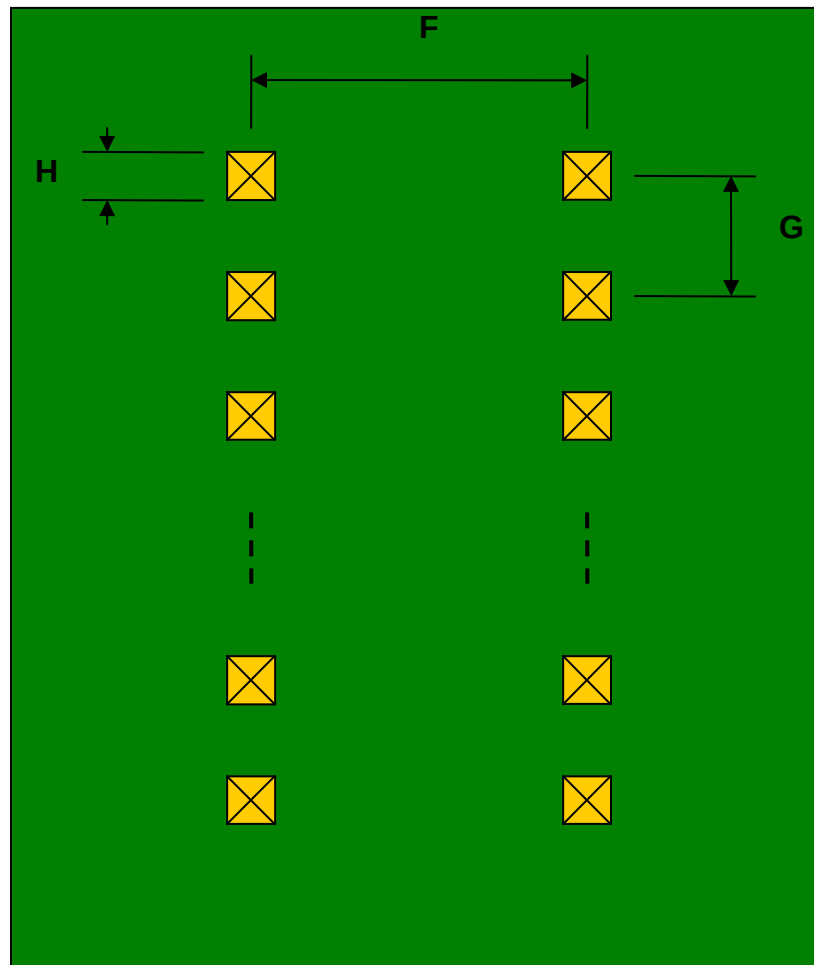

(Representative drawing only - not to scale)

**Side View (DIP Pins)**

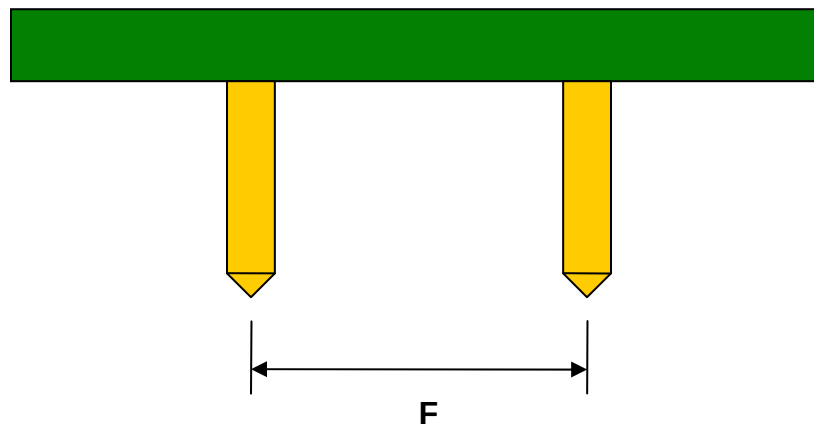

(Representative drawing only - not to scale)