
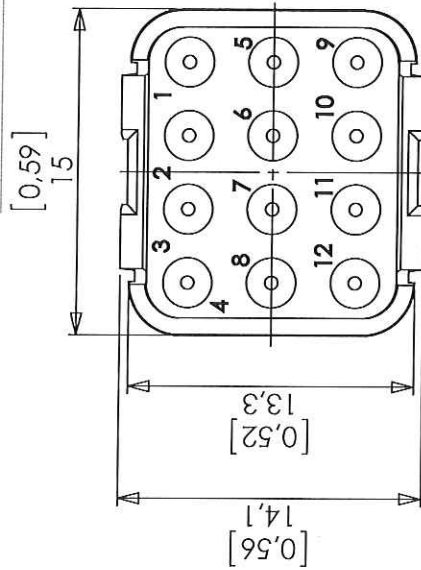



DMC-M 12-20 AX

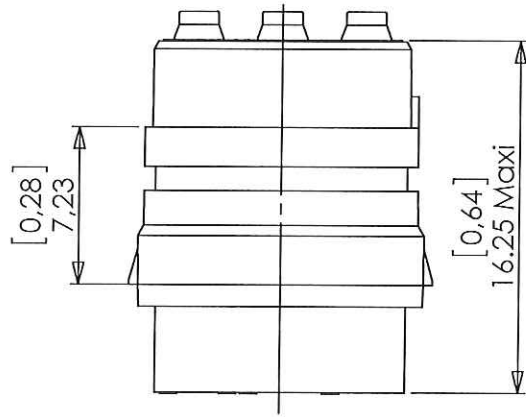

CARACTERISTIQUES :

CARACTERISTIQUES :

Operating temperature range -55°C à +175°C
Material: Thermoplastic et silicone
Withstand voltage: 1800 V eff.; 50 Hz
Weight: 3.6g Maxi (without contacts)
Dimensions: Millimeters [inches]
Contacts:

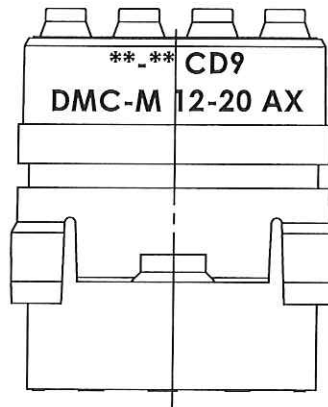

- Pin #20 : 724-0001-20 /
EN315508M2020

Outil insertion/extraction :
- M81969/14-10

Module livré sans contacts / Module delivered without contacts
- M8 1969/14-10

a	31/05/18	Création	SERIE	DMC-M	DATE	26/10/93	VISA Creation Created	VISA Approbation Approval
Observations			DESIGNATION	Module P 12 #20 Pin module 12 #20				
ORIGINE : C/PIN :			DE 34040					
			REF : P/N:					
			DMC-M 12-20 AX					

ET

Connecteurs Electriques Deutsch
17, rue LAVOISIER - BP 117 - 27091 EVREUX CEDEX 09 - FRANCE

FICHE TECHNIQUE
TECHNICAL DATA SHEET

TECHNICAL DATA SHEET

Ce document est la propriété de CED et ne peut être reproduit ou communiqué sans son autorisation This document is the property of CED and cannot be reproduced or disclosed without the CED approval