


Coaxial Panel Connector 23_BMA-N50-0-16/119_N

Description

Straight panel receptacle jack, flange mount

Interface standards
IEC 60169-33_MIL-STD-348/321 fully intermateable

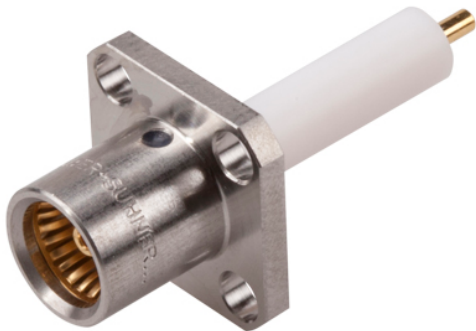

Technical Data

Electrical Data

Impedance 50 Ω
Interface frequency max. 18 GHz

Mechanical Data

Number of matings 1000
Weight 0.0036 kg

Environmental Data

Operating temperature -65 °C to 125 °C
2011/65/EU (RoHS - including
2015/863 and 2017/2102) compliant

Material Data

Piece Parts	Material	Surface Plating
Centre contact	Copper Beryllium Alloy	Gold Plating (Nickel underplated)
Outer contact	Copper Beryllium Alloy	Gold Plating (without Nickel underplating)
Body	Stainless Steel	
Insulator	PFA / PTFE	

Related Documents

Outline drawing DOU-00308860
Catalogue drawing DCA-00321890

Ordering Information

Single package 23_BMA-N50-0-16/119_NE