


Model 4768 Cable Assembly, Double Banana Plug To Micrograbber® Breakouts

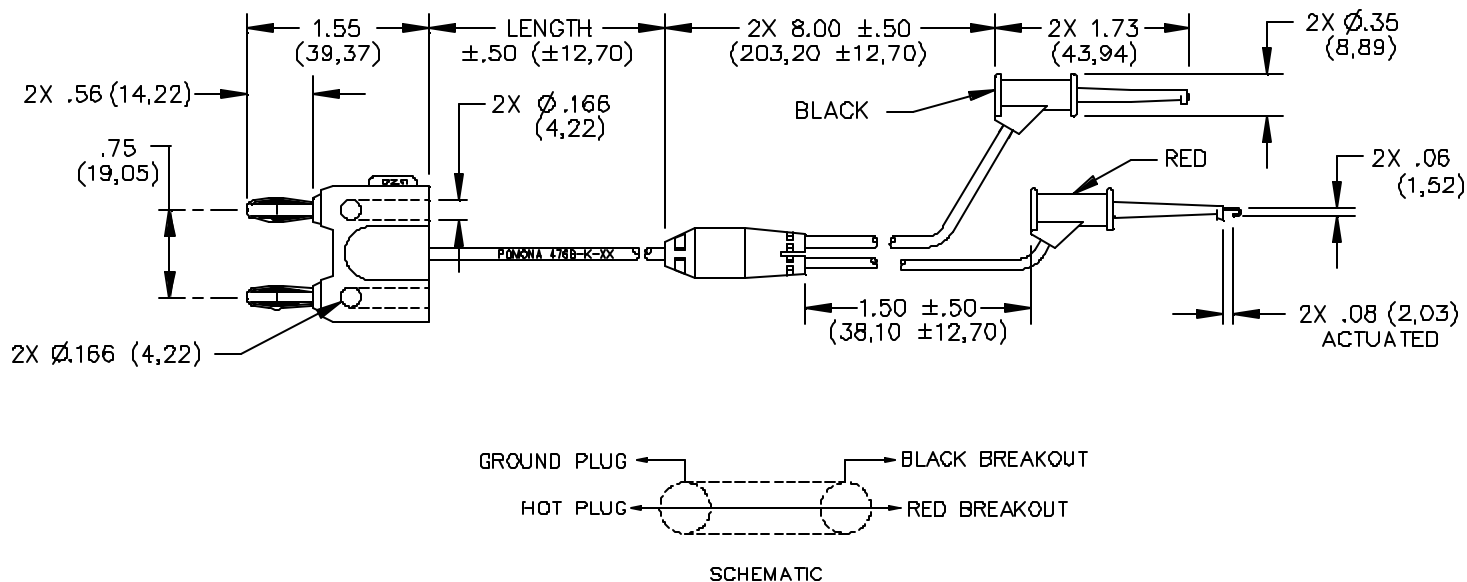

MATERIALS:

Connector: Double Banana Plug

Body: Brass

Spring: Beryllium Copper

Insulation: Polypropylene

Cable: RG 174/U, 2.54 (.100) O.D.

Marking: "Pomona 4768-K-XX"

Molded Breakout: PVC molded to breakout leads and cable.

Wire: 20 AWG

Connector: Micrograbber® Breakouts

Contact – Gold Plated Beryllium Copper

Spring – Stainless steel

Insulation – Glass filled nylon

RATING:

Operating Temperature: +50°C (+122°F) Max.

Operating Voltage: 1000 WVDC

ORDERING INFORMATION: Model 4768-K-XX XX = Cable length

Std. Lengths: 4" (102), 8" (203), 12" (305), 18" (457), 24" (610), 36" (914), 48" (1219), 60" (1524).

Additional lengths can be quoted upon request.

Ordering Example: 4768-K-24 is a cable with a length of 24".

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA