
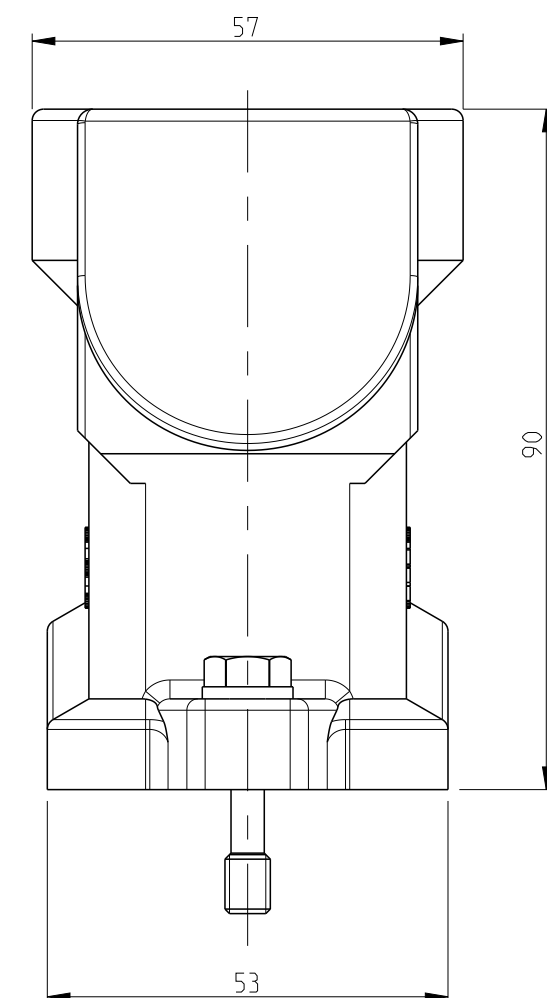
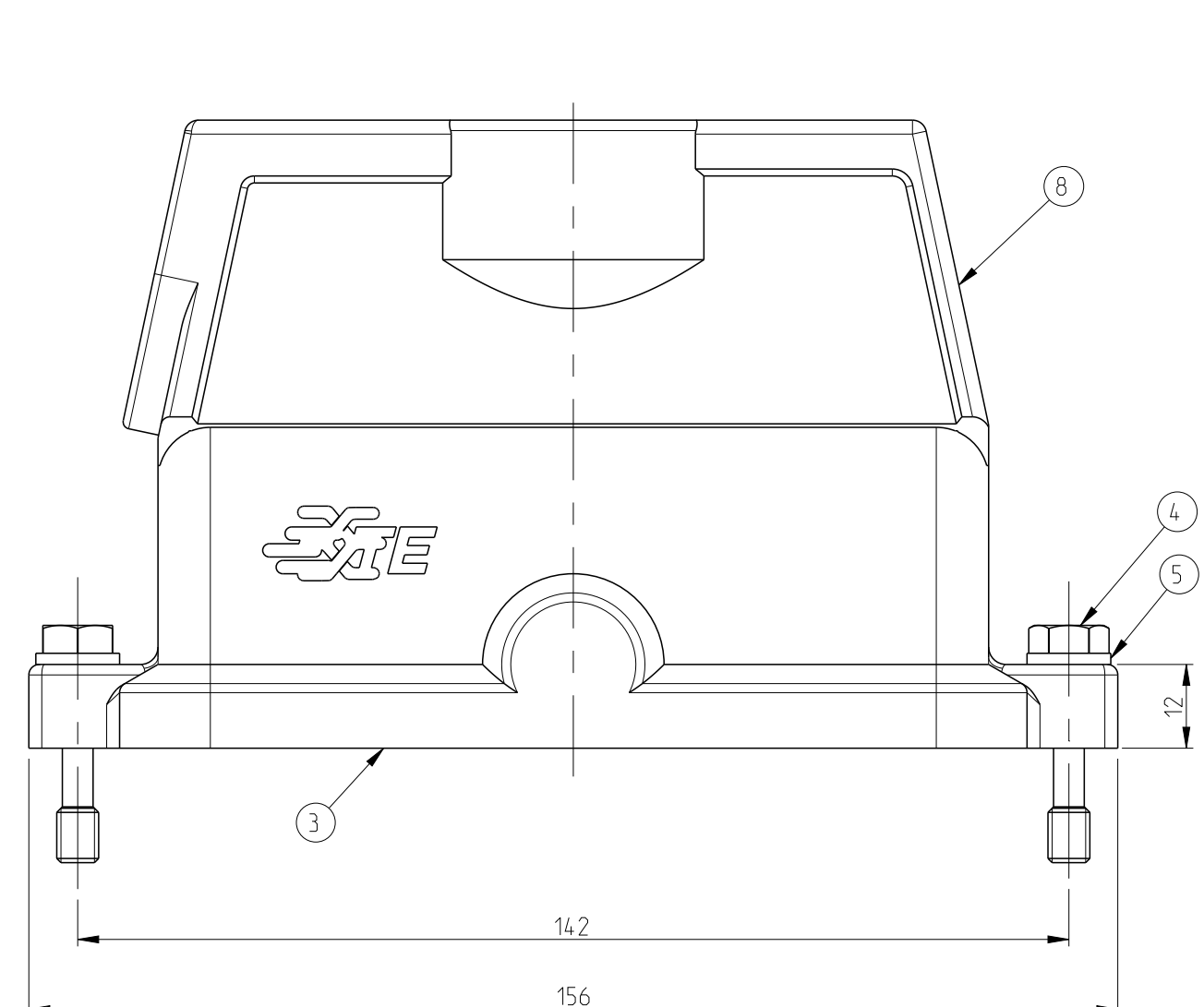
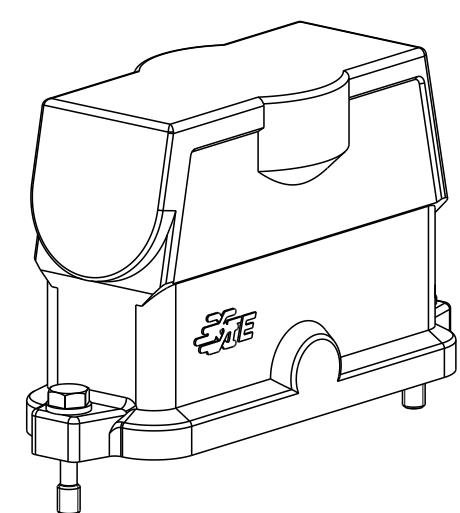
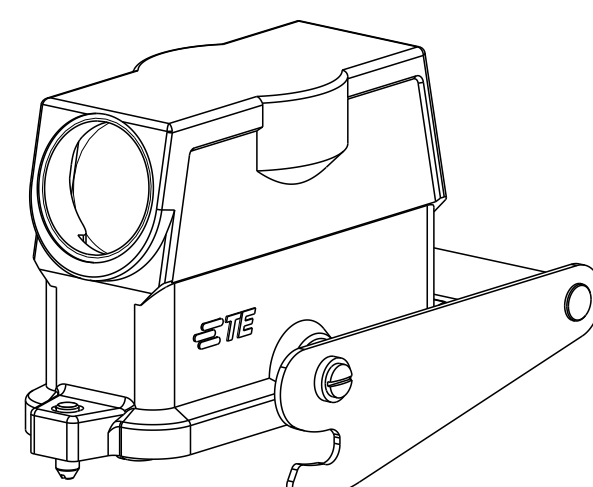
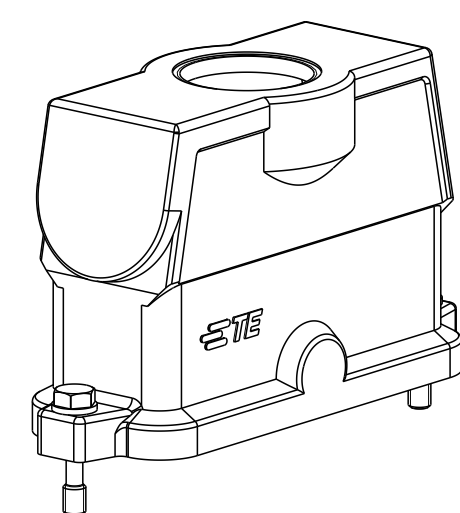
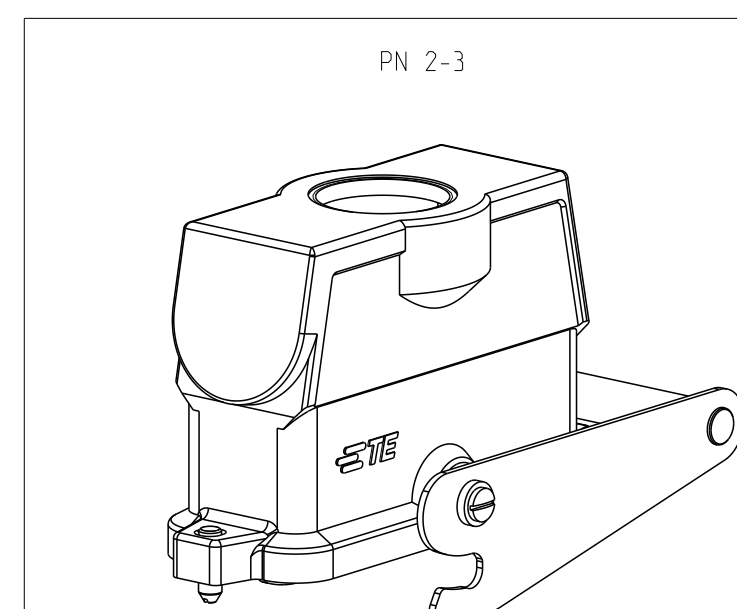
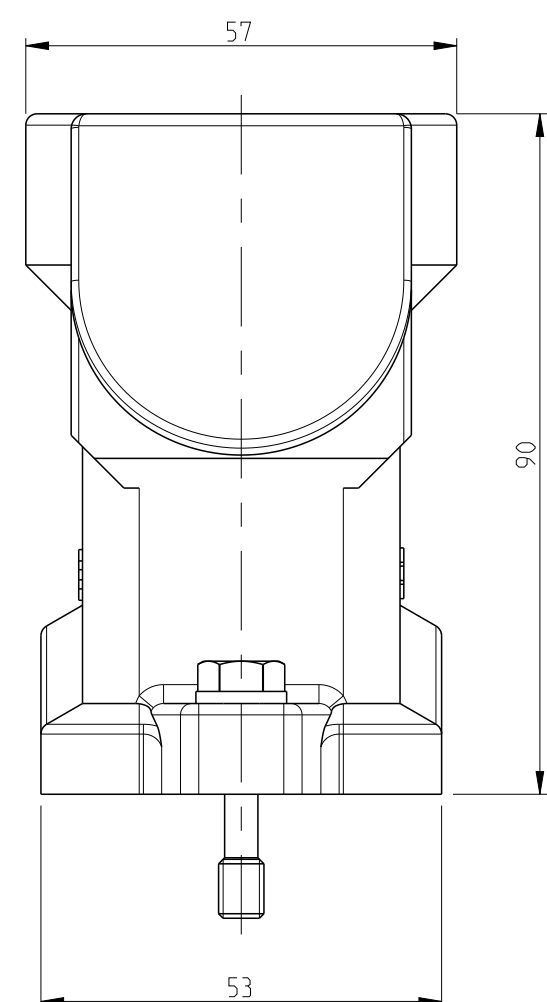
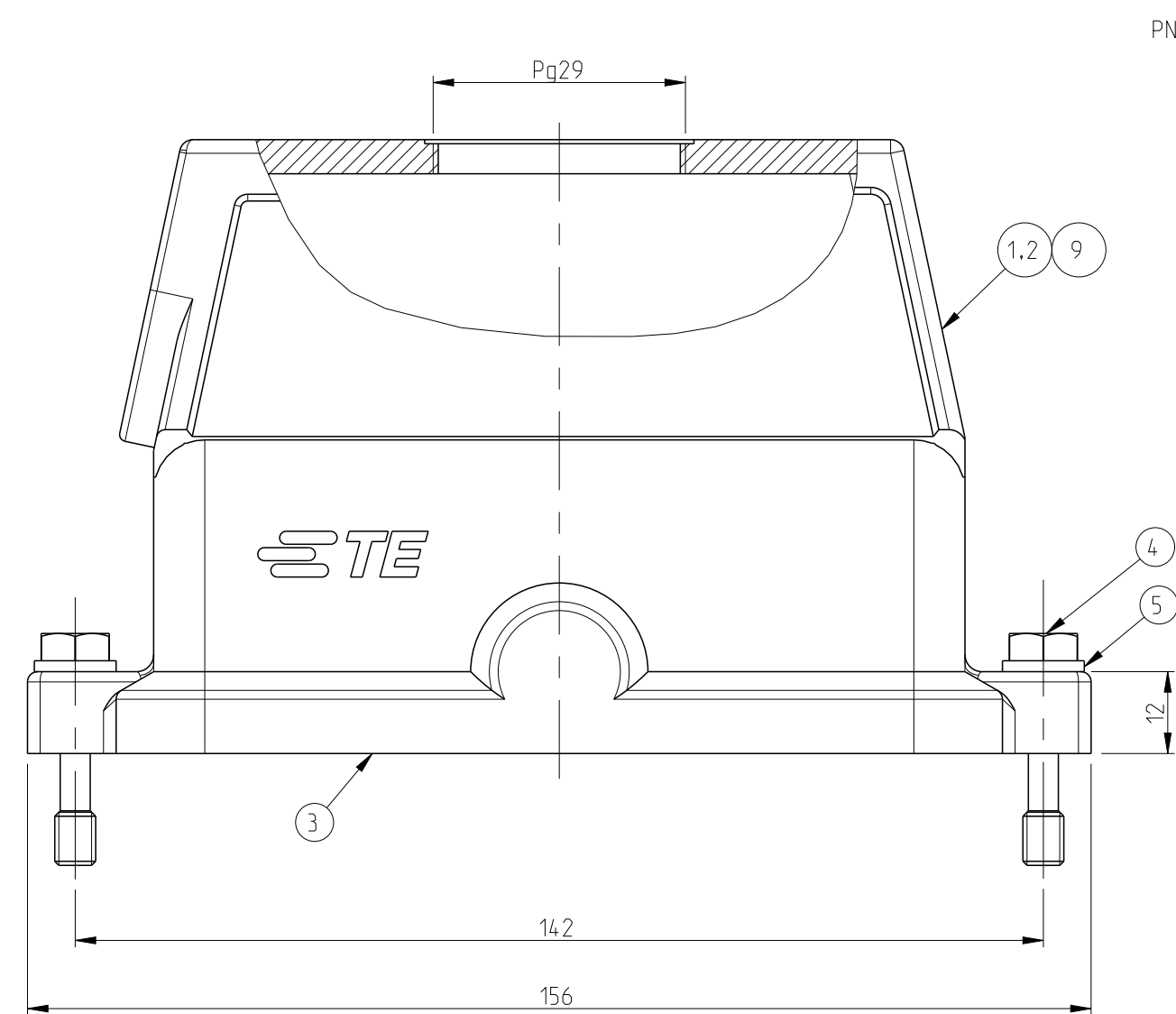
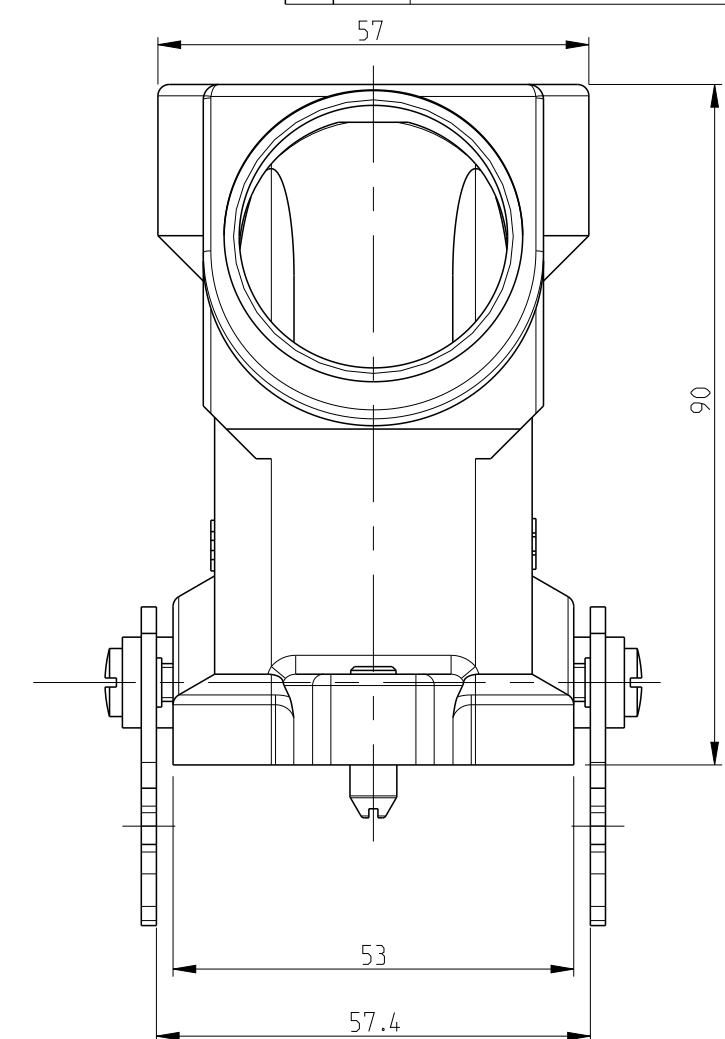
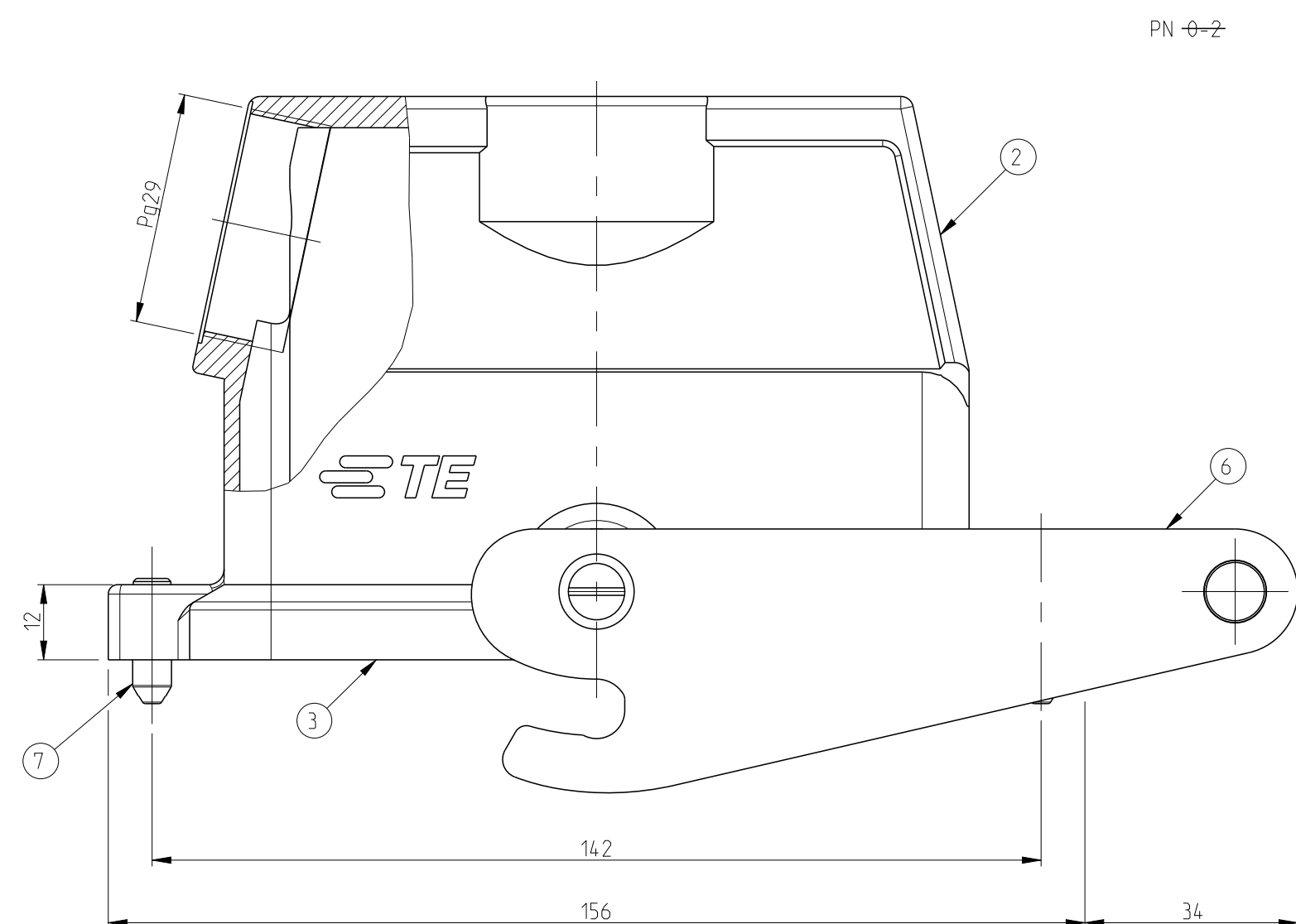


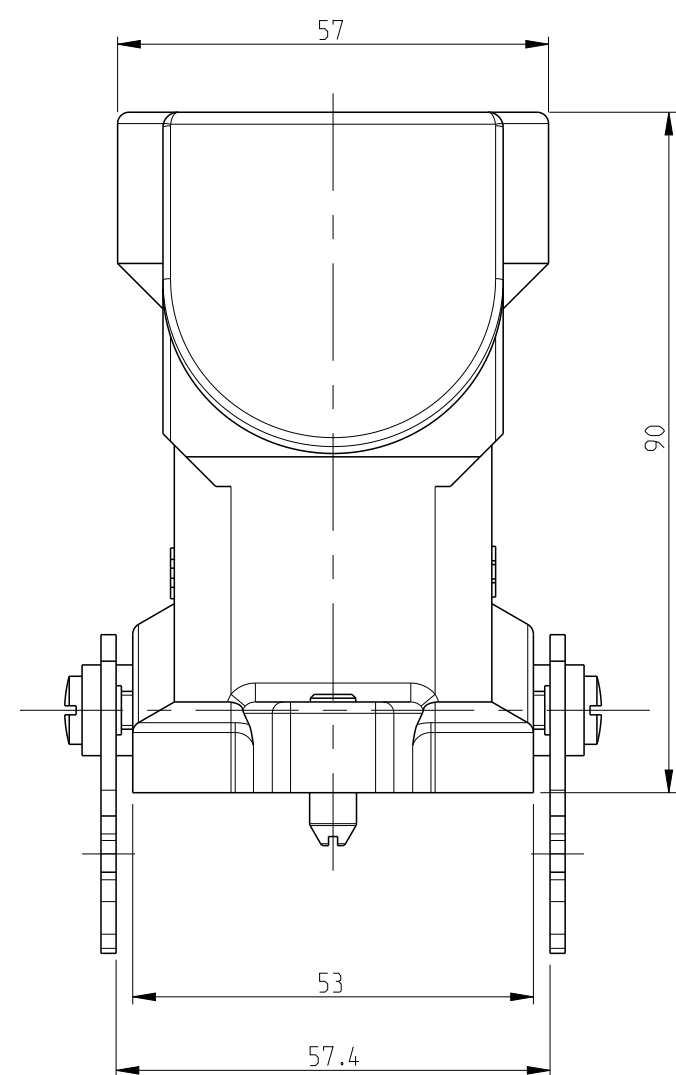

- NOTES
- 1 Material: Housing: Aluminium Diecasting Alloy
Seals: Neoprene
- 2 Surface:- Varnish-grey
Aluminium oxide+
Varnish black
- 3 Varnish on the inside not necessary
- 4 Packaging quantity: 5 pieces in a box

OBSOLETE		OBSOLETE								
1					Hood HIP	Aluminium		No varnish	9	Without varnish
					Hood HIP-K	Aluminium	Aluminium oxide	Black	8	Sonder Logo without PG-Thread
	2			2	Guide bolt	Stainless steel		Blank	7	
				1	ZB-Central clip	Stainless steel		Blank	6	
2	2	2	2		Spring washer	Stainless steel		Blank	5	B6.4
	2	2	2		Fixing screw	Stainless steel		Blank	4	M6x30
1	1		1	1	Seal	Neoprene		Black	3	
1	1		1	1	Hood HIP-K	Aluminium	Aluminium oxide	Black	2	
				1	Hood HIP	Aluminium		Grey	1	
0-3	0-2	0-1	2-5	2-3	DESCRIPTION	MATERIAL	SURFACE	COLOR	ITEM NO	REMARKS
					ORDERING TEXT					
					HIP-K-Z.24/64-ST0-ZB-1.29.G					
					HIP-24/64-ST0-1.29.G					
					HIP-K-24/64-ST-1.29.G					
					HIP-K-24/64-ST-WE					
					HIP-K-Z.24/64-ST5-ZB-1.29.G					
					HIP-24/64-ST0-1.29.G					

THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN 24.06.1998 CHK Schneider 24.06.1998 CHK Schneider 24.06.1998		 TE Connectivity	
DIMENSIONS:		TOLERANCES UNLESS OTHERWISE SPECIFIED:		NAME	
mm	0 PLC ± 1 PLC ± 2 PLC ± 3 PLC ± 4 PLC ± ANGLES ±	PRODUCT SPEC 108-74030 APPLICATION SPEC 114-74017		Hood HIP-K.24/64.ST0.1.29.G	
		FINISH		SIZE	CAGE CODE
MATERIAL		WEIGHT		DRAWING NO	
		-		A 1 00779 C=1102664	
CUSTOMER DRAWING				SCALE	SHEET
				1:1	1 of 1
				REV	B0