


LJT00R (MS27466) — crimp wall mounting receptacle

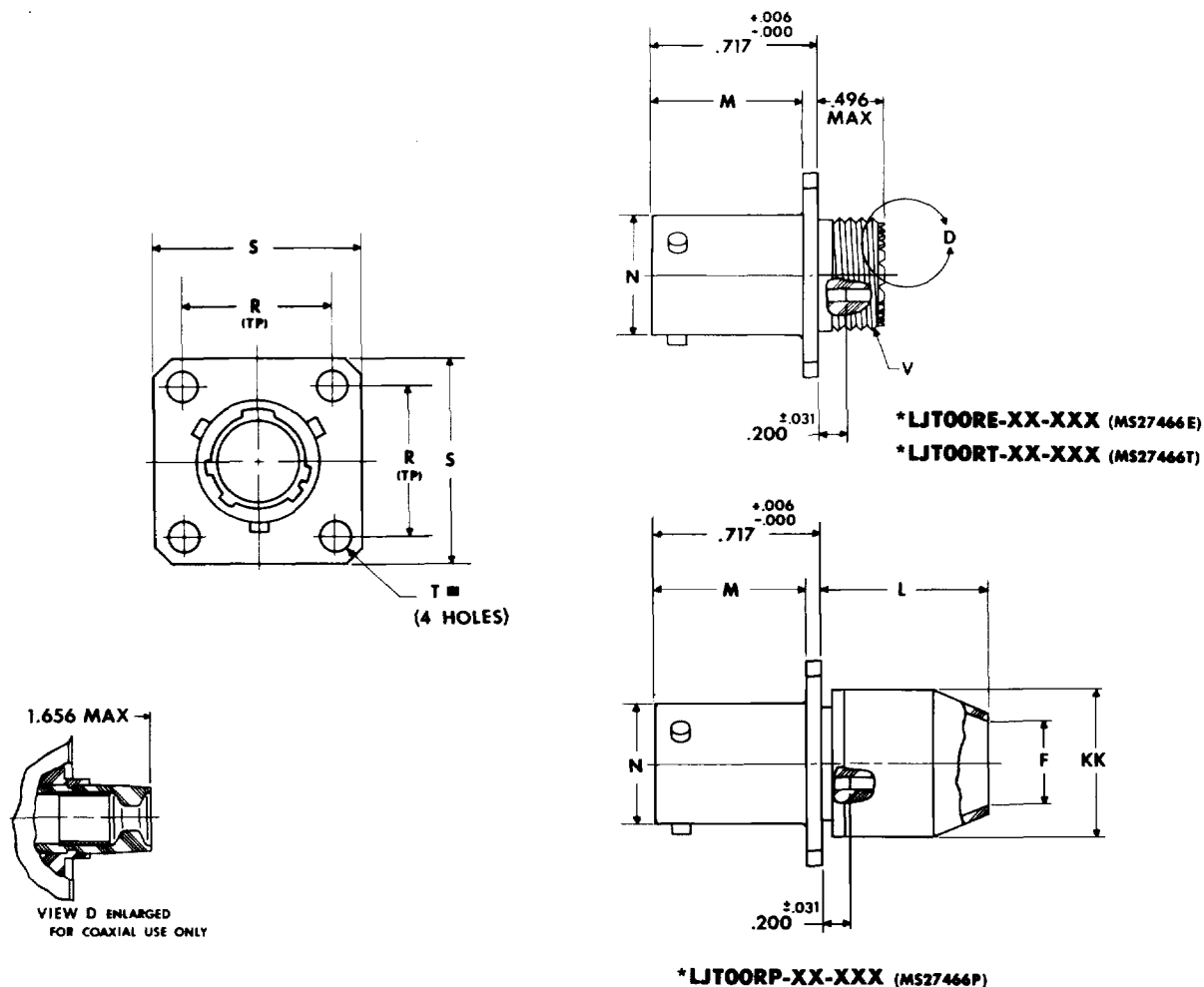

⌀.005 DIA Ⓜ

* To complete order number see page 47.

Shell Size	M +.000 -.005	V Thread Class 2A (Plated)	N +.001 -.005	S ±.016	R (TP)	T Dia. ±.005	F Dia.	KK Dia. Max.	L Max.
9	.632	.4375-28UNEF	.572	.938	.719	.128	.327	.608	.813
11	.632	.5625-24UNEF	.700	1.031	.812	.128	.444	.734	.813
13	.632	.6875-24UNEF	.850	1.125	.906	.128	.558	.858	.813
15	.632	.8125-20UNEF	.975	1.219	.969	.128	.683	.984	.813
17	.632	.9375-20UNEF	1.100	1.312	1.062	.128	.808	1.110	.813
19	.632	1.0625-18UNEF	1.207	1.438	1.156	.128	.909	1.234	.813
21	.602	1.1875-18UNEF	1.332	1.562	1.250	.128	1.034	1.360	.906
23	.602	1.3125-18UNEF	1.457	1.688	1.375	.147	1.159	1.484	.906
25	.602	1.4375-18UNEF	1.582	1.812	1.500	.147	1.284	1.610	.906

All dimensions for reference only.