


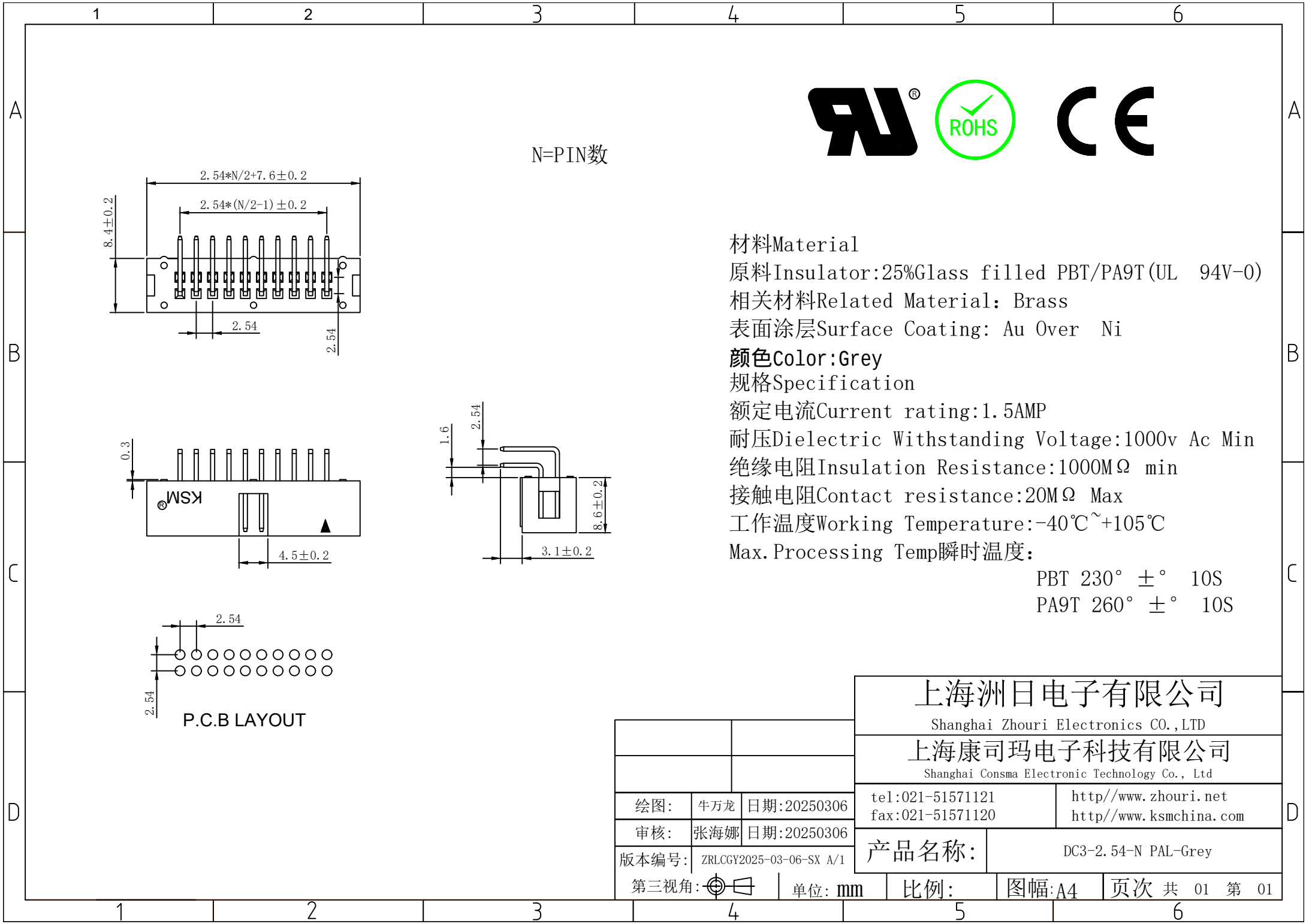

N=PIN数



材料Material
原料Insulator:25%Glass filled PBT/PA9T(UL 94V-0)
相关材料Related Material: Brass
表面涂层Surface Coating: Au Over Ni
颜色Color:Grey
规格Specification
额定电流Current rating:1.5AMP
耐压Dielectric Withstanding Voltage:1000v Ac Min
绝缘电阻Insulation Resistance:1000MΩ min
接触电阻Contact resistance:20MΩ Max
工作温度Working Temperature:-40℃~+105℃
Max.Processing Temp瞬时温度:
PBT 230° ±° 10S
PA9T 260° ±° 10S

上海洲日电子有限公司			
Shanghai Zhouri Electronics CO.,LTD			
上海康司玛电子科技有限公司			
Shanghai Consma Electronic Technology Co., Ltd			
绘图: 牛万龙		日期:20250306	
审核: 张海娜		日期:20250306	
版本编号: ZRLCGY2025-03-06-SX A/1		产品名称: DC3-2.54-N PAL-Grey	
第三视角: 		单位: mm	比例: 图幅:A4 页次 共 01 第 01