



Material材料

Insulator塑胶:30%Glass filled PBT, (UL 94V-0)

Contact 端子: Brass黄铜

Electrical Characteristics电气特性






Current rating额定电流:1.5AMP

Dielectric Withstanding Voltage耐压:
AC 1000V for 1Minute.

Insulator Resistance绝缘电阻:
1000M Ω Min. AT DC 500V.

Contact Resistance接触电阻:30M Ω Max. AT DC 100mA.

Operating Temperature工作温度:-40 $^{\circ}$ C~+105 $^{\circ}$ C

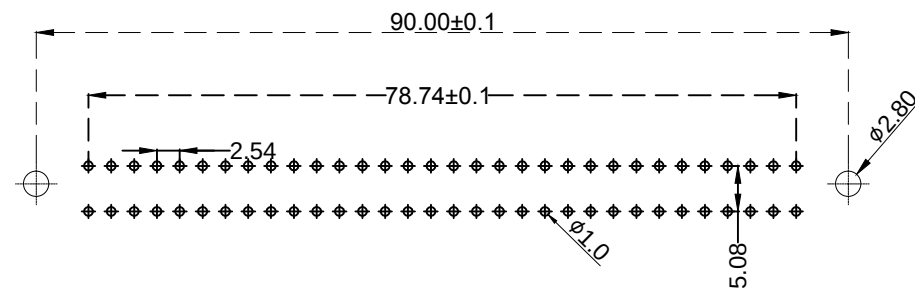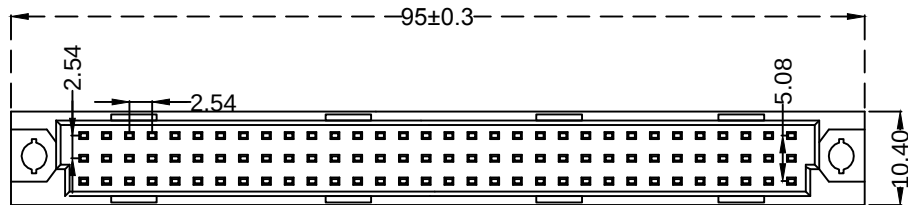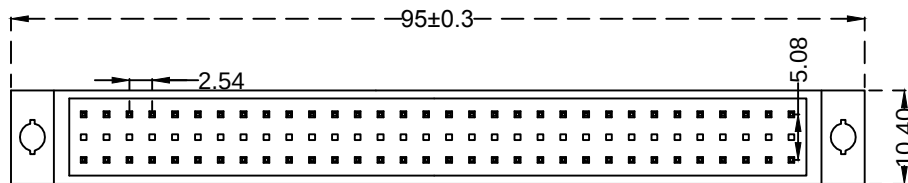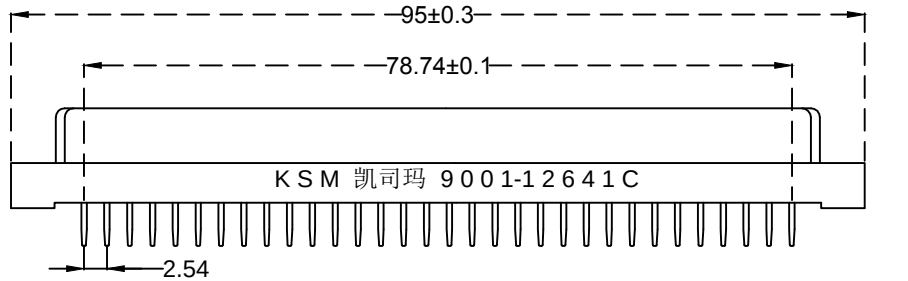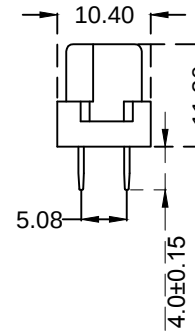

P.C.B LAYOUT

未注公差尺寸			KSM 9001-12641C 364		上海洲日电子有限公司 Shanghai Zhouri Electronics CO.,LTD									
尺寸	公差				上海康司玛电子设备进出口有限公司 Shanghai KangSiMa Eletronic Equipment import and export Co.,LTD									
	长度	角度												
X.	±0.3	±5°			版本号		20171018 A/0							
X.X	±0.2	±3°												
X.XX	±0.15													
绘图	周元金	201171018		图编号	ZR20171018-41		TEL:86-21-34975176/51571121							
审核	张海娜	201171018		物料编号	110662			1:1		mm	图幅	A4		
核准	章妹	20181122					: 1 1							