

## SUMMARY

### # Wires



High voltage	1
--------------	---

*Image is for illustrative purpose only*

Series	3Y
Termination type	Male solder High-Voltage
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	2.60 - 4.20 mm
Status	active
Matching parts	<a href="#">ERA.3Y.415.CTL</a>

### Download

[Request a quote](#)

[Catalog](#)

## TECHNICAL DETAILS

### Mechanics

Shell Style/Model	FFA*: Straight plug with cable collet
Keying	Circular
Housing Material	Brass (chrome plated [SAE AMS 2460]) shell and collet nut, nickel plated [SAE AMS QQ N 290] brass latch sleeve and mid pieces
Weight	106.02 g

### Performance

Configuration	3Y.415 : 1 High Voltage
Insulator	T: PTFE
Rated Current	15 Amps

### Specifications


Contact Type:	Solder
Test voltage (kV DC)	22.5
Test voltage (kV AC)	16
Creepage distance min.:	40 mm

### Others

Salt Spray Corrosion: >1000 hr

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

## DRAWINGS

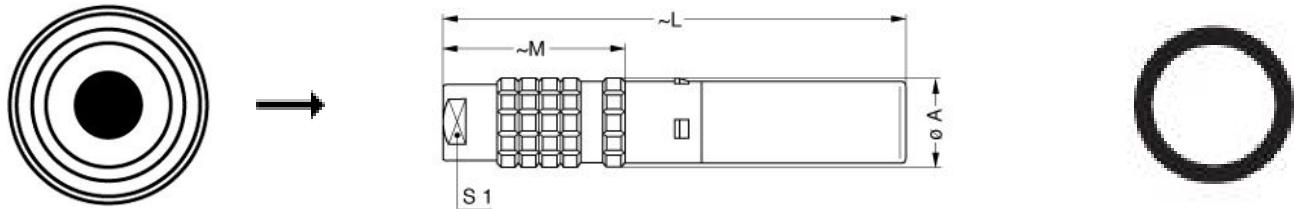

### Dimensions

	A	L	M	S1
mm.	19	98	42	15
in.	0,75	3,86	1,65	0,59

## RECOMMENDED BY LEMO

### Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.