

har-modular fixing rail 152.30

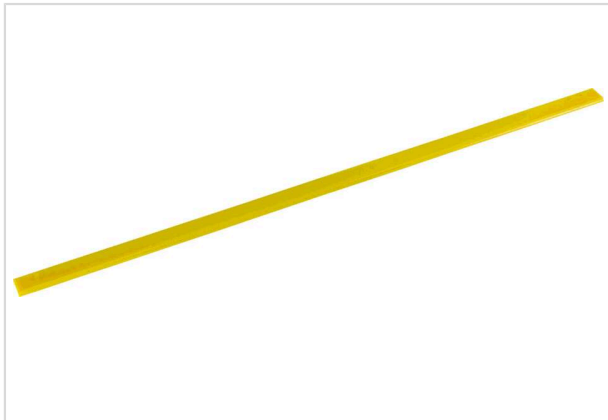


Image is for illustration purposes only. Please refer to product description.

Part number	02 09 500 1030
Specification	har-modular fixing rail 152.30
HARTING eCatalogue	https://b2b.harting.com/02095001030

Identification

Category	Accessories
Series	har-modular®
Type of accessory	Fixing rail

Technical characteristics

Length	152.3 mm
Limiting temperature	-55 ... +125 °C
Isolation group	I ($600 \leq CTI$)
Moisture Sensitivity Level (MSL)	1 acc. to ECA/IPC/JEDEC J-STD-020D

Material properties

Material (accessories)	Polyamide (PA)
Colour (accessories)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained
Fire protection on railway vehicles	EN 45545-2 (2020-08)



Pushing Performance
Since 1945

Material properties

Requirement set with Hazard Levels	R22 (HL 1-3)
	R23 (HL 1-3)

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E102079
	CSA-C22.2 No. 182.3 ECBT8.E102079

Commercial data

Packaging size	100
Net weight	1.05 g
Country of origin	Romania
European customs tariff number	85389099
GTIN	5713140216242
ETIM	EC002943
eCl@ss	27440292 Connector component (accessories)