

PZ 10 HEX ZERT**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com**Crimping tools for wire end ferrules, with and without plastic collars**

- Ratchet guarantees precise crimping
- Release option in the event of incorrect operation

General ordering data

Version	0.25mm ² , 10mm ² , Hexagonal crimp
Order No.	1989320000
Type	PZ 10 HEX ZERT
GTIN (EAN)	4050118373677
Qty.	1 pc(s).

PZ 10 HEX ZERT**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 26

D-32758 Detmold

Germany

www.weidmueller.com

Technical data**Dimensions and weights**

Width	195 mm	Width (inches)	7.677 inch
Net weight	510 g		

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1	SCIP	b28ab223-64ec-44cf-adb0-4dd6ebcae141
------------	----------------	------	--------------------------------------

Technical data

Description of article	(1)Crimping tool
------------------------	------------------

Description of contact

Conductor cross-section, max. AWG	AWG 8	Conductor cross-section, min. AWG	AWG 24
Crimping range, max.	10 mm ²	Crimping range, min.	0.25 mm ²
Type of contact	Wire-end ferrules with/ without plastic collars		

tool data crimping

Crimping type/profile	Hexagonal crimp	Wire end ferrules cross-section, max.	10 mm ²
Wire end ferrules cross-section, min.	0.25 mm ²		

Classifications

ETIM 6.0	EC000168	ETIM 7.0	EC000168
ETIM 8.0	EC000168	ECLASS 9.0	21-04-38-11
ECLASS 9.1	21-04-38-11	ECLASS 10.0	21-04-38-11
ECLASS 11.0	21-04-38-11	ECLASS 12.0	21-04-38-11

Downloads


User Documentation	Manual
Catalogues	Catalogues in PDF-format

PZ 10 HEX ZERT

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 26
D-32758 Detmold
Germany

www.weidmueller.com

Drawings

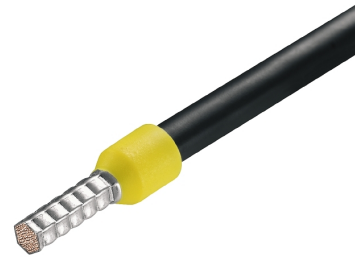

Example of use



Example of use



Example of use

