





REV.	ECN NO.	DATE	SIGN	DESCRIPTION
A	Initial Released	2020/11/25	Ruru	Old Item No. CX-00B0M32-7003

Unlock Tool
Part number: ULT-JOIN01

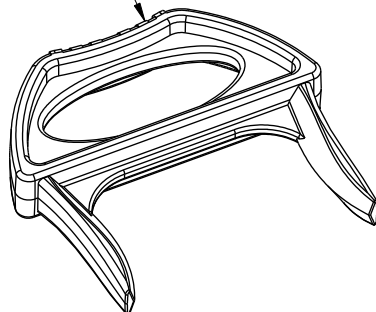

☉ Laser Mark:
YYYY = Year
WW = Week

Cable Joiner Housing Part Number
FC-001BNGY-700X

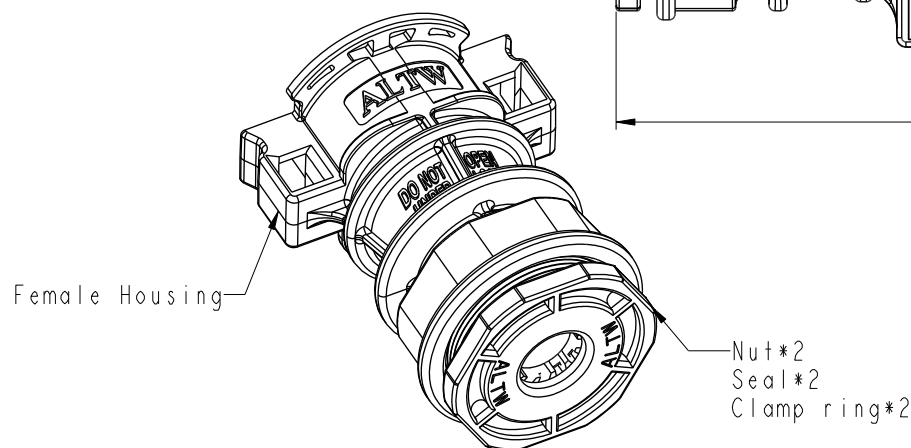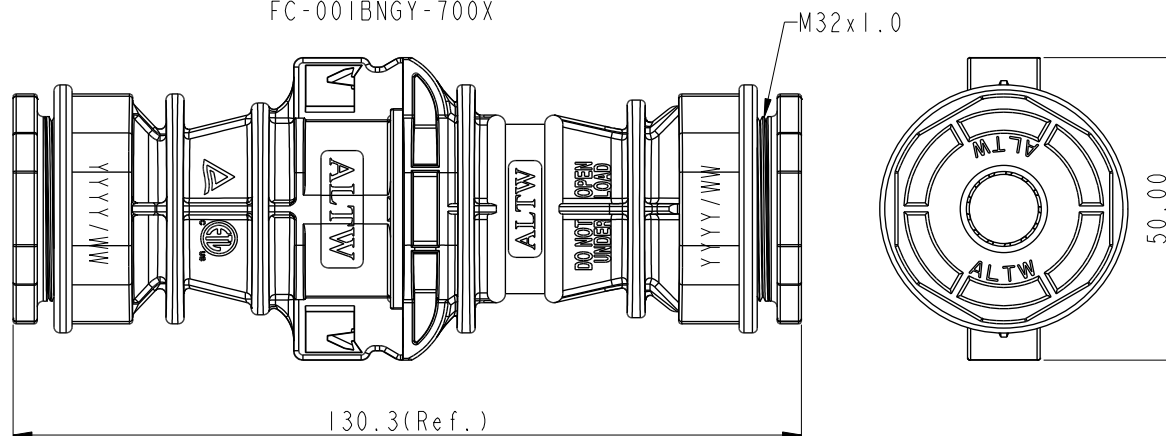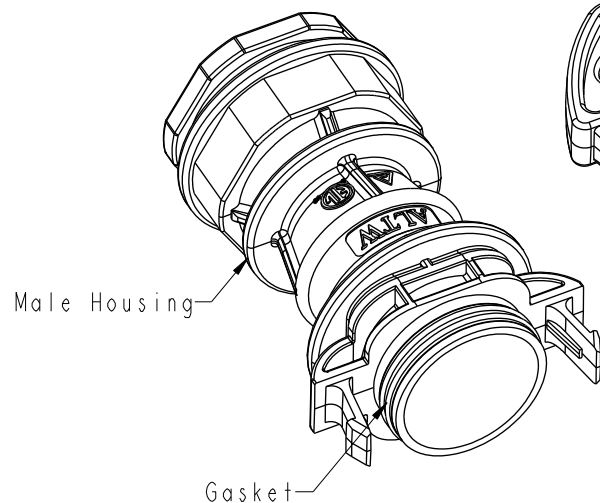

Note:

- * Waterproof Rate: IP67, Mated
- * Connector: Thermoplastic, Black
- * Butt Pin: Copper alloy
- * Gasket: Rubber, Gray
- * Disassembly-Using the Unlock tool.
- * Operating Temperature : -40~+105°C
- * Withstanding Voltage : 6KV
- * Pollution Degree : III
- * Cable OD Range: 10mm~08mm
- * Avoid oil and gasoline
- * Recommended sealing Nut torque
Minimum: 25Kgf-cm

* FC-001BNGY-700X
UL 6703A & TUV 2pfg 1915

UNIT:mm
TOLERANCE
±0.5 mm

TITLE
FICX, NONE, I, Field Installable
None, Gray
SCALE
4:5
SIZE
A4
SHEET
1 OF 1
REV.
A
WC-REV.
B.4
☉ Inspection item

Amphenol LTW
安費諾亮泰企業股份有限公司

ITEM NO FC-001BNGY-7003	DRAWN BY Ruru	DATE 2020-11-25
DWG NO FC-001BNGY-7003	CHECKED BY Rita	DATE 2020-11-25
CUSTOMER ALTW	APPROVED BY Max	DATE 2020-11-25