

## Frame Han 24HPR EasyCon Short PE-Mod-A-H

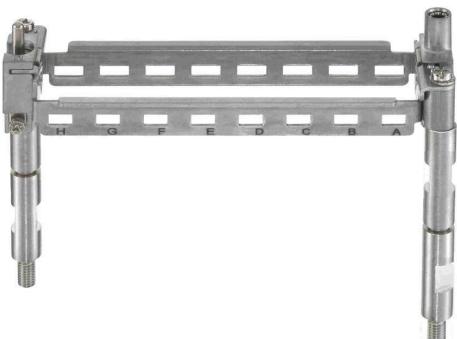


Image is for illustration purposes only. Please refer to product description.

Part number	09 40 024 9935
Specification	Frame Han 24HPR EasyCon Short PE-Mod-A-H
HARTING eCatalogue	<a href="https://b2b.harting.com/09400249935">https://b2b.harting.com/09400249935</a>

### Identification

Category	Accessories
Series of hoods/housings	Han® HPR EasyCon
Type of accessory	Frame
Description of the accessory	for up to 8 single modules A ... H Low construction

### Version

Size	24 B
Details	ATTENTION! Only to be used with Han® 24 HPR EasyCon Short hoods and housings!
Pack contents	1x male PE adapter 1x female PE adapter 2x M4/M5 distance bolts (AF 7) 2x M5/M6 distance bolts (AF 7) 2x M3 screw 2x M4 screw 2x washer SK S4

### Technical characteristics

Conductor cross-section	4 ... 10 mm <sup>2</sup> PE terminal power side 1 ... 2.5 mm <sup>2</sup> PE terminal signal side
Tightening torque	0.5 Nm Fixing screws M3 1.5 Nm Fixing screws M4 6 Nm Distance bolt 0.8 Nm PE terminal clamp 1 ... 2.5 mm <sup>2</sup> 1.5 Nm PE terminal clamp 4 ... 10 mm <sup>2</sup>
Limiting temperature	-40 ... +125 °C

## Technical characteristics

Mating cycles	≥500
---------------	------

## Material properties

Material (accessories)	Zinc die-cast Stainless steel
------------------------	----------------------------------

## Commercial data

Packaging size	1
Net weight	150 g
Country of origin	China
European customs tariff number	85389099
GTIN	5713140194472
ETIM	EC002310
eCl@ss	27440210 Fixing element for industrial connectors