


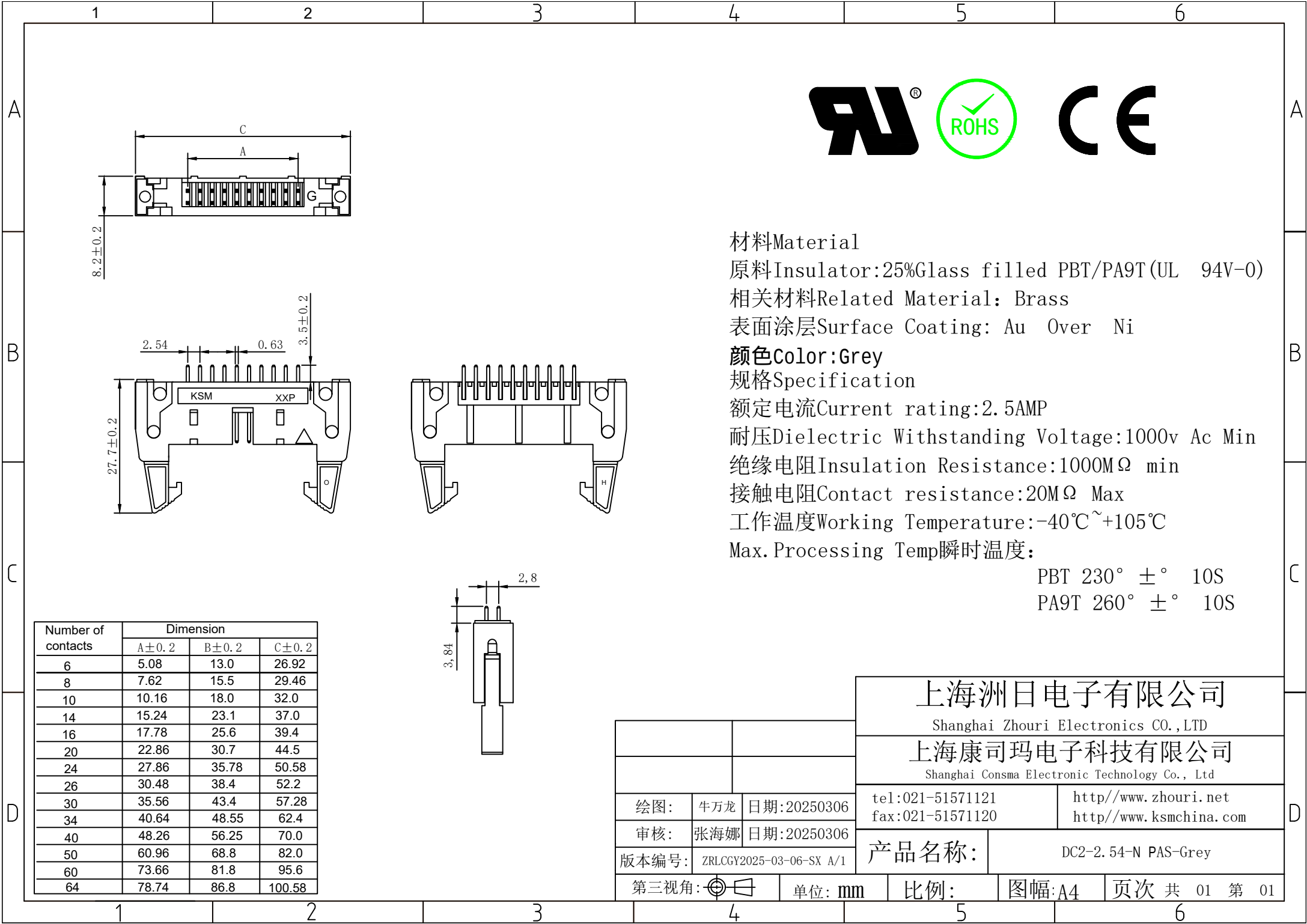

材料Material
原料Insulator:25%Glass filled PBT/PA9T(UL 94V-0)
相关材料Related Material: Brass
表面涂层Surface Coating: Au Over Ni
颜色Color:Grey
规格Specification
额定电流Current rating:2.5AMP
耐压Dielectric Withstanding Voltage:1000v Ac Min
绝缘电阻Insulation Resistance:1000MΩ min
接触电阻Contact resistance:20MΩ Max
工作温度Working Temperature:-40℃~+105℃
Max.Processing Temp瞬时温度:
PBT 230° ±° 10S
PA9T 260° ±° 10S

Number of contacts	Dimension		
	A±0.2	B±0.2	C±0.2
6	5.08	13.0	26.92
8	7.62	15.5	29.46
10	10.16	18.0	32.0
14	15.24	23.1	37.0
16	17.78	25.6	39.4
20	22.86	30.7	44.5
24	27.86	35.78	50.58
26	30.48	38.4	52.2
30	35.56	43.4	57.28
34	40.64	48.55	62.4
40	48.26	56.25	70.0
50	60.96	68.8	82.0
60	73.66	81.8	95.6
64	78.74	86.8	100.58

				上海洲日电子有限公司	
				Shanghai Zhouri Electronics CO.,LTD	
				上海康司玛电子科技有限公司	
				Shanghai Consma Electronic Technology Co., Ltd	
绘图:		牛万龙	日期:20250306	tel:021-51571121	http://www.zhouri.net
审核:		张海娜	日期:20250306	fax:021-51571120	http://www.ksmchina.com
版本编号:		ZRLCGY2025-03-06-SX A/1		产品名称:	DC2-2.54-N PAS-Grey
第三视角:		单位: mm	比例:	图幅:A4	页次 共 01 第 01