

DIALIGHT PART NUMBER	LED & LENS COLOR	TEST CONDITIONS	OPERATING CHARACTERISTICS AT 25°C AMBIENT									REV	ECN NO	REVISIONS	DRN	CKD	APP	DATE
			LUMINOUS INTENSITY (mcd)		FORWARD VOLTAGE (V)		FORWARD CURRENT (mA)		DOMINANT WAVELENGTH (nm)	PEAK WAVELENGTH (nm)	VIEWING ANGLE (DEG)	A	—	NEW RELEASE	BP	—	SK	1-3-17
			MIN	TYP	TYP	MAX	MIN	MAX	TYP	TYP	TYP							
555-2007-810F	RED, TINTED, DIFFUSED	I _F = 10mA	0.4	0.6	2.2	4.3	—	—	640	655	35							


ABSOLUTE MAXIMUM RATINGS (AT 25°C AMBIENT)	RED, TINTED DIFFUSED	UNITS
DC FORWARD VOLTAGE	—	V
DC FORWARD CURRENT	50	mA
REVERSE VOLTAGE (I _R =100μA)	5	V
OPERATING TEMP (NON-RESISTOR LAMPS)	-55 TO +100	°C
OPERATING TEMP (RESISTOR LAMPS)	-40 TO +85	
STORAGE TEMPERATURE	-55 to +100	°C
SOLDERING TEMPERATURE FOR 5 SEC	260	°C

RoHS Compliant 555-2007-810F

Part Numbers with the "F" suffix ending are RoHS Compliant.
Example: 555-2303F
Packaging is marked with "RoHS Compliant" label or equivalent markings. Parts can be wave soldered, dip soldered or hand soldered using typical lead-free soldering process with max 260°C temp. for 5 sec.

NOTES:


- PIN NUMBERS FOR REFERENCE ONLY, DESIGNATION NON-EXISTENT ON PART.
- DIALIGHT PART NUMBERS: 555-2007-810F.
- THIS ASSEMBLY CONTAINS ELECTROSTATIC DISCHARGE SENSITIVE DEVICES (ESDS). MAINTAIN ALL PRECAUTIONARY MEASURES DURING ASSEMBLY, HANDLING, AND STORAGE IN ACCORDANCE WITH IPC-A-610.
- LED LEAD DIMENSIONS SHOWN ARE MEASURED AT HOUSING EXIT.
- LEADS TO FIT INTO HOLES SPACED AS PER PATTERN.
- LED LEADS - PURE Sn PLATING OVER OLIN 194 COPPER ALLOY BASE METAL

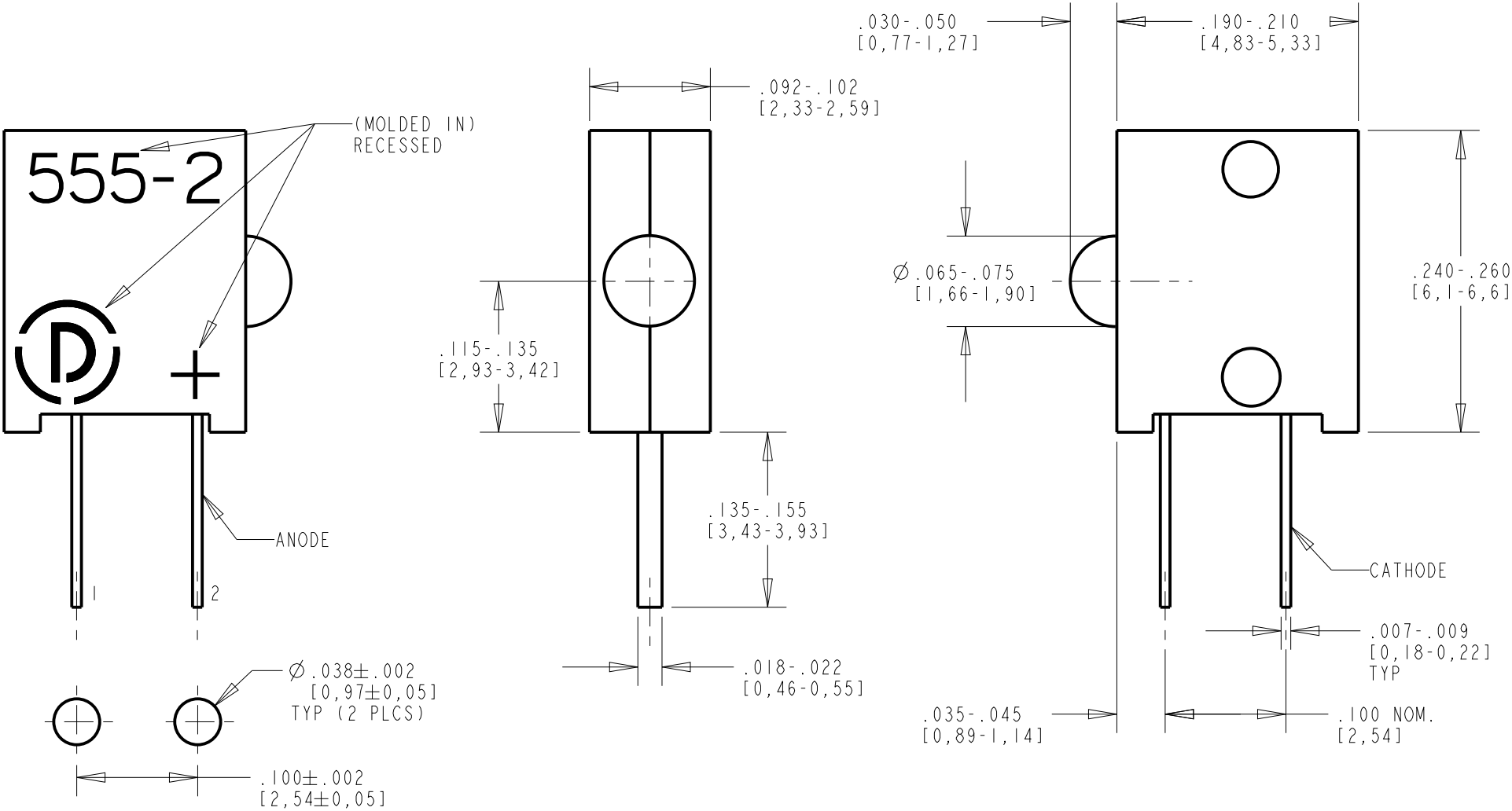

RECOMMENDED HOLE PATTERN



ATTENTION:
OBSERVE PRECAUTIONS FOR
HANDLING ELECTROSTATIC
SENSITIVE DEVICES

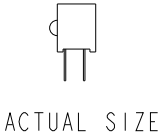

ACTUAL SIZE

THIS DRAWING AND THE CONTENTS HEREIN ARE CONFIDENTIAL AND THE SOLE PROPERTY OF DIALIGHT. REPRODUCTION OF THIS DRAWING OR CONSTRUCTION OF ANY PARTS WITHIN THIS DRAWING ARE FORBIDDEN WITHOUT THE WRITTEN CONSENT OF DIALIGHT.		
SCALE: 8.000 ALL DIM'S IN: INCHES (MM)	DRAWING NUMBER C-18241	REV A
TOLERANCES: UNLESS OTHERWISE SPECIFIED FRACTIONS: ±1/64 DECIMALS (.XX): ±.02 DECIMALS (.XXX): ±.015	TITLE Ø2mm SINGLE CBI, RIGHT ANGLE ESDBAG, RoHS COMPLIANT	
ANGLES: ±3° FINISH:	MATERIAL	
FSCM 83330	Dialight	1501 ROUTE 34 SOUTH FARMINGDALE, NJ 07727
SHEET 1 OF 1 FAMILY TABLE:		