

SUMMARY

Wires

High voltage 8



Image is for illustrative purpose only

Series	2P
Termination type	Female solder
IP rating	50
AWG wire size	0.00 - 0.00
Cable Ø	3.20 - 5.20 mm
Status	active

Download

[Request a quote](#)

[Catalog](#)

TECHNICAL DETAILS

Mechanics

Shell Style/Model CR*: Free receptacle with cable collet

Keying

Housing Material PSU (Polysulfone), black

Weight 9.55 g

Performance

Configuration 2P.H08 : 8 High Voltage

Insulator

Rated Current 6.5 Amps

Specifications

Test voltage contact-contact : 10.3 kV rms

Air clearance min.: 7.42 mm


Creepage distance min.: 7.42 mm

Others

Temp (min / max): -50°C / +150°C

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.

DRAWINGS

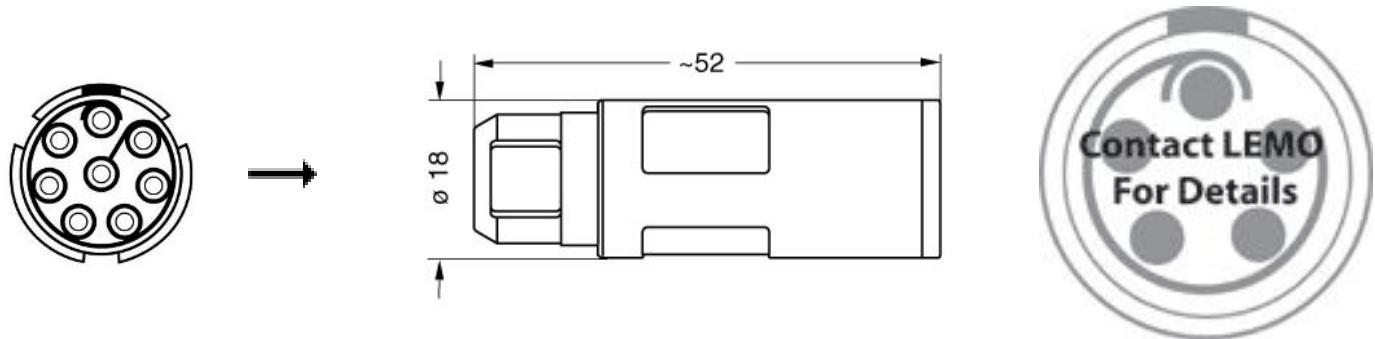

Dimensions

	A	L
mm.	18	52
in.	0,71	2,05

RECOMMENDED BY LEMO

Tools

LEMO products and services are provided "as is". LEMO makes no warranties or representations with regard to LEMO product & services or use of them, express, implied or statutory, including for accuracy, completeness, or security. The user is fully responsible for his products and applications using LEMO components.