
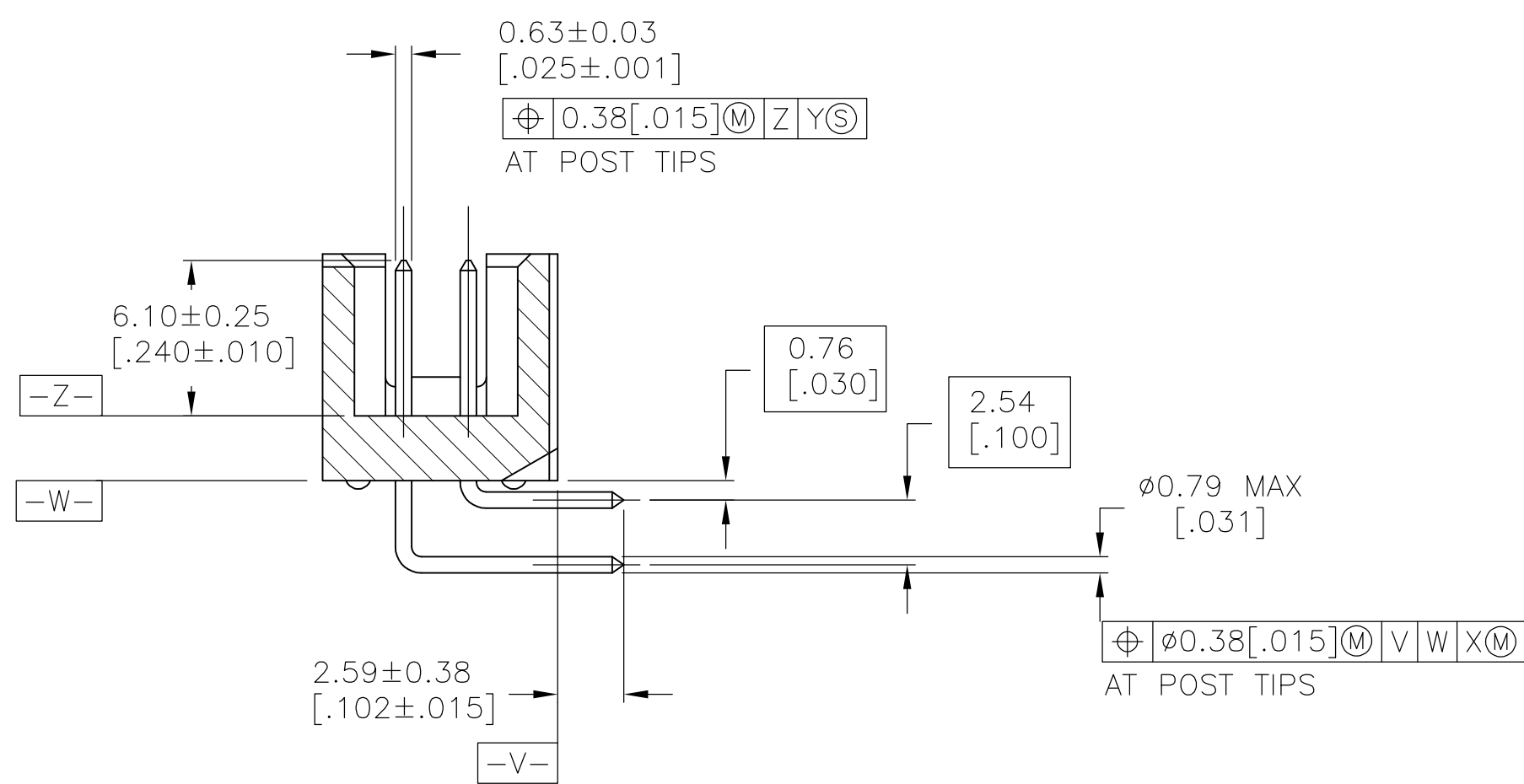


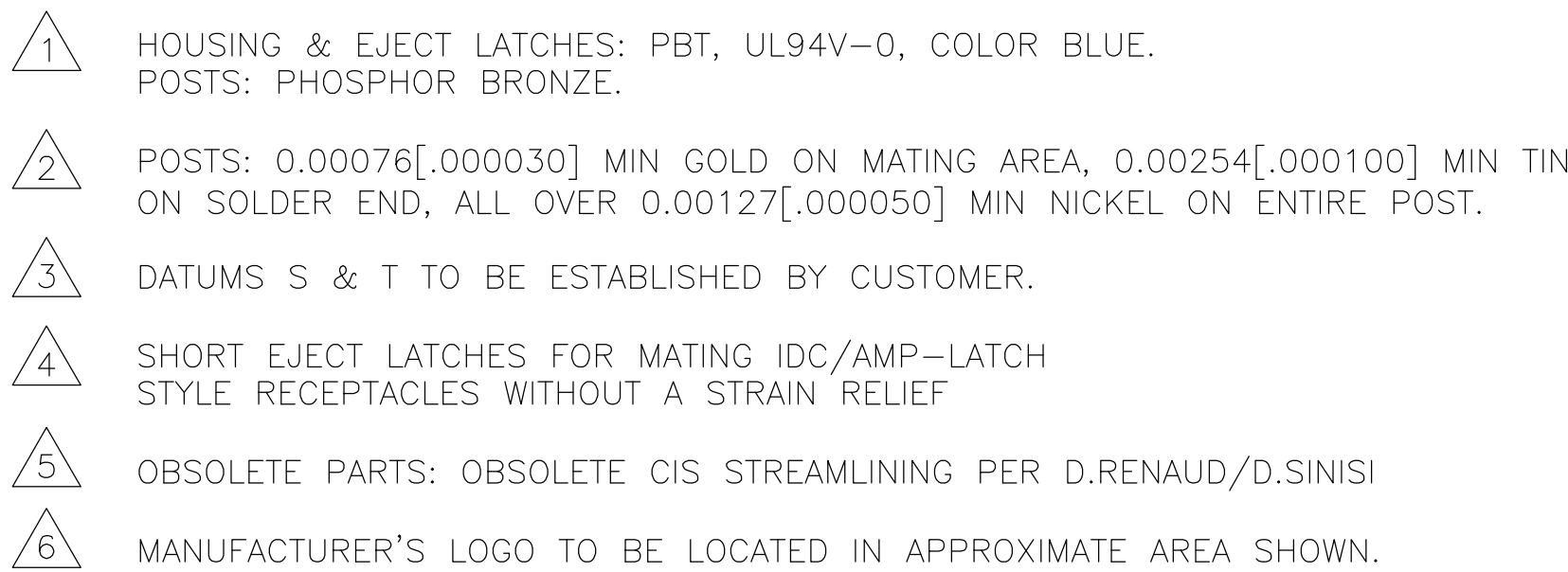

5	OBSOLETE	78.74 [3.100]	31	86.36 [3.400]	100.33 [3.950]	64	1-1761689-7
	OBSOLETE	73.66 [2.900]	29	81.28 [3.200]	95.25 [3.750]	60	1-1761689-6
	OBSOLETE	60.96 [2.400]	24	68.58 [2.700]	82.55 [3.250]	50	1-1761689-5
5	OBSOLETE	48.26 [1.900]	19	55.88 [2.200]	69.85 [2.750]	40	1-1761689-3
	OBSOLETE	40.64 [1.600]	16	48.26 [1.900]	62.23 [2.450]	34	1-1761689-1
	5	OBSOLETE	35.56 [1.400]	14	43.18 [1.700]	57.15 [2.250]	30
30.48 [1.200]			12	38.10 [1.500]	52.07 [2.050]	26	1761689-9
27.94 [1.100]			11	35.56 [1.400]	49.53 [1.950]	24	1761689-8
22.86 [.900]			9	30.48 [1.200]	44.45 [1.750]	20	1761689-7
5	OBSOLETE	17.78 [.700]	7	25.40 [1.000]	39.37 [1.550]	16	1761689-6
	OBSOLETE	15.24 [.600]	6	22.86 [.900]	36.83 [1.450]	14	1761689-5
		12.70 [.500]	5	20.32 [.800]	34.29 [1.350]	12	1761689-4
5	OBSOLETE	10.16 [.400]	4	17.78 [.700]	31.75 [1.250]	10	1761689-3
		D	C	B	A	NO OF POS	PART NUMBER

4805 (1/08)